



LED InstantFit Lamps

24T5 LED/HO/48-3000 IF 10/1

Philips LED T8 InstantFit Lamps are an ideal energy saving choice for existing linear fluorescent fixtures.


Product data

General Information		Voltage (Nom)	
Cap-Base	G5 [G5]	39-64 V	
Nominal Lifetime (Nom)	50000 h	Temperature	
Switching Cycle	50000X	T-Ambient (Max)	45 °C
B50L70	50000 h	T-Ambient (Min)	-20 °C
		T-Storage (Max)	65 °C
		T-Storage (Min)	-40 °C
Light Technical		Controls and Dimming	
Color Code	830 [CCT of 3000K]	Dimmable	No
Initial lumen (Nom)	3300 lm	Mechanical and Housing	
Luminous Flux (Rated) (Nom)	3300 lm	Product Length	1100 mm
Correlated Color Temperature (Nom)	3000 K	Approval and Application	
Color Consistency	<5	Energy Saving Product	Yes
Color Rendering Index (Nom)	82	Approbation Marks	UL certificate RoHS compliance
LLMF At End Of Nominal Lifetime (Nom)	70 %	Product Data	
Operating and Electrical		Order product name	24T5 LED/HO/48-3000 IF 10/1
Input Frequency	40000-80000 Hz	EAN/UPC - Product	046677467128
Power (Rated) (Nom)	24 W	Order code	467126
Lamp Current (Max)	600 mA	Numerator - Quantity Per Pack	1
Lamp Current (Min)	400 mA	Numerator - Packs per outer box	10
Starting Time (Nom)	0.5 s		
Warm Up Time To 60% Light (Nom)	0.5 s		
Power Factor (Nom)	0.9		

LED InstantFit Lamps

Material Nr. (12NC)	929001283704
Net Weight (Piece)	0.170 kg


Dimensional drawing

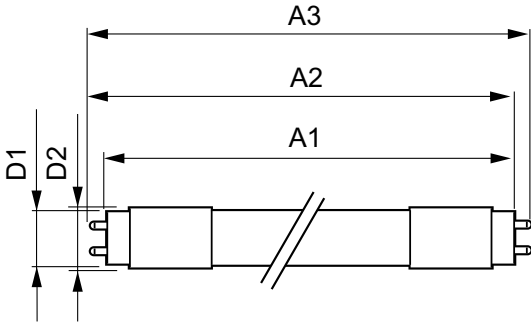

TLED 120V 24-54W 3600lm 3000K G5

Product	D1	D2	A1	A2	A3
---------	----	----	----	----	----

General Uniform Lighting

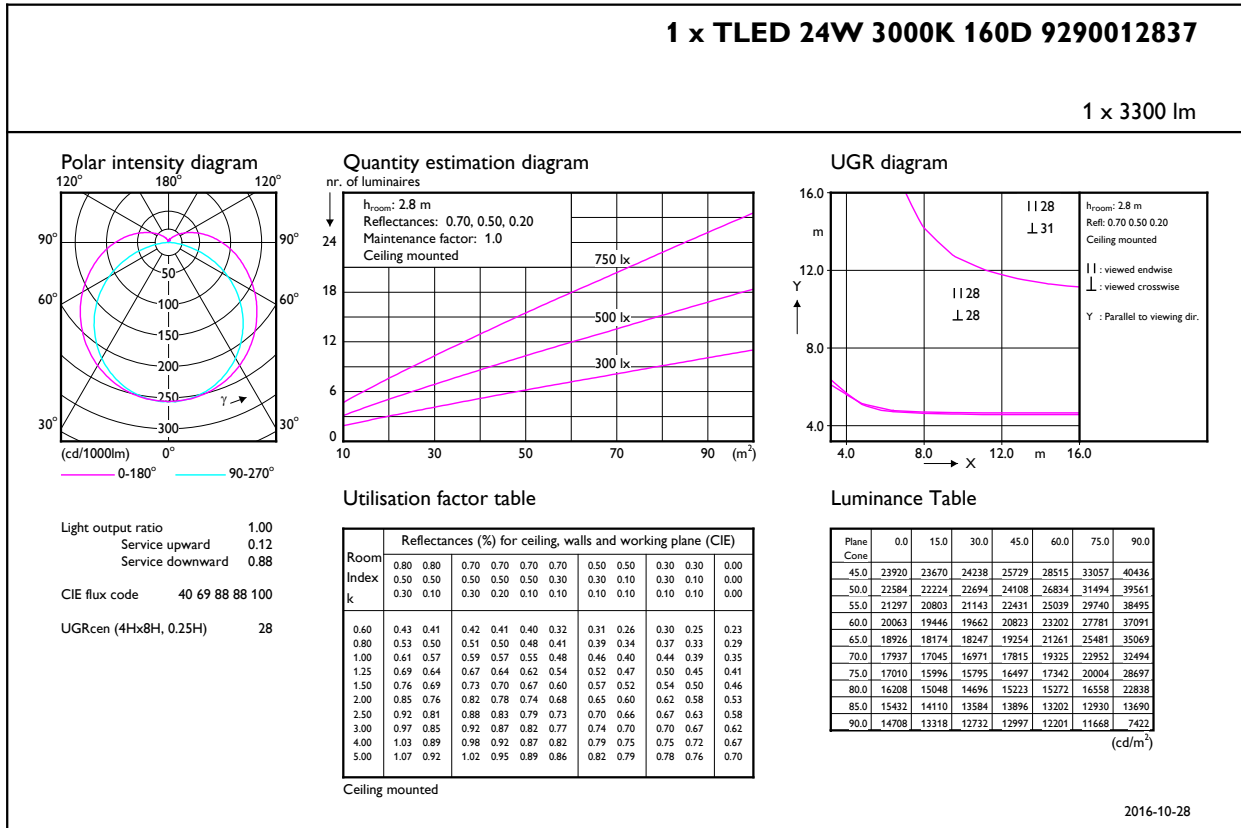

LED InstantFit Lamps

