



LED InstantFit Lamps

24T5 LED/HO/48-3500 IF 10/1

Philips LED T8 InstantFit Lamps are an ideal energy saving choice for existing linear fluorescent fixtures.


Product data

| General Information | | Voltage (Nom) | 39-64 V |
|---------------------------------------|---------------------|---------------------------------|--------------------------------|
| Cap-Base | G5 [G5] | Temperature | |
| Nominal Lifetime (Nom) | 50000 h | T-Ambient (Max) | 45 °C |
| Switching Cycle | 50000X | T-Ambient (Min) | -20 °C |
| B50L70 | 50000 h | T-Storage (Max) | 65 °C |
| | | T-Storage (Min) | -40 °C |
| Light Technical | | Controls and Dimming | |
| Color Code | 835 [CCT of 3500K] | Dimmable | No |
| Initial lumen (Nom) | 3300 lm | Mechanical and Housing | |
| Luminous Flux (Rated) (Nom) | 3300 lm | Product Length | 1100 mm |
| Correlated Color Temperature (Nom) | 3500 K | Approval and Application | |
| Color Consistency | <5 | Energy Saving Product | Yes |
| Color Rendering Index (Nom) | 82 | Approbation Marks | UL certificate RoHS compliance |
| LLMF At End Of Nominal Lifetime (Nom) | 70 % | Product Data | |
| Operating and Electrical | | Order product name | 24T5 LED/HO/48-3500 IF 10/1 |
| Input Frequency | 40000-80000 Hz | EAN/UPC - Product | 046677467135 |
| Power (Rated) (Nom) | 24 W | Order code | 467134 |
| Lamp Current (Max) | 600 mA | Numerator - Quantity Per Pack | 1 |
| Lamp Current (Min) | 400 mA | Numerator - Packs per outer box | 10 |
| Starting Time (Nom) | 0.5 s | | |
| Warm Up Time To 60% Light (Nom) | 0.5 s | | |
| Power Factor (Nom) | 0.9 | | |

LED InstantFit Lamps

| | |
|---------------------|--------------|
| Material Nr. (12NC) | 929001283804 |
| Net Weight (Piece) | 0.170 kg |


Dimensional drawing

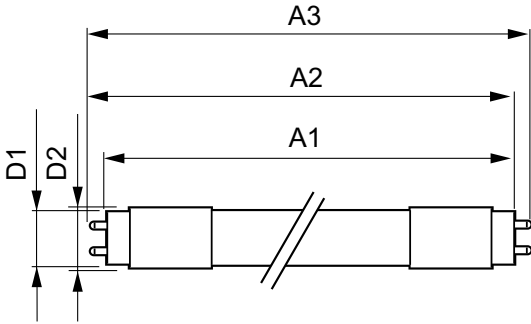

TLED 120V 24-54W 3600lm 3500K G5

| Product | D1 | D2 | A1 | A2 | A3 |
|---------|----|----|----|----|----|
|---------|----|----|----|----|----|

General Uniform Lighting

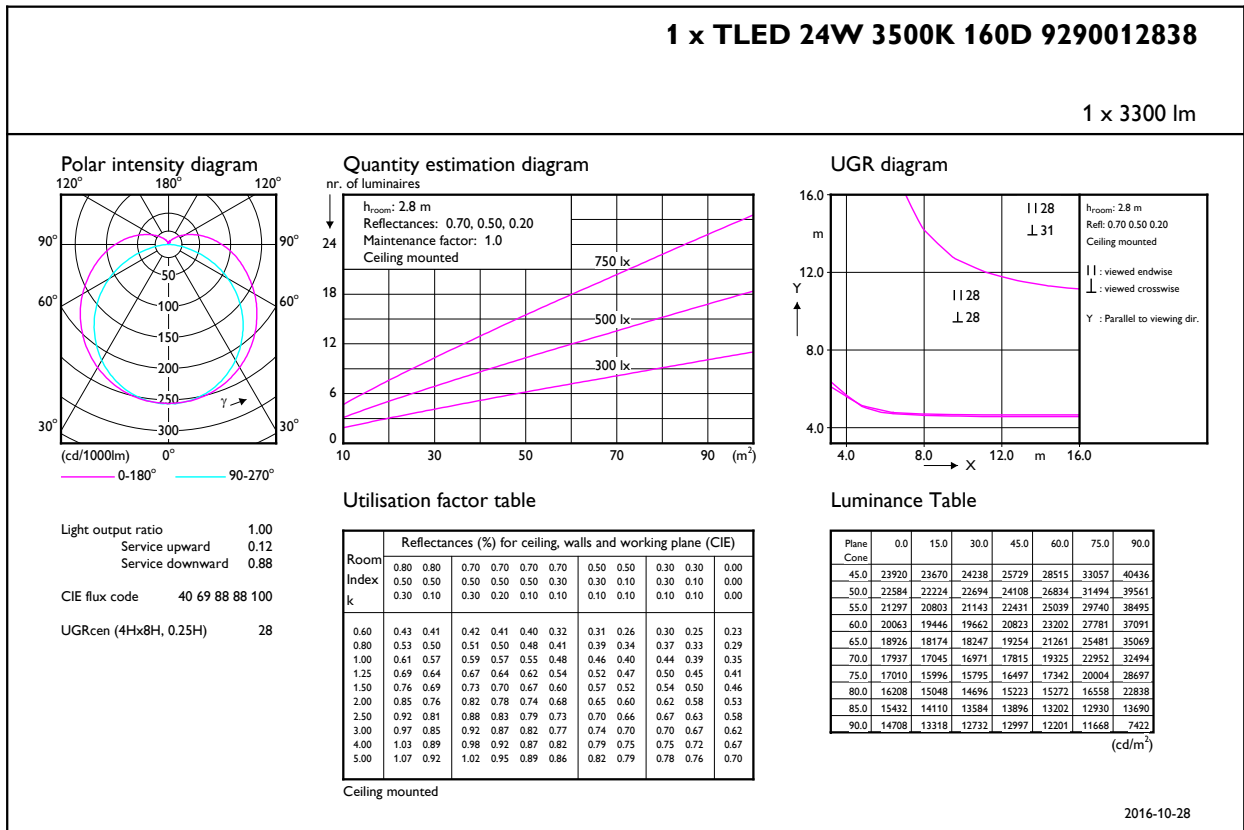

2016-10-28

LED InstantFit Lamps

