



A-Shape LED

8.5A19/LED/827/ND 120V 2PK/4

Philips A-shape Dimmable LED lamps are the smart LED alternative to standard incandescents. The unique lamp design provides omi-directional light with excellent dimming performance.

Product data

General Information

Cap-Base	E26 [Single Contact Medium Screw]
Nominal Lifetime (Nom)	10950 h
Switching Cycle	50000X
Technical Type	8.5-60W

Light Technical

Color Code	827 [CCT of 2700K]
Luminous Flux (Nom)	800 lm
Luminous Flux (Rated) (Nom)	800 lm
Color Designation	Warm White (WW)
Correlated Color Temperature (Nom)	2700 K
Luminous Efficacy (rated) (Nom)	94 lm/W
Color Consistency	ANSI
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %

Operating and Electrical

Input Frequency	60 Hz
Power (Rated) (Nom)	8.5 W
Lamp Current (Nom)	125 mA
Wattage Equivalent	60 W
Starting Time (Nom)	0.5 s

Warm Up Time To 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.5
Voltage (Nom)	120 V

Temperature

T-Case Maximum (Nom)	100 °C
----------------------	--------

Controls and Dimming

Dimmable	No
----------	----

Mechanical and Housing

Bulb Finish	Frosted
-------------	---------

Approval and Application

Suitable For Accent Lighting	No
------------------------------	----


Product Data

Order product name	8.5A19/LED/827/ND 120V 2PK/4
EAN/UPC - Product	50046677462159
Order code	929001135034
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	4
Material Nr. (12NC)	929001135034

A-Shape LED

Net Weight (Piece)	0.052 kg
--------------------	----------

Dimensional drawing

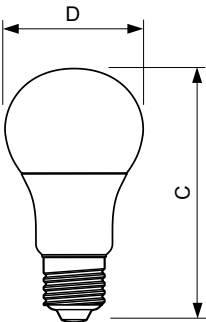

Bulb A19 120V 8.5W-60W 150D 2700K E26 ND

Product	D	C
8.5A19/LED/827/ND 120V 2PK/4	61 mm	107 mm

Photometric data

