


# Low Voltage

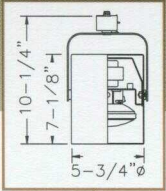


## Versalyte PAR-36

This is one of the most versatile low voltage luminaires in the Lytespan system. It can accommodate very narrow spot 5.5V PAR-36 lamps which are perfect for accenting small objects at long distances. It can also take the full range of 12V PAR-36 lamps from 25W to 50W, offering beam spreads from the very narrow to the very wide. The key is the built-in voltage 5.5V / 12V selector switch. Patented snap-in socket makes relamping easy by eliminating the need to attach leads to lamp terminals.

### Magnetic Transformer

**55211WH** White  
**55211BK** Black  
 PAR-36 50W max. 12V  
 PAR-36 25W max. 5.5V  
 Accessory Holders: 55203WH, 55203BK  
 Accessories: CF2, HF1, CC1, BD8, WW1, BE4, HC5, UV2

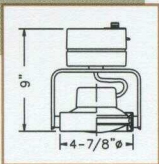

## Tron 36

This advanced Lytespot uses PAR-36 lamps for the strictest beam control applications. Lamp is regressed in housing for additional lateral shielding. Compact die-cast aluminum housing.

### Magnetic Transformer

**56613WH** White  
**56613BK** Black  
 PAR-36 50W Max.  
 Accessory Holders: 7653 (White), 7654 (Black)  
 Accessories: HC5, CF2, BE4, UV2, CC1

## Barelite



Available in kits, including one 40" track; two spots and a floating canopy; or as a single spot.

### Electronic Transformer

**850WH** White  
**850BK** Black  
 Single spot

**820WH** White  
**820BK** Black  
 Kit

MR-16 Bi-Pin 50W  
 Accessories: BE1, PS1, BS1, CF1, HC1, FL1, UV1

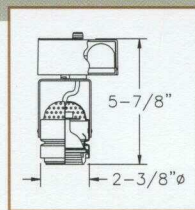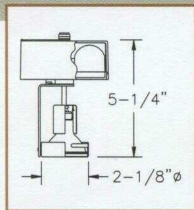

## Domelite

Available in kits including one 40" track, two spots and a floating canopy; or as a single spot.

### Electronic Transformer

**851WH** White  
**851BK** Black  
 Single spot

**821WH** White  
**821BK** Black  
 Kit

MR-16 Bi-Pin 50W  
 Accessories: BE1, PS1, BS1, CF1, HC1, FL1, UV1

For accessories see page 42.