



LED STEP LIGHT



OUTDOOR



INDOOR

LED FORMS

Inspiration will come in abundance once you try our LED accent step lights. Use them outdoors on your deck or on the stairs inside of your home. You will be truly impressed by the effect!

Key features

- **Integrated LED driver**
- **Indoor and outdoor use**
- **Fits in standard junction box**

MODEL

LEDSTEP001 4.5W LED step light, 3000°K, 355 Raw Lumens

SPECIFICATIONS


- Over 50,000 hours of service life.
- Warm white light output.
- Optimized light spread.
- Low power consumption.
- 120V AC direct connection.
- Excellent color rendering.
- Superior light color consistency.
- Esthetic profile.
- Die-cast aluminum housing.

INSTALLATION

- Fits on a standard junction box 3" L × 2" W × 2.5" D.
- Can be installed in indoor and outdoor applications.
- Non-visible hardware.

FINISH

BK	Black
BZ	Bronze
SG	Silver grey
WH	White

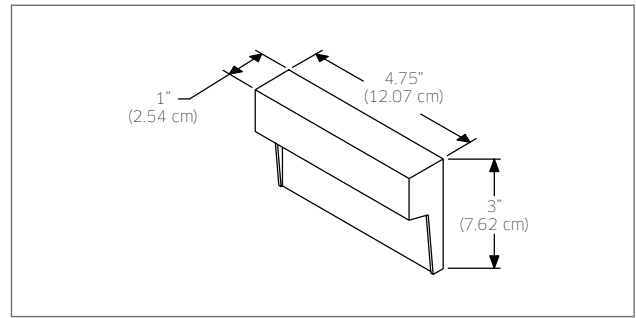


ORDERING EXAMPLE

LEDSTEP001-BK

Would order a LEDSTEP001 step light painted black.

TYPICAL LIGHT DISTRIBUTION

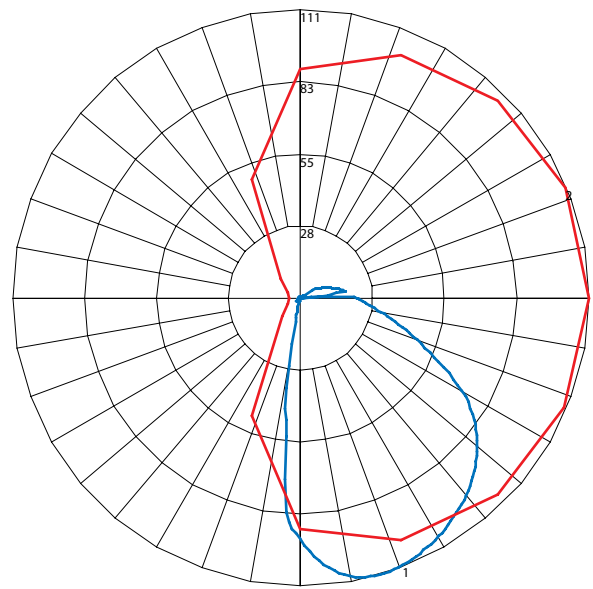

Red line is the horizontal cone through vertical angle (top view)
Blue line is the vertical plane through vertical angle (side view)

Visit our website for IES files .