

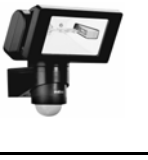




	Description	Part Number	Master Carton Qty	Suggested Trade
	Includes shrouds and soffit mount Accepts Par, PL, Fluorescent, R, or Quartz lamps, 150 watts 120 Volts AC			
	FL300B Dual Floodlight - Black *	61811	3	83.00
	FL300W Dual Floodlight - White *	61801	3	83.00
	Ultra Eye Lens with 2 motion sensors Includes shrouds and bulb Rain tight enclosure, UL rated IP54 120 Volts AC			
	HS150B 150 Watt Halogen Sensor Light - Black **	63301	3	83.00
	HS150W 150 Watt Halogen Sensor Light - White **	63311	3	83.00
	Ultra Eye Lens with 2 motion sensors Includes shrouds and bulb Rain tight enclosure, UL rated IP54 120 Volts AC			
	HS300B 300 Watt Halogen Sensor Light - Black	63321	3	94.00
	HS300W 300 Watt Halogen Sensor Light - White	63331	3	94.00
	Wall and ceiling mount IR motion detector Full circular 360° coverage, 40' Range Switching capacity 0 - 600 watts 120 Volts AC			
	IS360B Motion Sensor Switch - Black	60251	6	107.00
	IS360W Motion Sensor Switch - White	60261	6	107.00
	Switching Capacity 0 to 600 Watts No minimum load requirement Use with existing lights 120 Volts AC			
	IS140B Motion Sensor Switch - Black	60291	3	81.00
	IS140W Motion Sensor Switch - White	60301	3	81.00

* Energy Star Qualified when used in night lux setting with maximum of 100 watt bulbs.

** Energy Star qualified when used in night lux setting.