

HL 1810 S

Professional Heat Guns



 Double Insulated



HL 1810 S

Item No.	34820
With Case	34821
3 Stage Switch	Cool air stage 120°F / 3.6 CFM 750°F (399°C) / 10.0 CFM 1100°F (593°C) / 15.9 CFM
Output	1400 watts
Voltage	120 VAC / 60 Hz
Amps	11.7
Element	DuraTherm™ ceramic heating element
Power Cord	Industrial grade rubber, length: 6 ft
Dimensions	10.30" x 3.50" x 8.00" (l x w x h)
Nozzle Diameter	1.30" (33.02 mm)
Net Weight	1.92 lbs (30.72 oz)
Single Sell Pack	Dimension: 11.20" x 9.60" x 3.70" Weight: 2.93 lbs (46.88 oz)
Warranty	One year limited

HL 1810 S Three Stage Professional Heat Gun

- 3 Stage Switch
- Duratherm™ Heating Element
- Sleek, balanced design for comfortable long-term use
- Non-Slip Soft Stand

Multi-purpose heat gun with cool air stage and choice of 2 temperature settings for convenient hand-held or bench work. STEINEL's exclusive DuraTherm™ heating element ensures long life and even heat.

For shrink wrapping, activating adhesives, softening compounds, window tinting, bending plastics and other applications requiring long life and even heat



General Purpose Kit

- HL 1810 S
 - 20mm Reducer
 - 75mm Spreader
 - 39mm Reflector
 - 75mm Window Nozzle
 - Overhead Hanger
 - Guide Book
 - Heavy Duty Case
- No. 34822

Features

Made in E.U.



ISO 9001:2001




3 Stage Switch:
Cool / Low / High



Dual Air Filters



DuraTherm™
Heating Element

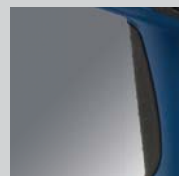

Soft Grip Handle



Rubber Stand



Rubber Power Cord