

PRODUCT CATALOG

> [Switches and Indicators](#) > [Indicator Lights](#) > [0820 and 0890 Series Indicator Lights \(while supplies last\); 0891 Series Indicator Lights](#)

0820 and 0890 Series Indicator Lights (while supplies last); 0891 Series Indicator Lights


McGill's indicator lights are ideal for machine, instrument, switch control panels, automotive, bus, RV, marine, and appliance industries. The 0820 and 0890 Series feature a matte finish and smooth rounded bezel corners for a distinct Euro-style look. The 0891 Series is conveniently blister carded for display racks or bulk packaged and is available in three styles.

- UL Recognized, CSA Certified
- Innovative, high-tech styling
- Choice of 14 or 28 Volt, 1.12 Watt incandescent or 125 Volt, .33 Watt neon lamps
- Available in red, green, amber, and clear lens colors
- Incandescent versions can be used in AC or DC applications
- .250 x .032 spade terminals are standard on 0820, 0890 and 0891 Series



0820 and 0890 Series (Black Matte Bezel) - Available While Supplies Last


Lens Color	Lamp Voltage	Cat. No.	
		0820 Miniature Series	0890 Standard Series
White	14V	0820-0001	0890-0001
Amber	14V	0820-0002	0890-0002
Red	14V	0820-0003	0890-0003
Green	14V	0820-0004	0890-0004
Amber	28V	0820-1002	--
Red	28V	0820-1003	--
Green	28V	0820-1004	--
White	125V AC	0820-2001	0890-2001
Amber	125V AC	0820-2002	0890-2002
Red	125V AC	0820-2003	0890-2003
Green	125V AC	0820-2004	0890-2004

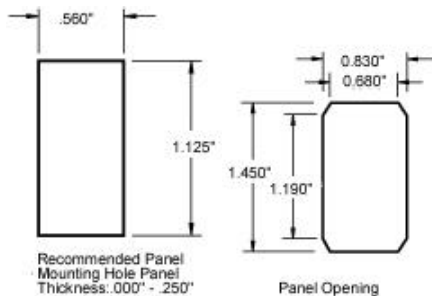

0891 Series Description


Rectangular Style Indicator Lights	Cat. No.		Flush Style Indicator Lights	Cat. No.		Raised Style Indicator Lights	Cat. No.	
	Blister Packed	Bulk Packed		Blister Packed	Bulk Packed		Blister Packed	Bulk Packed
14V Red	0891-1111	0891-2111	14V Red	0891-1311	0891-2311	14V Red	0891-1411	0891-2411
14V Green	0891-1121	0891-2121	14V Green	0891-1321	0891-2321	14V Green	0891-1421	0891-2421
14V Amber	0891-1131	0891-2131	14V Amber	0891-1331	0891-2331	14V Amber	0891-1431	0891-2431
14V Clear	0891-1141	0891-2141	14V Clear	0891-1341	0891-2341	14V Clear	0891-1441	0891-2441
28V Red	0891-1112	0891-2112	28V Red	0891-1312	0891-2312	28V Red	0891-1412	0891-2412
28V Green	0891-1122	0891-2122	28V Green	0891-1322	0891-2322	28V Green	0891-1422	0891-2422

28V Amber	0891-1132	0891-2132	28V Amber	0891-1332	0891-2332	28V Amber	0891-1432	0891-2432
28V Clear	0891-1142	0891-2142	28V Clear	0891-1342	0891-2342	28V Clear	0891-1442	0891-2442
125V Red	0891-1113	0891-2113	125V Red	0891-1313	0891-2313	125V Red	0891-1413	0891-2413
125V Green	0891-1123	0891-2123	125V Green	0891-1323	0891-2323	125V Green	0891-1423	0891-2423
125V Amber	0891-1133	0891-2133	125V Amber	0891-1333	0891-2333	125V Amber	0891-1433	0891-2433
125V Clear	0891-1143	0891-2143	125V Clear	0891-1343	0891-2343	125V Clear	0891-1443	0891-2443

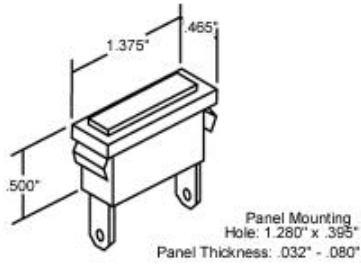


Rectangular Style

Nylon Lens (105°C), White Nylon Housing (125°C), Bright
Chrome Finish Bezel, .250" x .032"
Terminals, 14 and 28V
Incandescent, 125V Neon Lamps

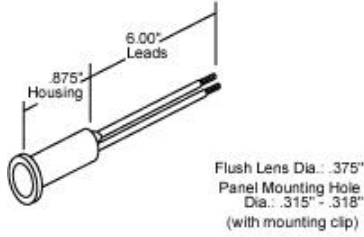

Flush Style

Nylon Lens (105°C), White Nylon Housing (125°C), 6"
20 Gauge Leads (1/2" Strip), Mounting Clip (included), 14 and 28V Incandescent, 125V Neon Lamps

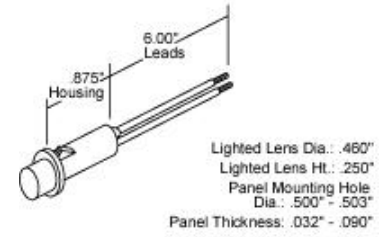

Raised Style

Nylon Lens (105°C), White Nylon Housing (125°C), 6"
20 Gauge Leads (1/2" Strip), 14 and 28V Incandescent, 125V Neon Lamps



McGILL ...The Professional's Choice

McGill Electrical Product Group
9377 W. Higgins Road
Rosemont, IL 60018
sales@mcgillelectrical.com