

# McGILL® 7000–38 Series Industrial Extension Lights

## For PAR-38 Lamps

### Applications

- These extension lights are ideal for temporary flood lighting, railroad car inspections, spot light inspecting of the internal conditions of large well pipes, and other applications requiring intense lighting.

### Features


- 7000 Series extension lights resist damage and deterioration.
- Open-end of extra-heavy, electrically welded, wire accommodates up to 200 Watt bulbs.
- Ideal for use where safety codes prohibit outlets in handles.
- Easy relamping cage.
- Internal strain relief withstands 30 lb/9.1 kg. pull test.
- All-weather cords with molded plugs.
- Long-life Levolver™ switch mechanism in handle with protective thumb guard.

### Standard Materials

- Cage: 10 gauge steel wire
- Cord: thermoplastic
- Handle: yellow, grease-resistant, high quality rubber

### Certifications and Compliances

- CSA Certified (with cord): LL89639
- CSA Certified (without cord): LL56247
- CSA Standard: C22.2 No. 12

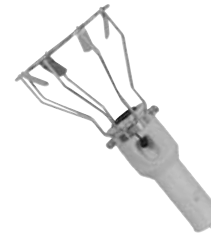

7000-SG-38

LIGHTING: MCGILL TEMPORARY

Lighting

		Catalog Number with 25'/7.6m 16/3-SJTW Cord	with 50'/15.2m 16/3-SJTW Cord
	with out Cord		
Handle and cage	7000-G-38	7025-G-38	7050-G-38
Handle and cage	C7000-G-38 <sup>1</sup>	C7025-G-38 <sup>1</sup>	C7050-G-38 <sup>1</sup>
Handle and cage with switch	7000-SG-38	7025-SG-38	7050-SG-38
Handle and cage with switch	C7000-SG-38 <sup>1</sup>	C7025-SG-38 <sup>1</sup>	C7050-SG-38 <sup>1</sup>

### Accessories and Replacement Parts

	With Out Reflector	Catalog Number With Reflector	with Trap
<b>Cages</b>			
Cage for 7000-38	1455-38	—	1455-38-T
	Catalog Number		
	With Out Switch	With Switch	
<b>Handles and Sockets</b>			
Handle for 7000, 7001, 7002		6403	6404-1
Grounding clamp		8959	8950
		25'/7.6m 16/3-SJTW	50'/15.2m 16/3-SJTW
<b>Cord Sets</b>			
Cord set with molded plugs		6229-1	6229-2

<sup>1</sup> CSA Certification only.