





 




FS and FD Two Gang Cast Device Boxes

CSA Certification Only.

UNILETS® for use with Threaded Rigid Conduit and IMC.

| | Description | Catalog Number | Wt. Lbs./Kgs. Per 100 |
|---|--|------------------|--------------------------|
| Two Gang Covers | | | |
|  | Blank Cover, Steel – Zinc Electroplate | FS-42 * | 20.00/9.07 |
|  | Round Receptacle Cover, Steel – Zinc Electroplate Hole dia. 1-7/16" | FS-52 * | 18.00/8.16 |
|  | Duplex Receptacle Cover, Steel-Zinc Electroplate | FS-62 * | 15.00/6.80 |
|  | Tumbler Switch Cover, Steel –Zinc Electroplate | FS-92 * | 20.00/9.07 |
|  | Combination Duplex Receptacle and Tumbler Switch Cover, Steel - Zinc Electroplate | FS-69 * | 15.00/6.80 |
|  | Combination Duplex Receptacle and Single Receptacle, Steel - Zinc Electroplate | FS-65 * | 15.00/6.80 |
| Weatherproof Covers | | | |
|  | Blank Cover, Gray Iron | FS-200G * | 56.00/25.40 |
|  | For external operation of tumbler switches with square handles | FSK-2VTS | 250.00/113.40 |
| Gasket – Replacement | | | |
|  | Neoprene - for use with 2-gang cast covers above | FS-GKR-2N | — |

* Available in Aluminum: Add suffix **-A** to catalog number.

✱ CSA Certification Only.

FS and FD Three Gang Cast Device Boxes

CSA Certification Only.

UNILETS® for use with Threaded Rigid Conduit and IMC. All device boxes have ridge top construction.

| Size | Gray Iron | | Aluminum | |
|------|----------------|---------------|----------------|---------------|
| | Catalog Number | Wt. Lbs./Kgs. | Catalog Number | Wt. Lbs./Kgs. |

FS Three Gang Bodies



| | | | | | | |
|-----|---------|---------------|-----------|---------|----------------|-----------|
| 3/4 | Shallow | FSC-23 | 3.60/1.63 | Shallow | FSC-23A | 1.20/0.54 |
| 1 | Deep | FDC-33 | 4.00/1.81 | Deep | FDC-33A | 1.33/0.60 |

| Description | Catalog Number | Wt. Lbs./Kgs. Per 100 |
|-------------|----------------|-----------------------|
|-------------|----------------|-----------------------|

Three Gang Covers



Duplex Receptacle Cover, Steel – Zinc Electroplate **FS-63 *** 23.00/10.43



Tumbler Switch, Steel –Zinc Electroplate **FS-93 *** 25.00/11.34

Weatherproof Covers




Blank Cover, Gray Iron **FS-300G *** 120.00/54.43



For external operation of tumbler or toggle switches with square handles **FSK-3VTS** 330.00/149.69

Dimensions in Inches/Millimeters

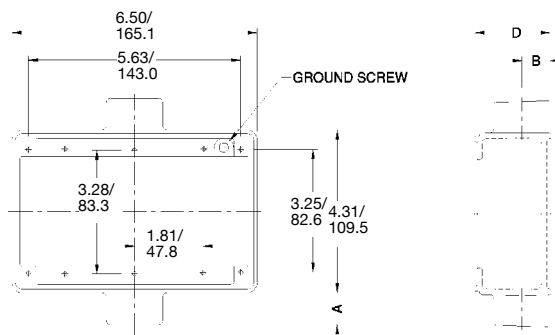

Three Gang Devices

| Hub Size | D | | | | | |
|----------|---------------|---------------|---------------|---------------|---------------|---------------|
| | A | B | C | FS | FD | E |
| 1/2 | 0.75/ 19.1 | 0.63/ 16.0 | 1.38/ 35.1 | 2.00/ 50.8 | 2.75/ 69.9 | 2.19/ 55.6 |
| 1 | 0.88/ 22.4 | 0.88/ 22.4 | 1.25/ 31.8 | 2.00/ 50.8 | 2.75/ 69.9 | 2.19/ 55.6 |

* Available in Aluminum: Add suffix -A to catalog number.

☞ CSA Certification Only.