

# CPU Universal Conduit Outlet Boxes and Covers

CSA Certification Only. Explosionproof, Dust-Ignitionproof

UNILETS® for use with Threaded Metal Conduit.

Class I, Division 1 and 2, Groups C, D  
Class I, Zone 1 and 2, IIB T6  
Class II, Division 1 and 2, Groups E, F, G  
Class III, Enclosure 3

## Applications

- Complies with a wide range of classified area requirements.
- Corrosion-resistant: ideal indoors or out.
- For pulling of wires.
- Connect conduit lengths and change direction of conduit runs.
- Provide access for maintenance.

## Features

- Malleable iron bodies have high tensile strength and ductility. Provides great resistance to corrosion, impact, and shock.
- Accurately tapped, tapered hub threads for tight, rigid joints and ground continuity.
- Furnished with covers.
- General purpose wiring.
- Universal design with four threaded universal hubs and three close-up plugs.
- Serve as mounting outlets for lighting fixtures when used with hub cover.
- Wide, accurately ground explosion-proof mating surfaces.
- Smooth, rounded integral bushing in each hub type box protects conductor insulation.

## Standard Materials

- Bodies and covers : malleable iron or copperfree (4/10 of 1% max.) aluminum
- Connection block: phenolic

## Standard Finishes

- Bodies and covers: triple-coat — (1) zinc electroplate, (2) chromate, and (3) epoxy powder coat

## Options

- To order with CB205 connection block installed add suffix **-CB**.

## Certifications and Compliances

- CSA Standard: C22.2 No. 25, C22.2 No. 30
- CSA Certified: 013017

Box Type	Conduit Size (Inches)	Fixture Stem Size Inches	Cover Opening Inches/ Millimeters	Capacity in <sup>3</sup> /dm <sup>3</sup>	Catalog Number	
					Malleable Iron	Aluminum

### CPU Box with Blank Cover

Furnished with four threaded universal 3/4" hubs, four 3/4" to 1/2" reducers, and three 1/2" close-up plugs. To order with CB205 connection block installed add suffix **-CB**.



1/2 or 3/4	Blank	3.81/96.8	21.0/0.34	<b>CPU20CN</b>	<b>CPU20ACN</b>
------------	-------	-----------	-----------	----------------	-----------------

### CPU Box with Hub Cover

(Supports lbs – 112.5 kg. Furnished with four threaded universal 3/4" hubs, four 3/4" to 1/2" reducers, and three 1/2" close-up plugs. To order with CB205 connection block installed add suffix **-CB**.



1/2 or 3/4	1/2	3.81/96.8	21.0/0.34	<b>CPU20-50CN</b>	<b>CPU20-50ACN</b>
1/2 or 3/4	3/4	3.81/96.8	21.0/0.34	<b>CPU20-75CN</b>	<b>CPU20-75ACN</b>

### CPU Covers only

Furnished with fastening screws.



Cover	Blank	3.81/96.8	21.0/0.34	<b>CPSK20BCN</b>	<b>CPSK20B-ACN</b>
-------	-------	-----------	-----------	------------------	--------------------



Hub Covers	1/2	3.81/96.8	21.0/0.34	<b>CPSK20-50CN</b>	<b>CPSK20-50ACN</b>
	3/4	3.81/96.8	21.0/0.34	<b>CPSK20-75CN</b>	<b>CPSK20-75ACN</b>

### CPU Connection Block — With fastening strap and two mounting screws





5-Wire, 20 Amp, 300 Volt

**CB205CN**

## Dimensions

### CPU Box with Cover

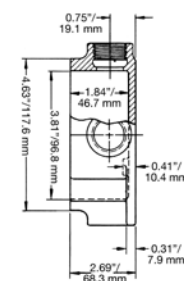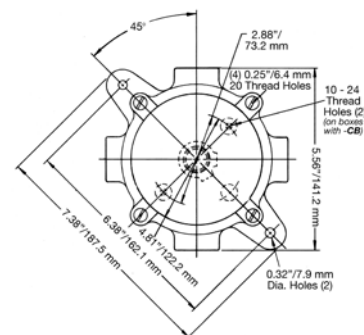

 CSA Certification Only.