



**PROFESSIONAL
OUTDOOR LIGHTING**

Type:

Model:

Project:

SPECIFICATION SHEET

MODEL 4242 Landscape Series • Step & Brick Lights

FIXTURE SPECIFICATIONS:

HOUSING:

Copper free, stamped & formed aluminum recessed box with 1/2" knockouts on the back & side.

COVER PLATE:

Die-cast, copper-free, aluminum fitted to the recessed box with UV-resistant weather stripping– providing a superior weather-tight seal.

FINISH:

Polyester powder-coated finish available in Black, Architectural Brick, Architectural Bronze, Light Bronze, Dark Bronze, Granite, Terracotta, Rust, Hunter Green, Weathered Bronze, Weathered Iron, White, Verde, Pewter, and Mocha.

SOCKET/LAMP HOLDER:

Top grade ceramic socket with nickel contacts, stainless steel springs, & Teflon-jacketed wire leads.

LENS:

Clear, high-impact, polycarbonate lens.

LAMP TYPE:

T3 – 20W maximum. LN-10 T3 Halogen (10W) Standard.

MOUNTING:

Recessed mounting box included.

FASTENERS:

All fasteners are stainless steel.

WIRING:

Provided with a three-foot pigtail of 18-2 SPT1 UV resistant cable & underground connectors for a secure connection to the supply cable.


CERTIFICATION:

UL Listed to U.S. & Canadian safety standards for low voltage landscape luminaires (UL 1838). The maximum wattages allowed by Underwriters Laboratories (UL) for the U.S. & Canadian markets may vary. Maximum wattages specified are Underwriters Laboratories U.S. standard. Please contact Vista for any questions about the maximum wattages allowed by UL Canadian standards.

All Vista luminaires are MADE IN THE U.S.A.

This fixture is also available as a LED luminaire. Please refer to LED Specification Sheet - 4242-LED.

DIMENSIONS:

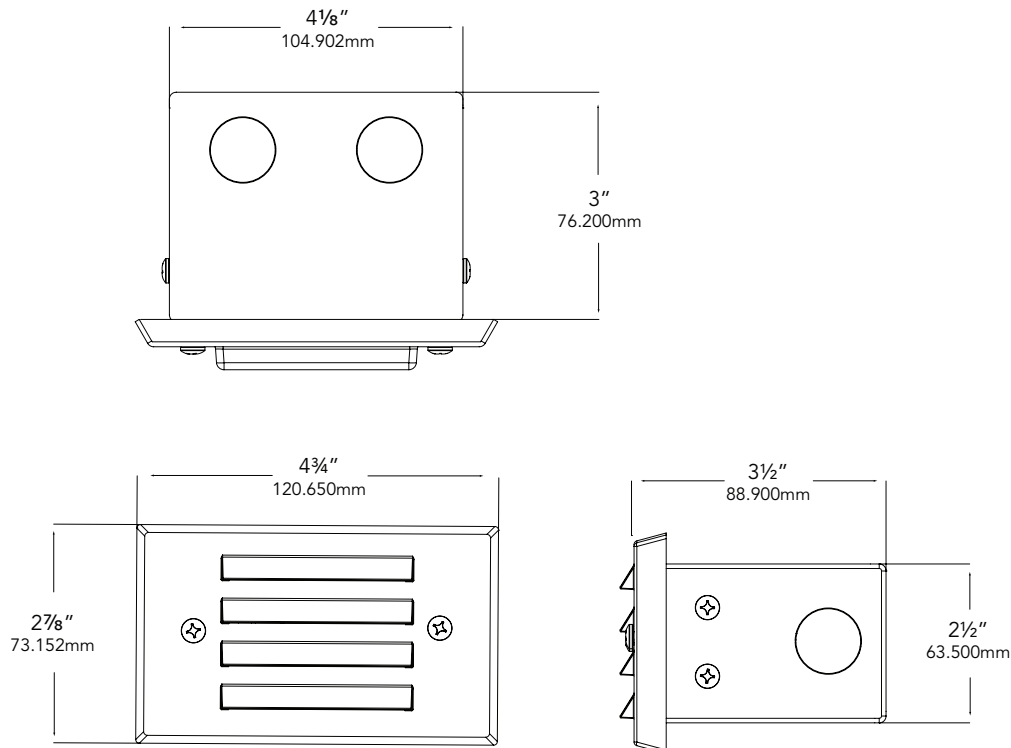

Vista Professional Outdoor Lighting reserves the right to modify the design and/or construction of the fixture shown without further notification.



SPECIFICATION SHEET

MODEL 4242 Landscape Series • Step & Brick Lights

FIXTURE ORDERING INFORMATION

TO ORDER FIXTURE: Select appropriate choice from each column as in the following example.

EXAMPLE: SL-4242-B-10T3

MOUNTING	MODEL	FINISH	LAMP
SL - Step Light	4242	B - Black BR - Architectural Brick Z - Architectural Bronze LZ - Light Bronze DZ - Dark Bronze GT - Granite TC - Terracotta R - Rust HG - Hunter Green WB - Weathered Bronze WI - Weathered Iron W - White G - Verde P - Pewter M - Mocha	10T3 - 10 watt T3 Halogen 20W Maximum LN-10 T3 Halogen (10W) Standard <i>(Please see lamp order code column on lamp guide, Vista product catalog.)</i>

Fixtures shipped with standard lamp, unless otherwise specified.
Fixtures shipped with specified mounting hardware.

Vista Professional Outdoor Lighting reserves the right to modify the design and/or construction of the fixture shown without further notification.