 



Data and specifications subject to change without notice

Project name	Type
Order number	
Date	

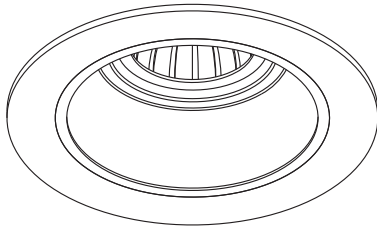


# AURORA

## MR16 TRIM

### SPECIFICATIONS

The Aurora trim offers performance, versatility, and excellent glare control in a multitude of reflector finishes.

NOTE: Trim & Housing combination are designed for typical 5/8" drywall application, contact factory for various ceiling thickness.

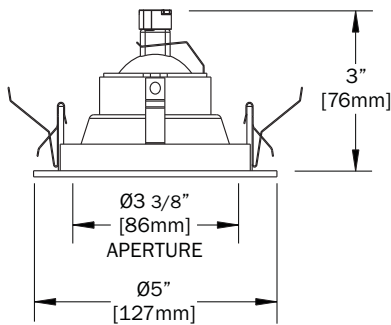

- ◆ Made of die-cast aluminum
- ◆ Powder coated or plated trim ring finishes
- ◆ Adjustable up to 35°
- ◆ Reflector options include baffles, satin and specular finishes, and powder coated smooth and step baffles
- ◆ Lamp holder accepts up to 2 lens accessories
- ◆ Designed for non-cover glass MR16 lamp
- ◆ Clear glass lens included
- ◆ 50W or 75W maximum rating depending on the housing
- ◆ See Slice decorative accessories specification sheet for more details
- ◆ See metal halide trim spec sheets for MH options

Applications: Aurora trim can be used for lobbies, conference rooms, corridors, hotels, restaurants, retail spaces, music halls, offices, and residential applications.

### ORDER GUIDE

HOUSING	VOLTAGE	TRIM	FINISH	REFLECTOR COLOR	FINISH
No Housing (Max 20W) <sup>1</sup>	120	2-120 Aurora	01 - White	SA - Silver Specular <sup>2</sup>	S - Satin
2-010-I/C (Max 50W)	277		02 - Chrome	GA - Gold Specular <sup>2</sup>	
2-010-I/C-A/T (Max 50W)	347 <sup>4</sup>		04 - Black	BA - Black Specular	
2-010-I/C-TOR (Max 50W)			05 - Matte Silver	COPA - Copper Specular <sup>2</sup>	
2-010-I/C-A/T-TOR (Max 50W)			06 - Bronze	BLUA - Blue Specular <sup>2</sup>	
2-012-I/C-TOR (Max 50W)			09 - Gold	GRNA - Green Specular <sup>2</sup>	
2-012-I/C-A/T-TOR (Max 50W)			11 - Matte Nickel	PURA - Purple Specular <sup>2</sup>	
2-020-F (Max 50W)				CHA - Champagne Specular <sup>2</sup>	
2-020-F-D/A (Max 50W)				WHS - White Stepped Baffle	
2-030-R (Max 50W)				BLS - Black Stepped Baffle	
2-030-R-TOR (Max 50W) <sup>4</sup>				NIC-S - Nickel Satin <sup>3</sup>	
2-060-F (Max 75W)				WHO - White Open Reflector	
2-060-F-D/A (Max 75W)				BLO - Black Open Reflector	
2-060-F-D/A-TOR (Max 75W)				MOCH - Brushed Mocha	
2-060-F-C/P (Max 75W)					
2-100-C/H (Max 75W)					

Note:

- 1) "No Housing" indicates use with a remote Class 2 transformer
- 2) Also available in satin finishes
- 3) Only available in satin finishes
- 4) Consult factory for availability

\*Spec sheets are subject to change without notice