




SLC-002S/SLC-002S-NL

DESCRIPTION

Low profile linear LED channel, anodized aluminum finish. Opal polycarbonate lens, grey end caps with mounting clips. (NOTE: NL version comes with no lens or end clips.)

LENGTH Max. 8 Feet (2.44 Meters)

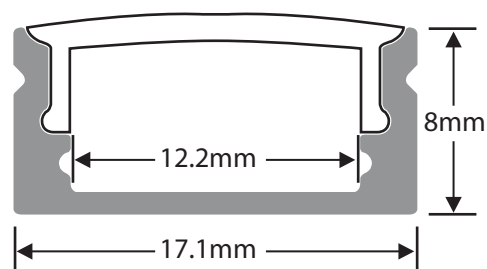

Technical specifications:

Dimension: 17.1mm x 8mm

Aluminum Channel: Anodized aluminum extrusion

Lens: Polycarbonate, high heat resistant, UV stable, shatter resistant

Length: 8 feet (2.44 meters)