


DIFFUSION lighting

SLC-007S

DESCRIPTION

45deg linear LED channel, anodized aluminum finish. Opal polycarbonate lens, grey end caps with mounting clips.

LENGTH Max. 8 Feet (2.44 Meters)

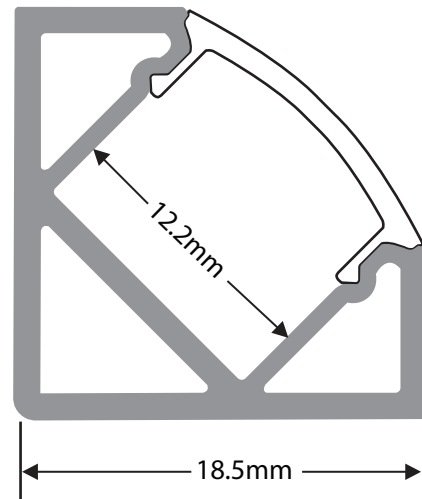

Technical specifications:

Dimension: 18.5mm x 18.5mm

Aluminum Channel: Anodized aluminum extrusion

Lens: Polycarbonate, high heat resistant, UV stable, shatter resistant

Length: 8 feet (2.44 meters)