


239
Series

papco® HAND RIVETERS RIVETEUSE MANUELLE


1.	2.	3.	4.	5.	6.
Drill a hole of the recommended size in each of the parts to be riveted and select correct nose-piece.	Fully open handles. Insert rivet until head touches nose-piece.	Insert rivet in the hole.	For soft materials or oversize holes use back-up plates to eliminate rivet pull-through.	Squeeze handles together. If mandrel does not break, open handles, push rivet head back to nose-piece and repeat until mandrel breaks.	Hold riveter with nose-piece up. Fully open handles and snapped off stem will fall out.

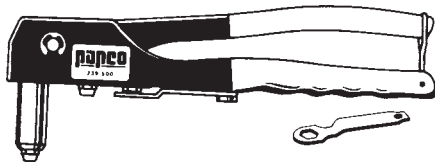

No. 239-500 MEDIUM DUTY BLIND RIVETER

An economical tool for medium duty. Vinyl grips on stamped long handles for extra leverage with milled steel nose. Sets 3/32", 1/8", 5/32" and 3/16" dia. aluminum rivets.

Individually packaged.

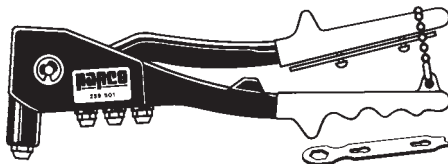

No. 239-501 PROFESSIONAL SERVICE BLIND RIVETER

Sturdy, fast acting tool. Will set 3/32", 1/8", 5/32" and 3/16" dia. rivets. Capacity 3/16" aluminum. Moulded contour hand grips and long forged handles for extra leverage. Complete with four nose-pieces.

Heavy Duty

Individually packaged.



No. 400-002 CERAMIC BLOCK MAGNETS

'Papco' High Strength Ceramic Block Magnets are ideal for temporary attachment of metal panels, work orders or masking material without damaging painted areas or other metal surfaces. Each skin-packed card contains two block magnets. Each magnet is 7/8" wide x 1-7/8" long x 3/8" thick. For other Magnet products see page 148.



 
BLIND RIVET MASTER ASSORTMENT No. 020-667

Contains 1200 pieces - 10 popular sizes of Aluminum and Steel Domed Head Rivets and 3 sizes of Back-up Plates. Packed in a sturdy metal container with handy moulded compartments and an actual size illustrated grease-resistant lid label.

Size: 9-3/4" w. x 13-3/4" l. x 2" d.

239
Series

papco® MULTI-GRIP BLIND RIVETS RIVETS OBTURATEURS MULTI-GRIP



Excellent where a combination of hard and soft materials needs fastening. Compensates for hole size and alignment variations. Aluminum body and steel mandrel. Domed head. Order by Stock Number.

These blind rivets cover the grip range of three standard rivets.



Standard Package 100 rivets.

Stock No.	Other No.	Rivet Dia.	Grip Range	Rivet Length
239-314	AD41-43	1/8 (.125)	.031-.185	.315
239-320	AD43-45	1/8 (.125)	.157-.335	.480
239-335	AD52-54	5/32 (.156)	.047-.248	.425
239-353	AD62-64	3/16 (.187)	.063-.252	.414

papco® BACK-UP PLATES



239-493
239-494
239-492

Back-up plates for 1/8" dia. Rivets (9/64 x 3/8 x 1/32) Plated Steel, 100 per box.
Back-up plates for 3/16" dia. Rivets (13/64 x 1/2 x 3/64) Plated Steel, 100 per box.
Back-up plates for 3/16" dia. Rivets (13/64 x 1/2 x 3/64) Aluminum, 100 per box.

Please Note: The parts on this page are outdated. Some have been discontinued and new ones have been added. Please refer to our current Body Shop Fastener catalogue.