


 







# AT 0 Compact Oiltight Limit Switches Operating Heads


NEMA 4, 13 / IEC IP 65 / CE

	Style	Direction of actuation	Type Article No.	Price see price list
<b>Operating heads</b>				
	with roller plunger	Form C to EN 50 047	lateral	<b>RS-ATO</b> 053145
	with roller plunger	single hole mounting	lateral	<b>ZRS-ATO</b> 031083
	with roller plunger	single hole mounting	axial, lateral	<b>ZS-ATO</b> 033456
	with spring-rod actuator	–	lateral	<b>F-ATO</b> 050772
	with roller lever	Form E to EN 50 047	lateral	<b>AR-ATO</b> 046026
	with angled roller lever	–	lateral	<b>WR-ATO</b> 048399
	with side roller lever	Form A to EN 50 047	lateral	<b>R-ATO</b> 038907
	with adjustable roller lever	–	lateral	<b>V-ATO</b> 041280
	with actuating rod	–	lateral	<b>H-ATO</b> 043653

**Notes**

The operating heads can be turned in 90 ° stages to match the specified direction of operation.

For IP 65 degree of protection, use cable gland M20 with a maximum connection thread length of 9.5mm (V-M20).

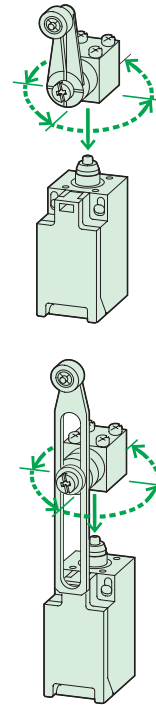

Not to be used as a safety limit switch:

- F-ATO
- H-ATO

**F-ATO** can be used only in conjunction with snap-action contacts.

Accessories	Page
Cable glands	06/020