

Tunnel terminal 3p 2x240mm² w. cover

Part no. NZM3-XKA2

Article no. 271461

Delivery programme

Accessories			Tunnel terminal
Number of conductors			3 pole
Rated current	I_n	A	630
For use with			NZM3(-4), PN3(-4), N(S)3(-4)
Terminal capacities			
Type of conductor			
Cu/Al cable			Copper cable Al cable
Terminal capacities			
flexible		mm ²	1 x 50 - 240 2 x 50 - 240
AWG/kcmil			
flexible		mm ²	1 x 0 - 500 2 x 0 - 500

Notes

Type contains parts for a terminal located at top or bottom for 3 or 4-pole circuit-breakers.

A standard with control circuit terminal for 1 x 0.75 - 2.5 mm² (18 - 14 AWG) or 2 x 0.75 - 1.5 mm² (18 - 16 AWG) copper conductors.

Fitted outside the switch housing

Use with flexible and highly flexible conductors ferrules. Maximum specified cross-section can only be connected when stranded and without ferrules.

Mounting of the cover NZM3(-4)-XKSA obligatory (supplied).

Approvals


Product Standards
UL File No.
UL CCN
CSA File No.
CSA Class No.
NA Certification
Suitable for

UL489; CSA-C22.2 No. 5-09; IEC60947, CE marking
E31593
DIHS
022086
1432-01
UL listed, CSA certified
Refer to main component information

Technical data ETIM 4.0

Suitable for number of poles			3
Type			-

Dimensions

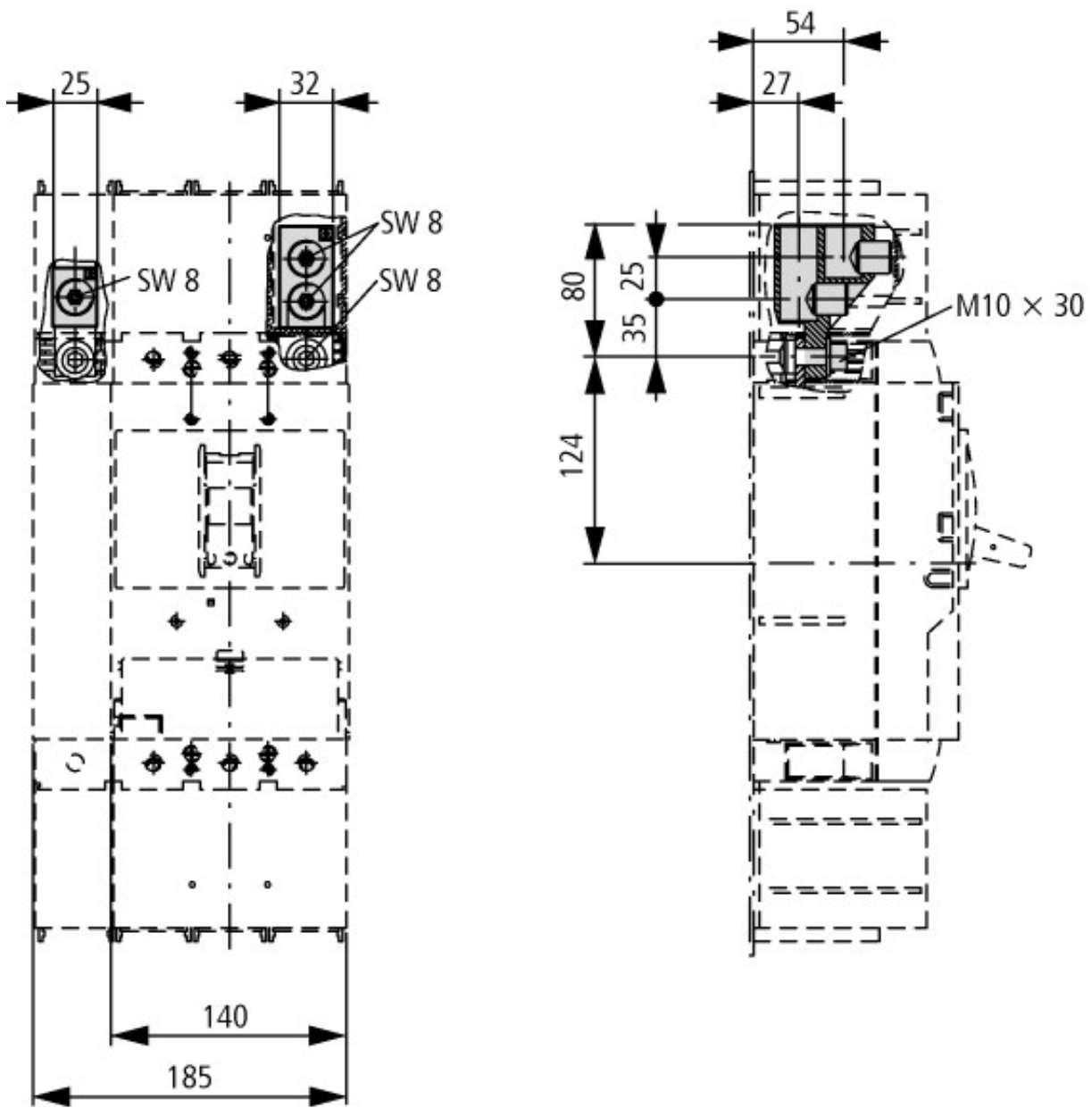

Additional product information (links)

IL01210007Z (AWA1230-2050) Tunnel terminal

IL01210007Z (AWA1230-2050) Tunnel terminal

ftp://ftp.moeller.net/DOCUMENTATION/AWA_INSTRUCTIONS/IL01210007Z2012_02.pdf