
 

 

 

 
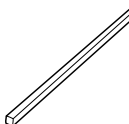


# 52 Circuit-breakers, disconnect switches

## Rotary handles with door interlock for UL/CSA approved NA switches

Moeller SK1230-1157EN-NA

Circuit-breakers, disconnect switches  
up to 1200 A

		For use with	Standard Part no. Article no. when ordered separately	Price see price list	Std. pack	Notes
<b>Door coupling rotary handle</b>						
Complete including rotary drive and coupling parts Extension shaft additionally required. Degree of protection IP66/UL/CSA Type 4X						
Standard, black/grey						
   	Lockable on handle and switch. Can be locked in 0 position, with adequate modification also in I position. With door interlock Lockable in 0 position on breaker.	NZM1, N1	NZM1-XTVDV-NA 100683	1 off	Door interlock <ul style="list-style-type: none"><li>• Not defeated in the locked OFF position</li><li>• Door opening possible with active rotation beyond the 0 position.</li><li>• Cannot be combined with mechanical interlock</li><li>• External warning plate/ designation label can be clipped on</li></ul>	
		NZM2, N2	NZM2-XTVDV-NA 100684			
		NZM3, N3	NZM3-XTVDV-NA 100685			
		NZM4, N4	NZM4-XTVDV-NA 100686			
Red-yellow for Emergency-Stop						
   	Lockable on handle and switch. Lockable in 0 position on handle. With door interlock Lockable in 0 position on breaker.	NZM1, N1	NZM1-XTVDVR-NA 271449	1 off	Door interlock <ul style="list-style-type: none"><li>• Not defeated in the locked OFF position</li><li>• Door opening possible with active rotation beyond the 0 position.</li><li>• Cannot be combined with mechanical interlock</li><li>• External warning plate/ designation label can be clipped on</li></ul>	
		NZM2, N2	NZM2-XTVDVR-NA 271450			
		NZM3, N3	NZM3-XTVDVR-NA 271451			
		NZM4, N4	NZM4-XTVDVR-NA 271452			
<b>Extension shaft</b>						
	Max. mounting depth: 400 mm	NZM1, N1 NZM2, N2	NZM1/2-XV4 261232	1 off	Can be cut to required length	
		NZM3, N3 NZM4, N4	NZM3/4-XV4 261234			
	Max. mounting depth: 600 mm	NZM1, N1 NZM2, PN2, N2	NZM1/2-XV6 260191			
		NZM3, N3 NZM4, N4	NZM3/4-XV6 260193			

### Notes

Circuit-breaker can also be installed in a lying position 90° left/right, with the handle still in the same position.