

# LED Accent Lights

Project Name:	Prepared By:
Project Number:	Date:
Catalog Number:	Type:

## ARROWHART® Commercial Specification Grade LED Accent Lights

120 V/AC  
60 Hz



LNL1 Series



LNL2 Series



LNL3 Series



LNL4 Series

### LED Accent Lights

#### FEATURES

- Fits into a standard junction box with 1-gang plaster ring for easy installation.
- Operates on standard 120V power supply.
- Offers up to 30 lumens of illumination.
- Integrated, illuminated push-button switch standard on LNL2 model.
- Energy-efficient LED light source in white, amber or red colors.
- Unique faceplate design distributes light evenly.
- Choose from louvered or scooped die cast aluminum faceplate design.
- White faceplate standard, black and brushed nickel options available.
- Wet location and low voltage models also available.
- Ideal for hotel rooms and lobbies, lecture halls, auditoriums, theaters, pathfinding, outdoor patios and decks, patient rooms, nurses' stations and exam rooms in healthcare environments.
- Polycarbonate lens protects electronics tampering.

Ordering Example: LNL4WA120 (white faceplate and amber LED).

#### LED Nightlights with Vertical Louvered Faceplate



W	V/AC	Description	Cat. No.	Faceplate	LED Colors
4	120	Standard	<input type="checkbox"/> LNL1__120	W, B, BN	A, R, W
		Wet Location	<input type="checkbox"/> LNL1__120-WL	W, B, BN	A, R, W
	12-24	Low Voltage	<input type="checkbox"/> LNL1_LV	W, B, BN	A, R, W
		Low Voltage, Wet Location	<input type="checkbox"/> LNL1_LV-WL	W, B, BN	A, R, W

#### LED Chart Lights with Push Button Switch & Vertical Scoop Faceplate

W	V/AC	Description	Cat. No.	Faceplate	LED Colors
3	120	Standard	<input type="checkbox"/> LNL2__120	W	W
		Wet Location	<input type="checkbox"/> LNL2__120-WL	W	W
	12-24	Low Voltage	<input type="checkbox"/> LNL2_LV	W	W
		Low Voltage, Wet Location	<input type="checkbox"/> LNL2_LV-WL	W	W

#### LED Nightlights with Vertical Scoop Faceplate

W	V/AC	Description	Cat. No.	Faceplate	LED Colors
3	120	Standard	<input type="checkbox"/> LNL3__120	W, B, BN	A, R, W
		Wet Location	<input type="checkbox"/> LNL3__120-WL	W, B, BN	A, R, W
	12-24	Low Voltage	<input type="checkbox"/> LNL3_LV	W, B, BN	A, R, W
		Low Voltage, Wet Location	<input type="checkbox"/> LNL3_LV-WL	W, B, BN	A, R, W

#### LED Nightlights with Horizontal Louvered Faceplate

W	V/AC	Description	Cat. No.	Faceplate	LED Colors
4	120	Standard	<input type="checkbox"/> LNL4__120	W, B, BN	A, R, W
		Wet Location	<input type="checkbox"/> LNL4__120-WL	W, B, BN	A, R, W
	12-24	Low Voltage	<input type="checkbox"/> LNL4_LV	W, B, BN	A, R, W
		Low Voltage, Wet Location	<input type="checkbox"/> LNL4_LV-WL	W, B, BN	A, R, W

For ordering, include Cat. No. followed by the color code. Faceplates: W (White), B (Black), BN (Brushed Nickel); LED color: A (Amber), R (Red) W (White).

#### TESTING & CODE COMPLIANCE

- Listed to UL1598, CSA Certified.
- ADA compliant.

#### MATERIAL CHARACTERISTICS

- Faceplate: Aluminum
- Back body: ABS plastic
- Strap: Aluminum
- Wire: 18 AWG, 600V, 105°C (221°F)
- Temperature: Rated to 25°C (77°F)

# LED Accent Lights Specification & Performance Data

Project Name:	Prepared By:
Project Number:	Date:
Catalog Number:	Type:

## ARROWHART® Commercial Specification Grade LED Accent Lights


120 V/AC  
60 Hz

### Applications


Hotel rooms and lobbies, lecture halls, auditoriums, theaters, pathfinding, outdoor patios and decks, outdoor paths, patient rooms, nurses' stations, exam rooms in healthcare environments, or anywhere else lighting is needed in low illumination for safe pathway finding or specific task lighting.

Series Type	Louvered Faceplate LNL1, LNL4 Series	Scoop Faceplate LNL2, LNL3 Series
<b>Illumination</b>	12 LEDs providing 15 Lumens LED life rated 30,000 hours	6 LEDs providing 30 Lumens LED life rated 20,000 hours
<b>Power Consumption</b>	>4 Watts	>3 Watts
<b>Housing</b>	Die cast aluminum	Die cast aluminum
<b>Testing &amp; Code Compliance</b>	<ul style="list-style-type: none"> <li>Listed to UL 1598</li> <li>CSA certified</li> </ul>	<ul style="list-style-type: none"> <li>Listed to UL 1598</li> <li>CSA certified</li> </ul>
<b>Power Supply</b>	120 V/AC	120 V/AC
<b>Installation</b>	Single-gang junction box	Single-gang junction box
<b>Materials:</b>		
Faceplate	Aluminum	Aluminum
Back body	ABS Plastic	ABS Plastic
Strap	Aluminum	Aluminum
Wire	18 AWG, 600V, 105°C	18 AWG, 600V, 105°C
<b>Temperature Rating</b>	25°C (77°F)	25°C (77°F)
<b>Flammability Rating</b>	UL 945-5V	UL 945-5V


#### LNL1 Series

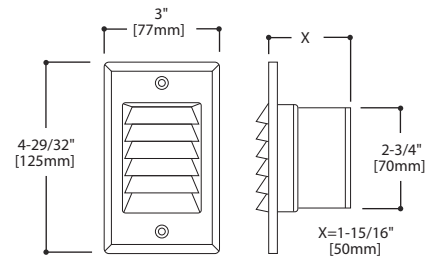


#### LNL2 Series

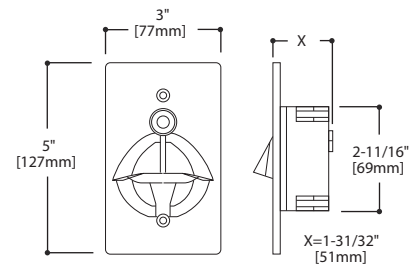


#### LNL3 Series

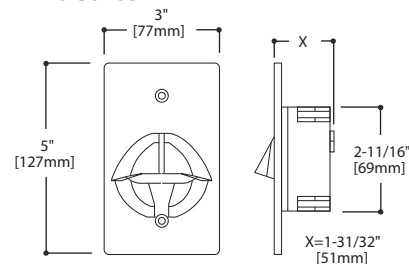

#### LNL4 Series

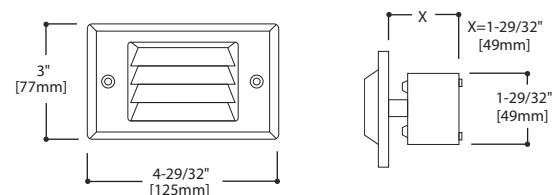

#### Photometrics

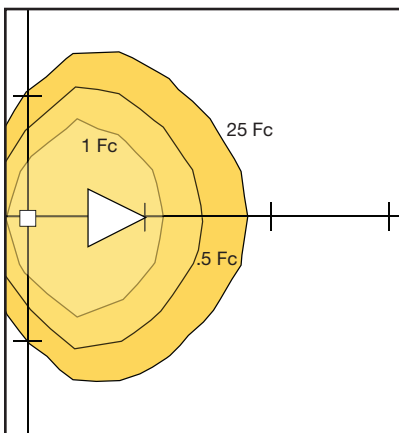

#### LNL2WW120

Scale: 1" = 2 ft.

Mounting Height = 18"