


**Commercial Grade
Straight Blade
Receptacles**

2-Pole, 3-Wire Grounding
Dual Voltage
15A, 125/250V/AC
NEMA 5-15R, 6-15R

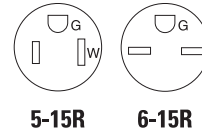


Dual Voltage Commercial Grade Receptacle

Rating		NEMA	Description	Color	Catalog No.	
A	V/AC					
15	125/ 250	5-15R/ 6-15R	Dual Voltage Duplex Receptacle, Side Wire	V	□ 829V	

**Commercial Grade
Straight Blade
Receptacles**

2-Pole, 3-Wire Grounding
15A, 250V/AC
20A, 250V/AC
NEMA 6-15R, 6-20R

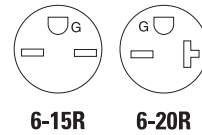





Commercial Grade Receptacles

Rating		NEMA	Description	Color Suffix	Catalog No.	
A	V/AC					
15	250	6-15R	Duplex Receptacle, Side Wire	B, V, W	□ 826_Δ	
			Single Receptacle, Side Wire	B, V, W	□ 816_	
20	250	6-20R	Duplex Receptacle, Side Wire	B, V, W	□ 815_Δ	
			Single Receptacle, Side Wire	A, B, BK, LA, V, W	□ 1876_	

Δ cULus & Fed Spec certified

Decorator Commercial Grade Receptacle

Rating		NEMA	Description	Color	Catalog No.	
A	V/AC					
20	250	6-20R	Single Receptacle, Side Wire	W	□ 6450W	• •

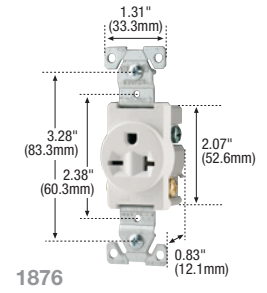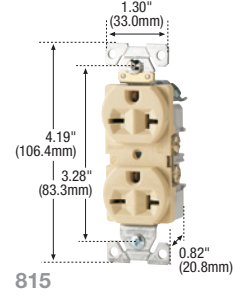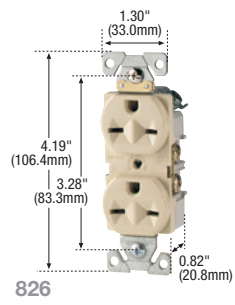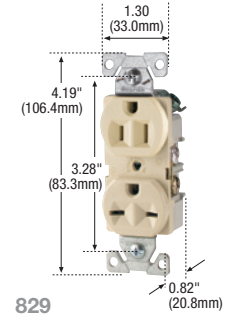

Color Ordering Information:

For ordering devices, include Catalog No. followed by the Color Suffix: A (Almond), B (Brown), BK (Black), LA (Light Almond), V (Ivory), W (White)



Specification Information: Commercial Receptacles: A-38
Specifications and availability are subject to change without notice.