
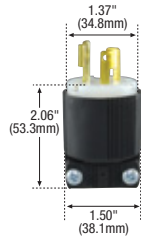


Industrial grade 15A locking devices

Product description


2-pole, 3-wire grounding
15A, 250V/AC
NEMA L6-15

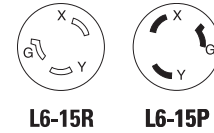

CWL615P



CWL615C

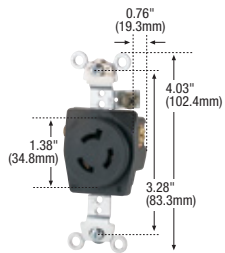

CWL615R



CWL615FI

Industrial grade plugs & connectors



Rating	A	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
15	250	L6-15	Safety grip straight body	0.33-0.66" (8.4-16.7mm)	BK & W	<input type="checkbox"/> CWL615P	<input type="checkbox"/> CWL615C			
			Auto grip straight body	0.33-0.66" (8.4-16.7mm)	BK & W	<input type="checkbox"/> 6565N	<input type="checkbox"/> 6566N			

Industrial grade receptacles



Rating	A	V/AC	NEMA	Description	Color	Single receptacle	Duplex receptacle			
15	250	L6-15	Standard industrial		BK	<input type="checkbox"/> CWL615R	—			
			Standard industrial		BK	—	<input type="checkbox"/> 6580			
			Isolated ground		RN	<input type="checkbox"/> IGL615R*	—			

*Not Fed Spec

Industrial grade flanged inlets & outlets



Rating	A	V/AC	NEMA	Description	Color	Flanged inlet	Flanged outlet			
15	250	L6-15	Standard industrial		BK	<input type="checkbox"/> CWL615FI	—			
			Standard industrial		BK & W	—	<input type="checkbox"/> CWL615FO**			

**Only UL Listed & CSA certified, *Not Fed Spec

Dimensional information:

C-76-C-78

Plug & connector specification information:

L6-15: C-84

Receptacle specification information:

L6-15: C-86

 
Isolated ground L6-15: C-86

Flanged inlet & flanged outlet specification information:

L6-15: C-88

Color information:

BK (Black), RN (Orange), W (White)



Compliances, specifications and availability are subject to change without notice.

Indicates NAFTA compliant - Page Q-32

RoHS compliant - Page Q-32