

Decorator dimmers

Product description

Single-pole & 3-way
300W, 600W/VA, 1000W/VA, or 8A; 120V/AC or 277V/AC
Incandescent/halogen, magnetic low-voltage, electronic low-voltage, fluorescent, compact fluorescent, LED

Design features

- Preset feature allows user to return to previous light setting when turning lights on
- Integrated linear slide control for easy, precise operation
- All units are available in combined single-pole/3-way versions
- Device can be wired into either 3-way location (load side or line side)
- Neutral is not required for installation of device
- Replaces a standard switch and offers dimmer capabilities
- Square Law Dimming—perceived dimming level is proportional to the slider position
- Power failure memory
- Electrostatic discharge protection
- Precise color matching
- Compatible with any decorator wallplate



DF8AP



DF10P

Dimmers, back & side wire

Rating		Compatible lamp types	Description	Color suffix	Catalog no.
W/AC	V/AC				
1000	120	INC, HAL, MLV	Incandescent/halogen/magnetic low-voltage dimmer, single-pole/3-way with preset	A, B, BK, GY, LA, V, W	<input type="checkbox"/> DI10P-__

cULus Listed to UL1472, file no. E47967; NOM certified

Fluorescent dimmers, back & side wire

Rating		Description	Color suffix	Catalog no.
A	V/AC			
8	120	Fluorescent dimmer; single-pole/3-way with preset; Mark 10 [®] , AmbiStar [®] & Tu-Wire [®] compatible	A, B, BK, GY, LA, V, W	<input type="checkbox"/> DF8AP-__
8	277	Fluorescent dimmer, single-pole/3-way with preset, Mark 10 [®] compatible	A, B, BK, GY, LA, V, W	<input type="checkbox"/> DF8AP7-__

cULus Listed to UL1472, file no. E47967; NOM certified


0-10V Dimmer, back & side wire

Rating		Compatible lamp types	Description	Color suffix	Catalog no.
Watt	V/AC				
1200	120	Dimmable LED/FLR 0-10V ballasts	Decorator dimmer, single-pole/3-way, preset	C1, C2, C4, C5	<input type="checkbox"/> DF10P-__
1600	277				
—	—	—	Color change faceplate for DF10P	A, BK, GY, LA, V, W	<input type="checkbox"/> DCK1-__

cULus Listed to UL1472, file no. E47967; NOM certified

Color ordering information:

For ordering devices, include Catalog no. followed by the Color suffix: A (Almond), B (Brown), BK (Black), GY (Gray), LA (Light Almond), V (Ivory), W (White), C1 (Color Change Kit: A, W, V), C2 (Color Change Kit: LA, W, V), C4 (Color Change Kit: BK, W, V), C5 (Color Change Kit: BK, W, GY).

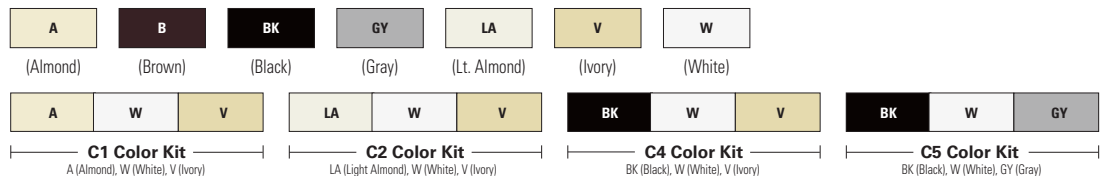

Derating Information: F-19 **Dimensional Information:** A-46 **Specification Information:** Please visit www.cooperwiringdevices.com
Mark 10[®] and AmbiStar[®] are registered trademarks of Philips Advance; Tu-Wire[®] is a registered trademark of Lutron.
Compliances, specifications and availability are subject to change without notice.