

Weatherproof while-in-use covers



Extra duty while-in-use weather protective cover

Product description

- 1-gang extra duty, self-closing
- 2-gang extra duty, self-closing

Features


- Meets 2014 NEC® 406.9 (B)(1) extra duty requirements for any application
- Rugged UV-resistant polycarbonate cover and back protects devices without cracking or breaking and is non-corrosive and non-conductive
- Self-closing cover
- Box inserts accommodate decorator devices, duplex receptacles and a variety of single receptacle sizes and toggle switches
- 1-gang box includes 3 inserts for 16 different configurations
- 2-gang box includes 3 inserts for over 60 different configurations
- Cord cover opening fits #12 AWG or lighter cord
- Includes pre-mounted gasket




WIU-1



WIU-1 Inserts

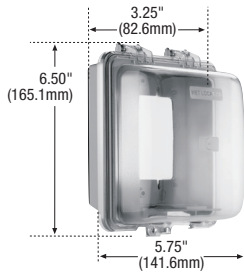

WIU-2

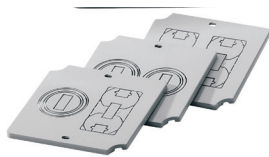

WIU-2 inserts

Extra duty while-in-use weather protective covers

Description	Gang	Color	Catalog no.
Horizontal mount	1	GY	<input type="checkbox"/> WIU-1HX
Horizontal mount	1	W	<input type="checkbox"/> WIU-1WHX
Vertical mount	1	GY	<input type="checkbox"/> WIU-1VX
Vertical mount	1	W	<input type="checkbox"/> WIU-1VWX
Horizontal/vertical mount	2	GY	<input type="checkbox"/> WIU-2X
Horizontal/vertical mount	2	W	<input type="checkbox"/> WIU-2WX

While-in-use weather protective cover

Product description

- 1-gang self-closing
- 1-gang extra depth, self-closing
- 2-gang, self-closing

Features

- Rugged UV-resistant polycarbonate cover and back protects devices without cracking or breaking and is non-corrosive and non-conductive
- Moveable hinges reposition easily for vertical or horizontal mounting (1-gang only)
- Self-closing cover
- 1-gang box includes 3 inserts for 16 different configurations
- 2-gang box includes 3 inserts for over 60 different configurations
- Includes pre-mounted gasket
- Meets Canadian electrical code rule 26-702

Standard duty while-in-use weather protective covers

Description	Gang	Color	Depth	Catalog no.
Horizontal/vertical mount	1	GY	3.25" deep (82.6mm)	<input type="checkbox"/> WIU-1
Horizontal/vertical mount	1	W	3.25" deep (82.6mm)	<input type="checkbox"/> WIU-1W
Horizontal/vertical mount	1	GY	4.75" deep (120.7mm)	<input type="checkbox"/> WIU-1D
Horizontal/vertical mount	2	GY	3.25" deep (82.6mm)	<input type="checkbox"/> WIU-2
Horizontal/vertical mount	2	W	3.25" deep (82.6mm)	<input type="checkbox"/> WIU-2W

Color information:

GY (Gray), W (White)



Compliances, specifications and availability are subject to change without notice.