


Commercial Duty

Bronze Line

All Bronze Line HD commercial fans are complete with corrosion resistant epoxy-coated metal blades.

save

up to
50% of your cooling cost
30% of your heating cost

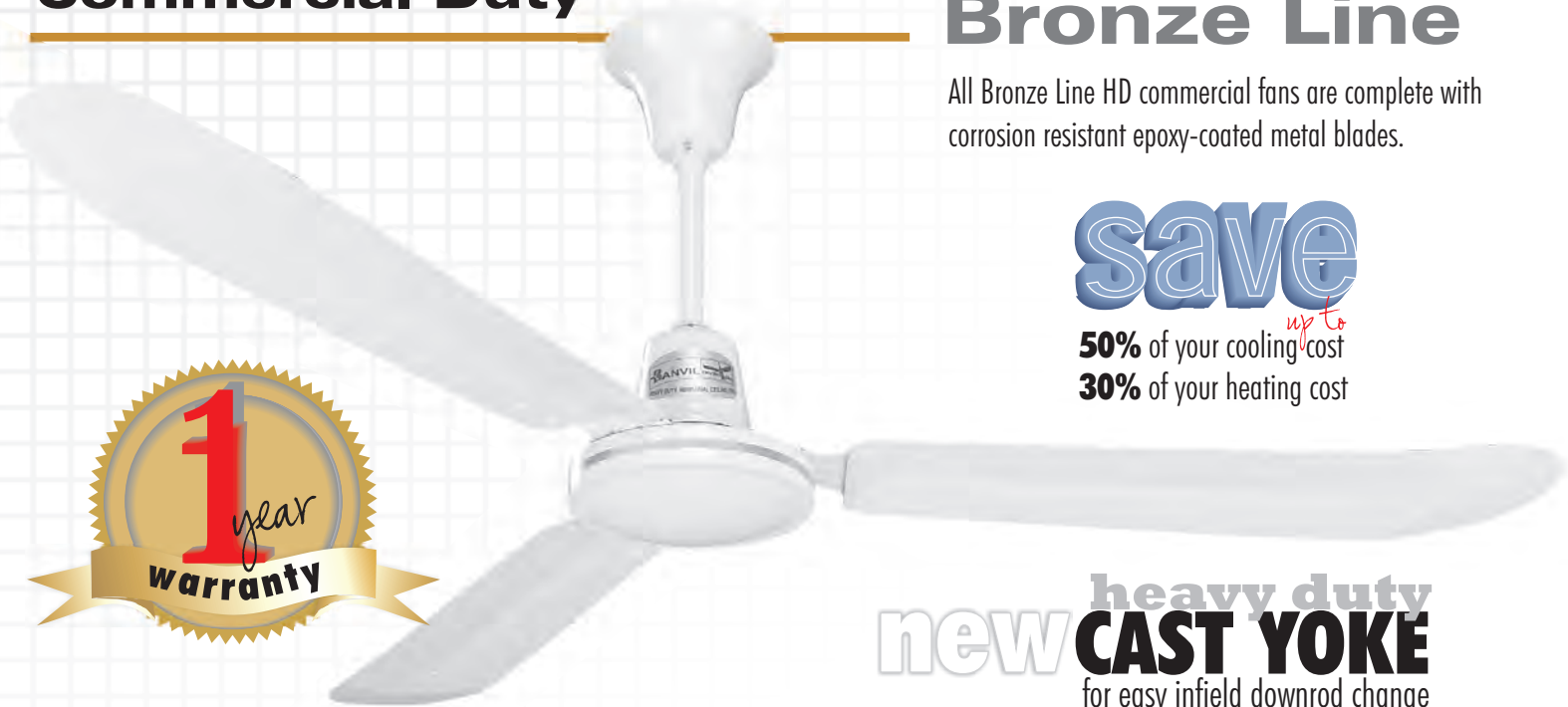

new heavy duty CAST YOKE
 for easy infield downrod change

Model	FP36	FP36R	FP36R-5W	FP48	FP48R	FP48R-5W	FP56	FP56-36**	FP56R	FP56R-36**
Safety Cable	60"	60"	60"	60"	60"	60"	60"	60"	60"	60"
Cord/Lead Wire	60"	60"	60"	60"	60"	60"	60"	60"	60"	60"
Diameter Sweep	36"	36"	36"	48"	48"	48"	56"	56"	56"	56"
CFM	10,500	10,500	10,500	18,000	18,000	18,000	22,000	22,000	22,000	22,000
Area (sq.ft.)	700	700	700	1,400	1,400	1,400	1,700	1,700	1,700	1,700
Velocity (ft/m)	600	600	600	600	600	600	600	600	600	600
Volts	120	120	120	120	120	120	120	120	120	120
Amps	0.35	0.35	0.35	0.50	0.50	0.50	0.55	0.55	0.55	0.55
Watts	40	40	40	50	50	50	65	65	65	65
RPM (max)	360	360	360	320	320	320	280	280	280	280
Wiring	plug-in	3+ground	4+ground*	plug-in	3+ground	4+ground*	plug-in	plug-in	3+ground	3+ground
Airflow	down only	up & down	up & down	down only	up & down	up & down	down only	down only	up & down	up & down
Weight	9 lbs	9 lbs	9 lbs	11 lbs	11 lbs	11 lbs	13 lbs	13 lbs	13 lbs	14 lbs



ideal for commercial use

*requires 106FR 5amp reversing control

**with 36" downrod

all Bronze models are curved tip

Bronze features

- Downrod diameter 7/8" eg E962-36
- Corrosion-resistant epoxy prime and finish coat on all metal housing & blades
 The aerodynamically curved-tip blade results in maximum air delivery.
- All metal, no plastic.
- Permanent lubricated sealed TPI ball bearings.
- Totally enclosed impedance protected motor. Non-polar, extra heavy duty capacitor.
- Use solid state infinite speed motor controls or church quiet control (WC103)
- Heavy cast yoke for easy infield downrod change.
- Customized downrod lengths over 36" available.
 Also 16' cord with plug part# Cord-Wh16.
- For church quiet control use WC103 Control
 for one fan only

