




N Series

Thermoplastic PAR18 Emergency Remotes

Approvals: 
CSA Certified to
C22.2 #141

Description

The Stanpro N series are thermoplastic remote heads featuring a fully adjustable locking tilt and swivel. Available with LED, tungsten or quartz lamps up to 18W, these remotes are designed for use with 6, 12 or 24V emergency lighting circuits. The 5" canopy mounts directly to a standard electrical box (not supplied). Standard finish is white. Also available in Colour black.

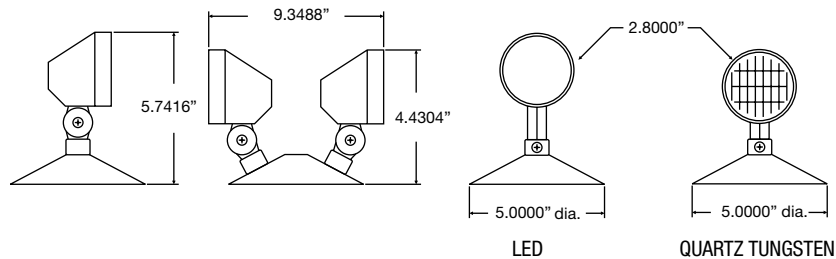

Warranty

As always, Stanpro is Focused on Quality. For complete warranty details, please see our terms and conditions.

Ordering guide

LED	Series	Voltage	Lamp watts	Lamp type	Colour
	N1 - Single head N2 - Double head N3 - Triple head N4* - Quad head	06-12V - 6V to 12V operational 24V - 24 volt	3W - 3 watts 4W - 4 watts	LJ - LED 6V-12V LR - LED 24V	BLANK - White (standard) BK - Black

QUARTZ TUNGSTEN	Series	Voltage	Lamp watts	Lamp type	Colour
	N1 - Single head N2 - Double head N3 - Triple head N4* - Quad head	06 - 6VDC 12 - 12VDC 24 - 24VDC	(eg. 12W) see lamp selection chart	Q - Quartz halogen T - Tungsten	BLANK - White (standard) BK - Black

* requires 12" diameter canopy

Lamp selection

	6 Volts	12 Volts	24 Volts
LED			
LJ - LED	3W, 4W		4LR
PAR18 - Small Heads			
Q - Quartz halogen	8W, 10W, 12W	8W, 10W, 12W	12W
T - Tungsten	5.4W, 7.2W, 9W	5.4W, 9W, 12W, 18W	9W, 18W

