

WPTL-L

LED WALL PACK

87W or 148W (7127 or 12769 lumens)

IP RATING
65



Approvals:

cULus listed

Suitable for outdoor use.




DESCRIPTION

The newly designed WPTL-L is a highly efficient LED wall mount luminaire. This fixture is supplied with a wall bracket (for surface mounting only). Other options include: a wiring box (for feed trough mounting), a trunion (for flood mounting) or a slipfitter (for area lighting). This fixture is best suited for entrances, underpasses, or anywhere controlled security lighting is required. The WPTL-L is made of tough die cast aluminum housing and is IP65 rated.

TECHNICAL SPECIFICATIONS

- Die Cast Aluminum housing
- Bronze UV resistant powder coat finish (standard)
- Input voltage: 120-277V AC or 347V AC
- High quality, long life LEDs
- Estimated lifespan of 50 000 hours
- 87 Watts offers 7127 total lumens
- 148 Watts offers 12769 total lumens
- 5000K colour temperature
- Low starting temperature of -40°C

DIMENSIONS

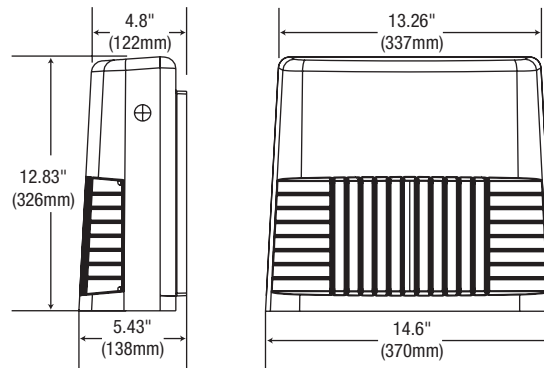

ORDERING GUIDE

Series	Lamp type	Wattage	Voltage	Color temperature	Options
WPTL	L - LED	S1 - 7 127 lumens (87W) S2 - 12 769 lumens (148W)	W - 120-277V H - 347V	50K - 5000K	P __ - Photocell (specify voltage) A - Slipfitter TR - Trunion or Yoke mount WB - Wiring box (for feed trough mounting)



DLC (Design-Lights Consortium®) qualified products. Please visit www.designlights.org/QPL to verify the latest update of the DLC Qualified Products List and validate which ones are qualified. Some restrictions may apply.