

YDD-L

LED DUSK TO DAWN YARD LIGHT 41W (3194 lumens)



Approvals:
cULus listed
Suitable for outdoor use.
Powered by **LEDs**



DESCRIPTION

The YDD-L series are energy conserving dusk to dawn yard lights. They are a versatile and economic light source that is good on the environment and use long life LED's for energy efficiency. The YDD-L comes standard with a photocell, which helps provide significant power savings. They also include installation brackets for pole mounting and a 21" arm for ease and versatility of installation.

Includes 5 feet of cable to facilitate connection to the junction box when mounting with the pole arm.


TECHNICAL SPECIFICATIONS

- Grey die cast housing
- Standard with photocell (120V only) and 21" arm
- Input voltage: 120-277V AC
- High quality, long life LEDs
- Estimated lifespan of 50 000 hours
- 41W that offers 3194 total delivered lumens
- 5000K color temperature
- Low starting temperature of -40°C

Accessories (order SEPARATELY)

PH0009	Shorting cap
---------------	--------------

DIMENSIONS

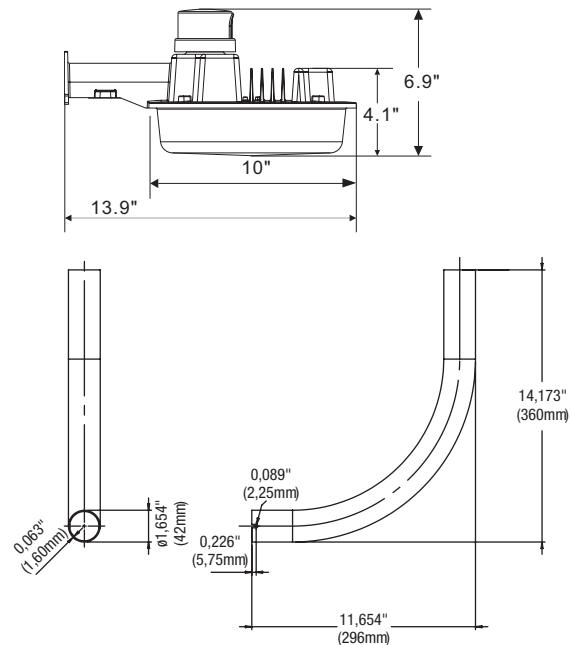

ORDERING GUIDE

YDD	L	S1	W	5K	PT120
Series	Lamp type	Wattage (delivered lumens)	Voltage	Color temperature	Options
YDD	L - LED	S1 - 41W (3194 lumens)	W - 120-277V	5K - 5000K	PT__ - Photocell (twist-lock - specify voltage)



DLC (Design-Lights Consortium®) qualified products. Please visit www.designlights.org/QPL to verify the latest update of the DLC Qualified Products List and validate which ones are qualified. Some restrictions may apply.