

RMR

RAINSTORM

NBC2010 compliant

NEMA4X 120/347VAC Input

Approvals:
 CSA Certified to C22.2 #141.15 and C860



DESCRIPTION

The RMR series of NEMA4X and EEMAC4X rated weatherproof signs is designed to operate in extreme environments. The fully gasketed housing is suitable for outdoor and wash-down locations. Available in AC only, AC/DC and internally self-powered versions.

CIRCUITRY - AC & AC/DC

- LED ultra bright light source
- 120/347VAC Input, field selectable
- 1.9W power consumption single or double face
- Emergency DC wattages as follows:
6VDC = 0.9W 12VDC = 0.9W 24VDC = 0.9W


CIRCUITRY - SELF-POWERED

- LED ultra bright light source
- 120/347VAC Input, field selectable
- 2W power consumption single or double face
- High-performance, sealed Ni-Cad battery
- 90 minutes emergency duration (standard)
 120 minutes emergency duration is optional
- Solid state transfer and battery charger

MECHANICAL

- Heavy-duty glass fibre reinforced polyester construction
- Lens with one piece, molded gasket
- Four integral mounting holes (one per corner) protected behind polycarbonate cover
- Lens secured to housing with four oversized captive screws
- The housing is supplied standard in a grey industrial finish. Face plate standard grey. Black is an option for indoor use only

DIMENSIONS

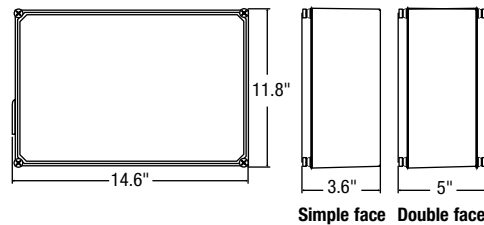

Comes standard (single face) with three pictogram legends for direction selection.



Comes standard (double face) with two pictogram legends.



For double face no arrow options, select "0" on the options column.

ORDERING GUIDE

RMR			GY			
Series	Nbr of faces	Mounting	Frame colour	Face colour	DC Voltage	Options†
RMR	1 - Single face 2 - Double face	CM - Ceiling mount WM - Wall mount EM - End mount PM - Pendant mount	GY - Grey	GY - Grey (standard) BK - Black (indoor only)	NDC - AC only UDC - Universal DC backup voltage 6, 12 or 24VDC IB - Self-powered for 90 minutes IB1 - Self-powered for 120 minutes	WG*, BO, WO, OP, TP 0 - No indicators (double face only) ↓ ↑ ↗ ↘ ↙ ↘ D U UR DR DL UL Note: Indicators option available for single & double option only.

† For detailed options descriptions, please consult the options page.

* Specify mounting.