

L2STL

LED STRIP WITH LENS

Approvals:
CSA and cULus



DESCRIPTION

A narrow LED lensed strip creates a smooth diffused light that is ideal for commercial, industrial, retail or residential applications. Can be used in covers and display applications. Also ideal for task and general area lighting.

HOUSING & FINISHING

- Sleek and compact design ideal for installation in tight spaces
- 22 gauge white powder painted steel
- Contoured frosted acrylic diffuser
- Enclosed lens prevents penetration of dust, insects and other debris into the LED compartment


MOUNTING

Surface (standard), suspended or row mounting possible (see accessories).

TECHNICAL SPECIFICATIONS

- Easy to clean and service
- Long life LEDs that provide 80+ CRI are available in 3000K, 3500K and 4000K colour temperature
- Estimated lifespan of over 50000 hours to L70
- 0-10V dimming is standard
- Canopy plate for octagonal junction box is included (field installable)
- Ambient temperature: -30°C to +50°C

DIMENSIONS

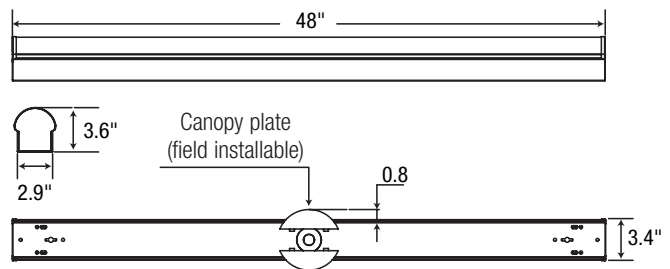

Accessories (order separately)

HAR766	V Hook (order 2 pieces per fixture)
BKT604	Continuous row mounting aligner for suspended installation
WGD055-48-SL	White wireguard 48"

QUICK SHIP

Part Number	Wattage	Voltage	Colour temperature	Stocking SKU	Premium DLC listed
L2STL-48LS2-W/35K	2464 lumens 22W	120-277V	35K - 3500K	✓	✓
L2STL-48LS2-W/40K	2530 lumens 22W	120-277V	40K - 4000K	✓	✓
L2STL-48LS3-W/35K	3680 lumens 35W	120-277V	35K - 3500K	✓	✓
L2STL-48LS3-W/40K	3710 lumens 35W	120-277V	40K - 4000K	✓	✓
L2STL-96LS2-W/35K	4550 lumens 40W	120-277V	35K - 3500K	✓	✓
L2STL-96LS2-W/40K	4600 lumens 40W	120-277V	40K - 4000K	✓	✓
L2STL-96LS3-W/35K	7600 lumens 67W	120-277V	35K - 3500K	✓	✓
L2STL-96LS3-W/40K	7650 lumens 67W	120-277V	40K - 4000K	✓	✓

CONFIGURABLE ORDERING GUIDE

Series	Size	Lamp type	Lumen package delivered*	Voltage	Colour temperature	Options
L2STL	48 - 48"	L - LED	S2A - 2530 lumens (22W) S3A - 3710 lumens (35W)	A - 120V H - 347V W - 120-277V	30K - 3000K 35K - 3500K 40K - 4000K	DIM2 - Line voltage dimming, driver 120V DALI1** - Digital addressable lighting interface driver OSI *** - Occupancy sensor IOSI - Integrated OSI
	96 - 96"		S2A - 5100 lumens (44W) S3A - 7400 lumens (73W)			

* See IES files for details.

** Not available for 48" S2A.

*** To see available options, please consult the OSI selection guide on our website.

DLC (Design-Lights Consortium®) qualified products. Please visit www.designlights.org/QPL to verify the latest update of the DLC Qualified Products List and validate which ones are qualified. Some restrictions may apply.