

DOUBLE ROW TERMINAL BLOCKS

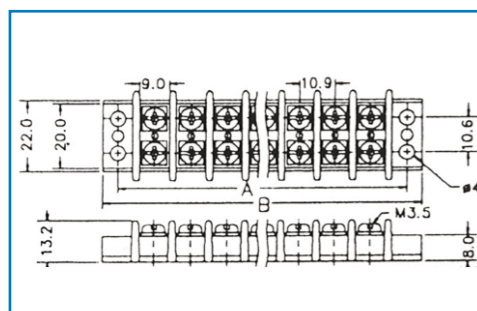
TB200 Series Double Row Terminal Blocks

C7

ITEM NUMBER	NUMBER OF POLES	OA LENGTH	MOUNT CC
TB200-02	2	1.63"	1.31"
TB200-03	3	2.07"	1.75"
TB200-04	4	2.51"	2.18"
TB200-05	5	2.94"	2.62"
TB200-06	6	3.38"	3.06"
TB200-07	7	3.82"	3.50"
TB200-08	8	4.25"	3.93"
TB200-09	9	4.69"	4.37"
TB200-10	10	5.13"	4.81"
TB200-11	11	5.57"	5.25"
TB200-12	12	6.00"	5.68"

TB200 Series

- 20 Amp/300 Volt
- $\frac{7}{16}$ " Centre-to-Centre
- #6-32 Philslot Screw Terminal
- Maximum Wire Size: #12 AWG


Terminal
Blocks

TB300 Series Double Row Terminal Blocks

ITEM NUMBER	NUMBER OF POLES	OA LENGTH	MOUNT CC
TB300-02	2	2.13"	1.68"
TB300-03	3	2.69"	2.25"
TB300-04	4	3.25"	2.81"
TB300-05	5	3.81"	3.37"
TB300-06	6	4.37"	3.93"
TB300-07	7	4.94"	4.50"
TB300-08	8	5.50"	5.06"
TB300-09	9	6.06"	5.62"
TB300-10	10	6.62"	6.18"
TB300-11	11	7.18"	6.75"
TB300-12	12	7.75"	7.31"

TB300 Series

- 30 Amp/300 Volt
- $\frac{9}{16}$ " Centre-to-Centre
- #8-32 Philslot Screw Terminal
- Maximum Wire Size: #10 AWG