



Parts List for Models 591 and 592

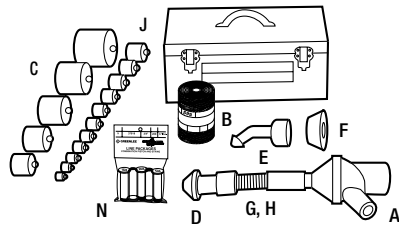

592 Mighty Mouser® Blow Gun Kit

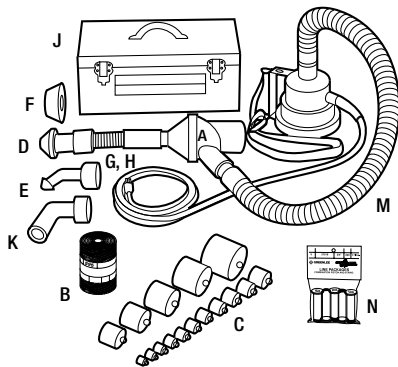

591 Portable Blower Power Fishing System

| KEY | CAT. NO. | UPC NO. | DESCRIPTION | 592 | 591 |
|-----|----------|---------|--|-----|-----|
| A | 691 | 32095 | Mighty Mouser® Blow Gun | 1 | 1 |
| B | 595 | 32433 | Fish Line – 85 lbs. (378N) pulling strength; 2,150' (655 m) long | 1 | 1 |
| C | * | | Piston set for 1/2"-4" conduit (EMT & Rigid) | | |
| D | 25644 | 25644 | Adapter Cone 1-1/4"-2-1/2" Conduit | 1 | 1 |
| E | 25646 | 25646 | Adapter Cone 1/2"-1" Conduit | 1 | 1 |
| F | 25645 | 25645 | Adapter Cone 3"-4" Conduit | | 1 |
| G | 32104 | 32104 | Flexible Hose 1-1/2" dia. x 1' (38.1 mm x 305 mm) | 1 | 1 |
| H | 33451 | 33451 | Hose Clamp | 1 | 1 |
| J | 32662 | 32662 | Storage Box | 1 | 1 |
| K | 23360 | 23360 | Adapter Nozzle for Tape and Line | | 1 |
| M | 32431 | 32431 | Flexible Hose 1-1/2" x 4' (38.1 mm x 1.2 m) | | 1 |
| N | 37917-10 | 06274 | 1/2" Conduit x 150' (46 m) Line Pkg. | 10 | 10 |
| N | 37920-5 | 06277 | 3/4" Conduit x 450' (137 m) Line Pkg. | 5 | 5 |
| N | 37923-5 | 06280 | 1" Conduit x 450' (137 m) Line Pkg. | 5 | 5 |

*See below

Conduit Pistons



- Use with blower or vacuum power fishing system to pioneer the line through the conduit run.
- Flexible foam body for an air-tight seal.
- Color-coded end disk with embossed size markings for fast, easy selection.
- Strong steel center rod with loops on both ends.
- Pistons available for all types and sizes of conduit 1/2" through 6".

PISTON SETS

| CAT. NO. | UPC NO. | DESCRIPTION |
|----------|---------|--|
| S2613 | 26777 | 1/2", 3/4", 1", 1-1/4", 1-1/2" and 2" EMT, IMC and Rigid |
| 34317 | 34317 | 2-1/2", 3", 3-1/2" and 4" EMT |

INDIVIDUAL PISTONS

| CAT. NO. | UPC NO. | PACKAGE | CONDUIT SIZE | CONDUIT TYPE | COLOR |
|----------|---------|---------|--------------|--------------|--------|
| 608-5 | 08263 | POP | 1/2" | All | Green |
| 608 | 11038 | BULK | 1/2" | All | Green |
| 609-5 | 08264 | POP | 3/4" | All | Green |
| 609 | 11039 | BULK | 3/4" | All | Green |
| 610-5 | 08265 | POP | 1" | All | Green |
| 610 | 11040 | BULK | 1" | All | Green |
| 611-3 | 08266 | POP | 1-1/4" | All | Green |
| 611 | 11041 | BULK | 1-1/4" | All | Green |
| 612-2 | 08267 | POP | 1-1/2" | All | Green |
| 612 | 11042 | BULK | 1-1/2" | All | Green |
| 613 | 16511 | | 2" | All | Green |
| 614 | 16512 | | 2-1/2" | IMC, Rigid | Green |
| 621 | 19107 | | 2-1/2" | EMT | Yellow |
| 615 | 16513 | | 3" | IMC, Rigid | Green |
| 622 | 19109 | | 3" | EMT | Yellow |
| 616 | 16514 | | 3-1/2" | IMC, Rigid | Green |
| 646 | 24326 | | 3-1/2" | EMT | Yellow |
| 617 | 16515 | | 4" | IMC, Rigid | Green |
| 623 | 19110 | | 4" | EMT | Yellow |
| 618 | 16517 | | 5" | All | Green |
| 619 | 16951 | | 6" | All | Green |