



mpresario
CONVECTAIR



LIVING SPACES

A CAMPA PRODUCT


CAMPA

■ Impresario pairs a minimalist design with contemporary coloured tempered glass to enhance your most elegant decor.

■ Impresario diffuses immediate, regular, even and perceptible heat.

The exceptional technology of continuous radiant heating and the intelligent controls deliver unequalled comfort.

The next
to huma

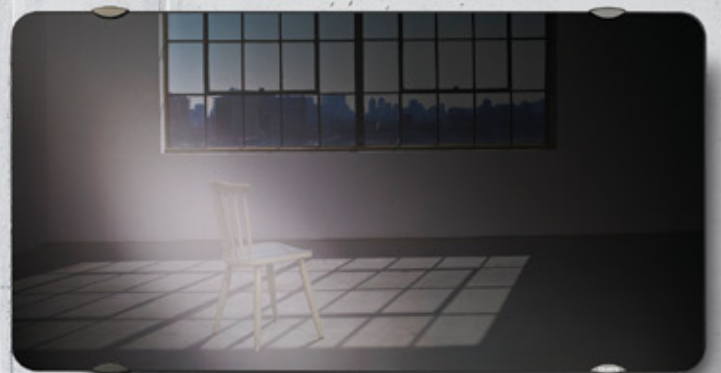

best thing
in warmth



mpresario


IMPRESARIO

LIVING SPACES



GOLDEN SAND COPPER BROWN ASTRAKAN BLACK WHITE LILY IVORY LACQUER GREY QUARTZ MIRROR

TECHNICAL SPECIFICATIONS 7716

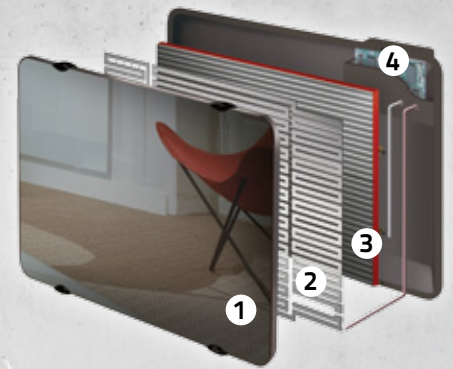

HEATING ELEMENTS

Total capacity 1 000, 1 500 or 2 000 W

Radiant heat - Radiant front panel (1) with integrated surface element (2).
- Internal high-efficiency aluminum radiant element (3).

Thermal protection Automatic reset overheat protection.

INSTALLATION AND CONNECTION

Installation height 8 in (20 cm).

Clearances

Front: 30 in (75 cm)

Sides: 6 in (15 cm)

Above: 6 in (15 cm)

Installation Quick-mounted surface installation with screw-in bracket.

Connection 240-V unit: Flexible cord connection. Installation requires 2 in X 3 in wall box (not included).

Note 3-conductor cable or 2-conductor cable with a third wire should be used if unit is to be linked with the Convectair Programmer module (7392 FP).

TEMPERATURE CONTROL [4]

An intelligent system that manages both heating elements to achieve the ultimate comfort of radiant heating. On-demand energy-saving detection of open window.

Programmer Control panel designed to accept the 7392 Programmer module.
Compatible with the Programmer system - Pilot wire.

CONTROL PANEL

Location Located on top right hand side of the unit with protective cover.

Backlit LCD display with lockable digital controls.

Knob Temperature adjustment

Key 1 To activate open-window detection.

Key 2 On/Off switch.

Key 3 4-Operating mode selection key: Comfort; Economy; Frost protection (45°F (7°C)); Program (automatic setback when connected to the Convectair Programmer).

CABINET

Front Panel shock-resistant tempered glass facade.

Steel construction with polyester/epoxy anti-rust powder coating.

Colours - Standard: BCC = White Lily; SEP = Astrakan Black; MIR = Mirror

- On request: BRU= Copper Brown; GRI= Grey Quartz; SAB = Golden Sand; BEI=Ivory Lacquer

PRODUCT CHART

MODEL	Catalog N°	Colour	Power		Height		Width		Thickness		Weight	
			220-240 V	208 V	cm	in	cm	in	cm	in	kg	lb
Impresario 1000	7716-C10	Standard or on request	1000 W	800 W	56.5	22 1/4	82	32 1/4	12	4 3/4	17	37.4
Impresario 1500	7716-C15	Standard or on request	1500 W	1250 W	56.5	22 1/4	110	43 1/4	12	4 3/4	22.6	50
Impresario 2000	7716-C20	Standard or on request	2000 W	1600 W	69.2	27 1/4	110	43 1/4	12	4 3/4	27.7	61

For guaranteed, dependable operation, we recommend that all units be installed by a licensed electrical contractor. Consult convectair.com to find the most recent installation instructions for our heaters.

WARRANTY

- 2 years against all manufacturing defects†
- 5 years on heating elements

† Unless otherwise indicate

In keeping with our ongoing commitment to research and development, we reserve the right to change product specifications without notice.

IMPRESARIO.CONVECTAIR.COM

1 800 463-6478

Fax: 1 877 434-3166 (toll-free)

E-mail: support@convectair.ca

30, Carré Sicard, Sainte-Thérèse

(Québec) J7E 3X6 Canada

Disponible en français

