
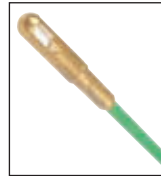


Fiberglass Fish Tapes


 540-50,
 540-100
 (12" Case)


542-100

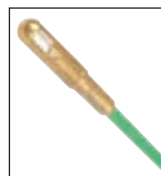

- 12" (305 mm) case has high-impact nylon, one-piece handle for maximum durability, long life, and easy, comfortable use.
- Non-conductive fiberglass tape with low friction coating.
- Has unique non-coiling properties that enable it to fish in large and small conduit equally well, even with wire or cable in place.
- Exclusive, unique, lightweight reel for easy, positive feed out and rewind.
- Excellent for installation of telecommunications and data communication cables in overhead plenums, above suspended ceilings and under raised flooring.
- Fiberglass fish tape is the fastest manual fish tape available. It is intended for fishing only. Rope or line is recommended for pulling.

CAT. NO.	UPC NO.	DESCRIPTION
540-50	35742	50' × 0.175" (15.2 m × 4.4 mm) Fiberglass Fish Tape in Winder Case
540-100	35743	100' × 0.175" (30.5 m × 4.4 mm) Fiberglass Fish Tape in Winder Case
542-150	35745	150' × 3/16" (45.7 m × 4.8 mm) Fiberglass Fish Tape in Reel Stand
542-200	35746	200' × 3/16" (61 m × 4.8 mm) Fiberglass Fish Tapes in Reel Stand
542-250	35747	250' × 3/16" (76.2 m × 4.8 mm) Fiberglass Fish Tape in Reel Stand
R540-100	35744	100' × .175" (30.5 m × 4.4 mm) Fiberglass Fish Tape without Case
05156	05156	150' × 3/16" (45.7 m × 4.8 mm) Fiberglass Fish Tape without Case
05157	05157	200' × 3/16" (61 m × 4.8 mm) Fiberglass Fish Tape without Case
05158	05158	250' × 3/16" (76.2 m × 4.8 mm) Fiberglass Fish Tape without Case
10565	10565	.175" (4.4 mm) pulling eye repair kit, includes (1) pulling eye and adhesive
35750	35750	Accessory Kit for 3/16" (4.78 mm) fish tapes. Includes flexible pulling leader, flexible pushing leader, pulling eye, splice ferrule and threaded ferrule
35908	35908	1/8" (3 mm) Repair Kit - includes threaded end ferrule, splice ferrule and pulling eye
35909	35909	3/16" (4.7 mm) Repair Kit
35919	35919	1/8" (3 mm) Pulling Eye
35930	35930	3/16" (4.7 mm) Pulling Eye
39790	39790	One-Piece Handle
39791	39791	12" (305 mm) diameter Replacement Case
39799	39799	Retrofit Kit to convert 540-50/35742 Fish Tape to one-piece design; includes one-piece handle and retaining strap, winder case and assembly screws
39800	39800	Retrofit Kit to convert 540-100/35743 Fish Tape to one-piece design; includes one-piece handle and retaining strap, winder case and assembly screws

SPECIFICATIONS

Capacity	540 Series- 0.175" (4.4 mm) dia. - 300 lbs. (1.3 kN) maximum design strength
	542 Series-3/16" (4.7 mm) dia. - 400 lbs. (1.7 kN) maximum design strength
Weight	540-50 - 1.8 lbs. (0.8 kg)
	540-100- 2.1 lbs. (1 kg)
	R540-100 -1.2 lbs. (0.6 kg)
	542-150 -15 lbs. (6.8 kg)
	542-200- 16 lbs. (7.2 kg)
	542-250- 17 lbs. (7.7 kg)