


# Distribution blocks, single pole

## Type BRU


### Screw clamp, DIN 3

BRU 160 A - 70 mm<sup>2</sup> block - 35.2 mm 1.388" spacing

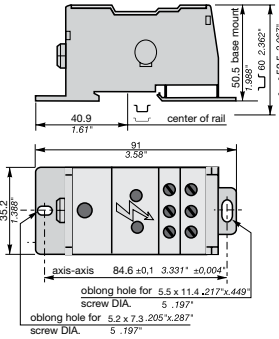

BRU 160 A

Characteristics		IEC		UL / CSA
		NFC	DIN	
Rated voltage	V	600	600	600
Rated current	A	160	160	160
Inputs (maximum wire size)				
left input wire size	mm <sup>2</sup> /AWG	10-70 mm <sup>2</sup>		8-00 AWG
right input wire size				
Recommended torque	Nm / lb.in	5		35.5 lb.in
Recommended torque wrench				Allen key/5 mm
Outputs: with ferrules	mm <sup>2</sup> /AWG	6x2.5 to 16 mm <sup>2</sup>		14 AWG to 6 AWG
without ferrules				
Recommended torque	Nm / lb.in	1.5 Nm		17.5 lb.in

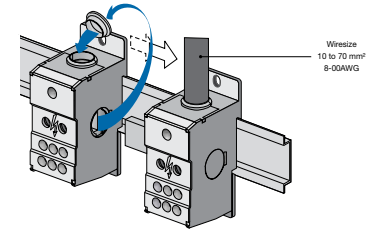


#### Selection

Description	Type	Packaging	Catalog number
Grey body	BRU 160 A	1	035620021


#### Accessories

 Description	Type	Packaging	Catalog number
End stop	BAM2 9.9 mm	50	020635116
Busbar	BO 16/5 2 poles	1	035620116
	BO 16/5 3 poles	1	035620217
	BO 16/5 4 poles	1	035620310



10

BRU 250 A - 120 mm<sup>2</sup> blocks - 44.5 mm 1.752" spacing

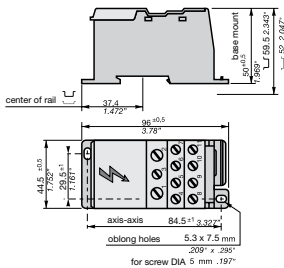

BAM2

Characteristics		IEC		UL / CSA
		NFC	DIN	
Rated voltage	V	600	600	600
Rated current	A	160	160	160
Inputs (mini)				
max. wire size	mm <sup>2</sup> /AWG	35-120 mm <sup>2</sup>		2-0000 AWG
Recommended torque	Nm / lb.in	19		170 lb.in
Recommended torque wrench				Allen key/6 mm
Outputs: with ferrules	mm <sup>2</sup> /AWG	2x2.5 to 25 mm <sup>2</sup>		2x14 AWG to 4 AWG
without ferrules		2x2.5 to 35 mm <sup>2</sup>		2x14 AWG to 2 AWG
Recommended torque	Nm / lb.in	3.5 Nm		31 lb.in
Wire size with/without ferrule	mm <sup>2</sup> /AWG	5x2.5 to 16		5x14 AWG to 6 AWG
Recommended torque	Nm / lb.in	2 Nm		18 lb.in
Wire size with/without ferrule	mm <sup>2</sup> /AWG	4x2.5 to 10		4x14AWG to 8 AWG
Recommended torque	Nm / lb.in	2 Nm		18 lb.in

#### Selection

Description	Type	Packaging	Catalog number
Grey body	BRU 250 A	1	017965715
Black body	BRU 250 ALU	1	035620714

#### Accessories

Description	Type	Packaging	Catalog number
End stop	BAM2 9.9 mm	50	020635116
Copper lug		1	XUS003154
Replacement cover for BRU 250 A		1	XUS003157
Replacement cover for BRU 250 ALU		1	XUS003158

