


30mm, IP 65, UL Type 4, PG 13.5 and 1/2" NPT

Movement to be detected

30° Cam translation movement

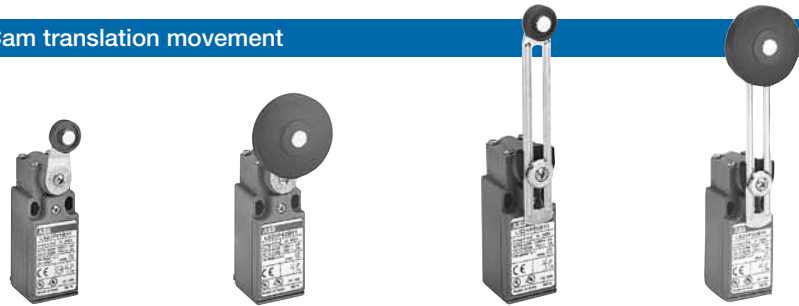

Operating head type

	Ø 18 Polyamide roller lever	Ø 45 Rubber roller lever	Adjustable Ø 18 polyamide roller lever	Adjustable Ø 45 rubber roller lever
Conformity / (N.C. contact with positive opening operation)	EN 50 047			
Maximum actuation speed	m/s 1.5	1.5	1.5	1.5
Min. torque:				
- actuation	N.m 0.10	0.10	0.10	0.10
- positive opening operation	N.m 0.32	—	—	—

Additional technical data

B11 = Snap action contacts	Catalog number	LS35P41B11	LS35P42B11	LS35P51B11	LS35P52B11
	Operation diagram				
D11 = Non-overlapping slow action contacts	Catalog number	LS35P41D11	LS35P42D11	LS35P51D11	LS35P52D11
	Operation diagram				
C11 = Overlapping slow action contacts	Catalog number	LS35P41C11	LS35P42C11	LS35P51C11	LS35P52C11
	Operation diagram				
L02 = Slow action contacts	Catalog number	LS35P41L02	LS35P42L02	LS35P51L02	LS35P52L02
	Operation diagram				
L20 = Slow action contacts	Catalog number	LS35P41L20	LS35P42L20	LS35P51L20	LS35P52L20
	Operation diagram				
B02 = Snap action contacts	Catalog number	LS35P41B02	LS35P42B02	LS35P51B02	LS35P52B02
	Operation diagram				
Weight (packing per unit)	oz.	3.17	4.23	3.52	4.58

Approximate dimensions (mm)

