

Other configurations


Side operated

30A – 800A



For a complete assembly,
please select one of each:

- 1 switch
- 1 handle
- 1 shaft
- 1 terminal lug kit

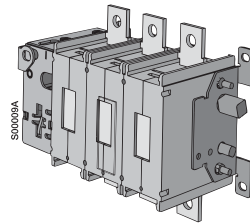


OETL-NF200A-S



OXP8X240




OHB80J8TE00S

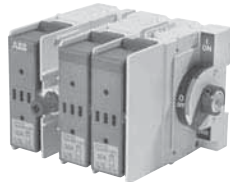

OSNF30-S



OHY_J_

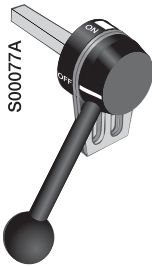

OETL-ZX74



OXP5X170
OXP8X240
OXP12X325



OZXA-24



OZXA-25



OZXA-26

Side operated switches — 3 pole

CSA general purpose amp rating	IEC AC21 amp rating	Maximum horsepower rating					Catalog number	List price
		Three phase						
		200V	208V	240V	480V	600V		
30	32	5	7.5	7.5	15	20	OSNF30-S	
60	63	15	15	15	30	50	OSNF60-S	
100	125	25	25	30	60	75	OSNF100-S	
200	250	60	60	75	150	200	OETL-NF200A-S	
400	630	100	100	125	250	350	OETL-NF400-S	

Handles

UL/NEMA type	Color	Length mm	Marking	Defeatable	Padlockable	Catalog number	List price
For use with OSNF30-S							
1, 12, 3R	Black	65	O/I & OFF/ON	Yes	Yes	OHB65J6	
1, 12, 3R	Red/Yel	65	O/I & OFF/ON	Yes	Yes	OHB65J6	
For use with OSNF60-S — OSNF100-S							
1, 12, 3R	Black	80	O/I & OFF/ON	Yes	Yes	OHB80J6	
1, 12, 3R	Red/Yel	80	O/I & OFF/ON	Yes	Yes	OHY80J6	
For use with OETL-NF200A-S							
1, 12, 3R	Black	80	O/I & OFF/ON	Yes	Yes	OHB80J8	
1, 12, 3R	Red/Yel	80	O/I & OFF/ON	Yes	Yes	OHY80J8	

Shafts

For use on :	Length mm	Description	Catalog number	List price
OSNF30-S	170	6 x 6mm	OXP6X170	
OSNF60-S – OSNF100-S	210	6 x 6mm	OXP6X210	
OETL-NF200A-S	240	8 x 8mm	OXP8X240	
OETL-NF400-S	325	12 X 12mm	OXP12X325	

Terminal lug kits

For use on:	Wire size	Weight	Wire type	Lugs per kit	Catalog number	List price
OSNF30-S	#18 – 8	—	Cu	—	Integral	
OSNF60-S	#14 – 4	—	Cu	—	Integral	
OSNF100-S	#14 – 2/0	0.43	Cu/Al	6	OZXA-24	
OETL-NF200A-S	#6 – 300 kcmil	0.93	Cu/Al	6	OZXA-25	
OETL-NF400-S	#2 – 600 kcmil	3.520	Cu/Al	6	OZXA-26	