




# 400A – 1200A Fusible disconnect switches

## CSA fuse class J, T, L



### 400 – 800 Amp switches, 600V

CSA general purpose amp rating	CSA Fuse type 600V	Maximum horsepower rating Three phase				Catalog number	List price	
		200V	208V	240V	480V			600V
<b>2 pole</b>	400	J	—	—	—	—	OS400J02	
	600	J	—	—	—	—	OS600J02	
	800	L	—	—	—	—	OS800L02	
	1200	L	—	—	—	—	OS1200L02	
<b>3 pole</b>	400	J	100	125	125	250	350	OS400J03
	400	J	100	125	125	250	350	OS400J12
	400	J	100	125	125	250	350	OS400J30
	600	J	150	150	200	400	500	OS600J03
	600	J	150	150	200	400	500	OS600J12
	600	J	150	150	200	400	500	OS600J30
	800	L	200	200	250	500	600	OS800L03
	800	L	200	200	250	500	600	OS800L12
	1200	L	—	—	—	—	—	OS1200L03
	1200	L	—	—	—	—	—	OS1200L12
<b>4 pole</b>	400	J	100	125	125	250	350	OS400J04
	600	J	150	150	200	400	500	OS600J04
	800	L	200	200	250	500	600	OS800L04
	1200	L	—	—	—	—	—	OS1200L04

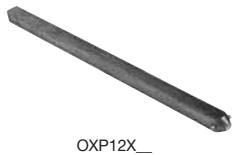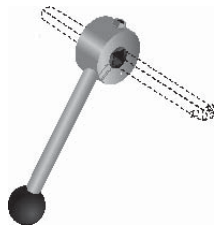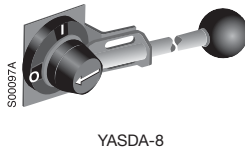

### Pistol handles — ( □ 12 x 12mm ) ②

NEMA type	IEC type	Color	Length mm	Marking	Defeat-able	Padlock-able	Catalog number	List price
1,3R,12	IP65	Blk	145	O/I & Off/On	Yes	Yes	OHB145J12	
1,3R,12	IP65	R/Y	145	O/I & Off/On	Yes	Yes	OHY145J12	
1,3R,12	IP65	Grey	145	O/I & Off/On	Yes	Yes	OHG145J12	
1,3R,12	IP65	Blk	175	O/I & Off/On	Yes	Yes	OHB175J12	
1,3R,12	IP65	R/Y	175	O/I & Off/On	Yes	Yes	OHY175J12	
1,3R,4,4X,12	IP66	Blk	145	O/I & Off/On	Yes	Yes	OHB145L12	
1,3R,4,4X,12	IP66	R/Y	145	O/I & Off/On	Yes	Yes	OHY145L12	
1,3R,4,4X,12	IP66	Blk	175	O/I & Off/On	Yes	Yes	OHB175L12	
1,3R,4,4X,12	IP66	R/Y	175	O/I & Off/On	Yes	Yes	OHY175L12	
1,3R,4,4X,12	IP65	Metal	220	Off/On	—	Yes	YASDA-8	
1,3R,4,4X,12	IP66	SS	125	O/I & Off/On	Yes	Yes	OHM125L12	
1,3R,4,4X,12	IP66	SS	175	O/I & Off/On	Yes	Yes	OHM175L12	
1,3R,4,4X,12	IP66	SS	275	O/I & Off/On	Yes	Yes	OHM275L12	
1,3R,12	IP65	Blk	274	O/I & Off/On	Yes	Yes	OHB274J12	
1,3R,12	IP65	Blk	330	O/I & Off/On	Yes	Yes	OHB330J12	

### Direct mounted handles Padlockable with three padlocks in the OFF-position. Includes shaft and mechanism cover

For use on	Color	Description	Marking	Padlockable	Catalog number	List price
OS200	Black	No shaft required	O/I	Yes	OSV200BK	
OS400	Black	No shaft required	O/I	Yes	OSV400BK	
OS600	Black	No shaft required	O/I	Yes	OSV800BK	
OS400-600, OES800	Metal	Mounts on 12mm shaft	-	No	YASDA-33	

### Shaft 12 mm — ( □ 12 x 12mm )

For use on	Shaft length mm	Mounting depth <sup>①</sup> (mm)		Catalog number	List price
		OS400J_	OS600J_ – OS800L_		
	250	231 – 340	254 – 325	OXV12X250	
	280	259 – 368	285 – 356	OXV12X280	
	325	305 – 414	330 – 401	OXV12X325	
	395	376 – 485	401 – 472	OXV12X395	
	465	445 – 556	470 – 541	OXV12X465	
	535	516 – 625	536 – 612	OXV12X535	

### Terminal lug kit

For use on:	Wire size	Wire type	Terminal lugs per kit	Catalog number	List price
OS400J_	#2 – 600 kcmil	Cu/Al	6	OZXA-400	
OS400J_	(2)#2 – 300 kcmil	Cu/Al	6	OZXA-402	
OS400J_	(2)#2 – 500 kcmil	Cu/Al	6	OZXA-33	
OS600J_ , OS800L_	(2)#2 – 600 kcmil	Cu/Al	6	OZXA-800	
OS1200L_	(4)#2 – 600 kcmil	Cu/Al	6	OZXA-1200	

① Mounting depth is the distance from the outside of the door to the disconnect switch mounting plate. Shaft can be cut to desired length.  
 ② Plastic pistol grip handle with stainless steel hasp, add suffix EH.  
 ex.: OHB175J12EH.