


LSG

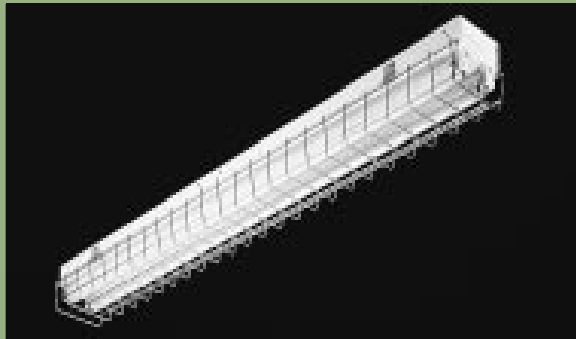

Fluorescent lighting strips for rapid start and preheat lamps.

Low or high power factor ballast.

Combination end plate and strip connector for continuous row installation.

Baked white enamel finish.

Zinc plated wire guard.

RAPID START	LAMPS	LENGTH	CAT. NO.	VOLTS*	BALLAST*
LOW POWER FACTOR BALLAST 	1-15 W/T12	18"	LSG-18-115L-	120	STD
	1-20 W/T12	24"	LSG-2-120L-	120	STD
	1-30 W/T12	36"	LSG-3-130L-	120	STD
	1-40 W/T12	48"	LSG-4-140L-	120	STD
HIGH POWER FACTOR BALLAST 	1-15 W/T12	18"	LSG-18-115-	120	STD
	1-17 W/T8	24"	LSG-2-117-	120	ES
	1-20 W/T12	24"	LSG-2-120-	120	STD
	1-25 W/T8	36"	LSG-3-125-	120	ES
	1-30 W/T12	36"	LSG-3-130-	120	ES
	1-32 W/T8	48"	LSG-4-132-	120	ES
	1-40 W/T12	48"	LSG-4-140-	120	ES
	2-32 W/T8 (tandem)	96"	LSG-8-232-	120	ES
	2-40 W/T12 (tandem)	96"	LSG-8-240-	120	ES
HIGH POWER FACTOR BALLAST 	2-17 W/T8	24"	LSG-2-217-	120	ES
	2-20 W/T12	24"	LSG-2-220-	120	STD
	2-25 W/T8	36"	LSG-3-225-	120	ES
	2-30 W/T12	36"	LSG-3-230-	120	ES
	2-32 W/T8	48"	LSG-4-232-	120	ES
	2-40 W/T12	48"	LSG-4-240-	120	ES
	4-32 W/T8 (tandem)	96"	LSG-8-432-	120	ES
	4-40 W/T12 (tandem)	96"	LSG-8-440-	120	ES

*VOLTS
 120
 277
 347

*BALLAST
 ES = ENERGY SAVING
 EL = ELECTRONIC
 STD = STANDARD

ORDERING EX: CAT. NO. = **LSG-4-240-120-ES**