

C SERIES FLUORESCENT FIXTURE RETROFIT KITS

SURFACE OR RECESSED FIXTURES - 2x2 TWO U-LAMPS TO TWO T8 LAMPS

Kit # C2U22-UNV-ALU-T8

Convert an existing 2' x 2' recessed fluorescent fixture from four T-12 lamps or two U-lamps to two T-8 lamps complete with a new white aluminum snap fit one piece reflector/ballast cover.

COMPONENTS



SPECIFICATIONS


- = 2 x End plates - Fixture white finished steel.
- = 1 x Reflector - Ballast grade 91% TR Aluminum c/w poly film protection
- = 4 x Sockets - Bi-pin locking type. (Shunted unless otherwise specified)
- = Wiring - Color-coded leads #18 TEW solid wire.
- = Mounting - All necessary mounting hardware is provided.
- = Approvals - CSA & UL certified.

*Click on image to print
or save as PDF*



KIT TYPE VERIFICATION PROCEDURE

Check critical dimensions of the fixture you're retrofitting by contacting JAFtech for verification of the correct application.

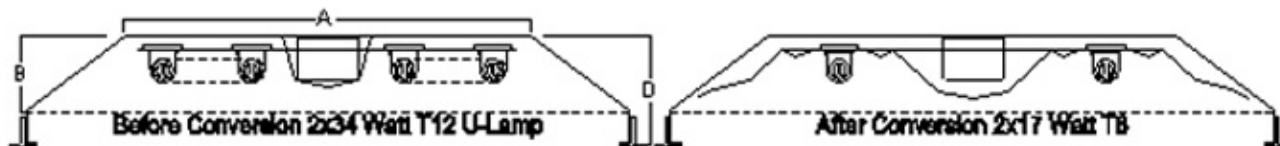

- = **A = 16" - 24"** Inside fixture width measure at top of fixture housing.
- = **B = 2 1/2"** Depth from back of fixture to T-bar rib.
- = **C = 20" - 23.5"** Measurement at opening to fixture.
- = **D = 3.5" - 6"** Overall depth of fixture