

FB900 SKYBAY FIXTURE SERIES

"T8" 8 Lamp High Lumen High Bay Fluorescent Luminaire


Catalogue # FB904-832-8UIS-HB

Four Foot - 120/277 Volts
 Standard Instant Start Ballast
 (89% Ballast Factor)



SPECIFICATIONS

- IES Procedures Tested 94% Efficient
- Total weight 20 lbs
- Standard Instant Start Ballast (89% BF)
- Up to 21,000 initial lumens
 (with high 2950 lumen lamps)
- Total luminaire watts 228W

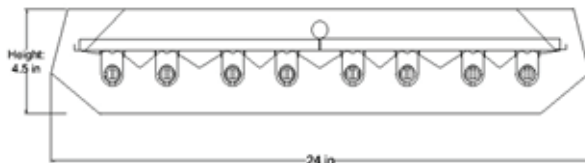

FEATURES

- Instant restart
- High (CRI) Color Rendering Index
- Economical re-lamping
- Lower fixture costs
- 92% white reflective surface
- Ideal for chain or surfacemounting
 ("V" hanging included)
- Anti-vibration cam-lock sockets
- Simple light level control
- High efficiency
- CSA/UL certified

FIXTURE OPTIONS

- Powder coated wire guard
- Available in color
 (see JAFtech color chart)
- Multi level lighting control
- Occupancy and/or photo sensor
- Cord sets and plugs
- Available with 95% Total Reflectance
 Silver Reflector
- Integrated emergency lighting

