 



## SJ Series: General Information



**SJ1S-05B**

<b>Style</b>	5-blade snap mount/surface mount
<b>Terminal/Torque</b>	0.6 - 1.0N•m (Maximum 1.2N•m)
<b>Wire Size</b>	Maximum up to 2 - #14 AWG
<b>Electrical Rating</b>	250V, 12A
<b>Compatible Relay</b>	RJ1S
<b>Compatible Timer</b>	N/A
<b>Hold-Down Spring</b>	N/A
<b>Replacement Locking Lever</b>	SJ9Z-C

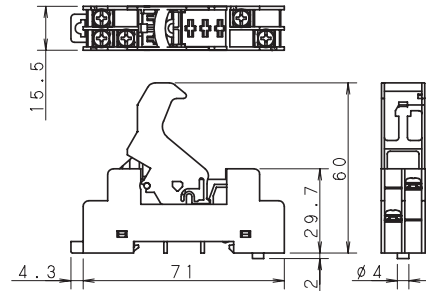



(Top View)



**SJ1S-07L Fingersafe**

<b>Style</b>	5-blade, snap mount/surface mount
<b>Terminal/Torque</b>	0.6 - 1.0N•m (Maximum 1.2N•m)
<b>Wire Size</b>	Maximum up to 2 - #14 AWG
<b>Electrical Rating</b>	250V, 12A
<b>Compatible Relay</b>	RJ1S
<b>Compatible Timer</b>	N/A
<b>Hold-Down Spring</b>	N/A
<b>Replacement Locking Lever</b>	SJ9Z-C

 **SJ1S-07L**


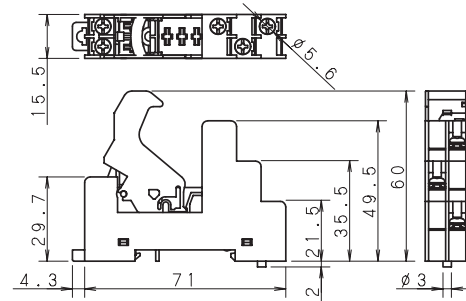


(Top View)



**SJ2S-05B**
 
<b>Style</b>	8-blade, snap mount/surface mount
<b>Terminal/Torque</b>	0.6 - 1.0N•m (Maximum 1.2N•m)
<b>Wire Size</b>	Maximum up to 2 - #14 AWG
<b>Electrical Rating</b>	250V, 8A
<b>Compatible Relay</b>	RJ2S
<b>Compatible Timer</b>	N/A
<b>Hold-Down Spring</b>	N/A
<b>Replacement Locking Lever</b>	SJ9Z-C

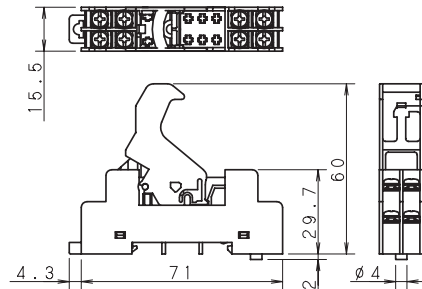

(Top View)

**F Sockets**

All dimensions are in mm.