

FatMax® Blades

- Induction-hardened edge offers 75% longer-lasting* blade life
- 20% stronger* blade is heat treated for flexibility
- Blade edge remains 35% sharper*



*Based on average values compared with Stanley® 1992® blades

SKU #	NUMBER OF BLADES	LENGTH		THICKNESS	BOX QTY	CARTON QTY	UPC
		IN.	MM				
11-700	3	2-7/16	62	.024	10	100	076174117004
11-700A	100	2-7/16	62	.024	6	36	076174760590
11-700L	50	2-7/16	62	.024	6	36	076174760583
11-700T	10	2-7/16	62	.024	10	100	76174760576

Drywall Utility Blades

- Edge is engineered to easily cut abrasive drywall material
- S3 technology double hardens the blade edge for increased* cutting life
- 100% longer life on average compared to Stanley® 11-921 Heavy-Duty Blade, resulting in far fewer blade changes
- Cuts and scores drywall, ceiling tile, wallboard and similar materials
- "DRYWALL" call-out is laser etched on blade to help prevent mixing with standard blades



*Based on average values compared with Stanley® 1992® blades

SKU #	NUMBER OF BLADES	LENGTH		THICKNESS	BOX QTY	CARTON QTY	UPC
		IN.	MM				
11-937	3	2-7/16	62	.024	10	100	076174119374
11-937L	50	2-7/16	62	.024	6	24	076174783513

Paper Blade


- Edge is engineered for precision cuts on wall coverings, borders, paperboard and other light sheet materials
- 50% sharper compared to Stanley's 11-911 Regular-Duty Blade
- "PAPER" call-out is laser etched on blade to help prevent mixing with standard blades



SKU #	NUMBER OF BLADES	LENGTH		THICKNESS	BOX QTY	CARTON QTY	UPC
		IN.	MM				
11-938W	3	2-7/16	62	.024	5	25	076174119381

1991® Extra Heavy-Duty Utility Blades

- Cuts thick, dense sheet materials
- Designed for use in fixed blade knives only

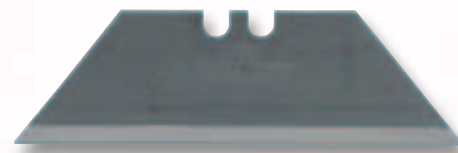

SKU #	NUMBER OF BLADES	LENGTH		THICKNESS	BOX QTY	CARTON QTY	UPC
		IN.	MM				
11-931	5	2-7/16	62	.035	10	200	076174004939
11-931A	100	2-7/16	62	.035	1	10	076174119312