

Knives & Cutting Tools

Klein provides a wide range of knives, scissors and other cutting tools for professional applications across all trades.

FOR PROFESSIONALS... SINCE 1857®



Knives & Cutting Tools



Pocket Knives – One Blade

Lightweight Lockback Knives

- Blades are AUS 8 stainless steel hardened to 58-59 Rc.
- Premium quality blade offers superior edge holding.
- Impact-resistant nylon resin handle with rubber insert (Cat. Nos. 44002-44005).
- Slim and comfortable silver anodized-aluminum handle for corrosion-resistance (Cat. Nos. 44000, 44001, 44006, 44007).
- Black chrome blade and black anodized-aluminum handle for corrosion-resistance (Cat. Nos. 44000-BLK and 44001-BLK).
- Reversible thumb stud provides easy one-handed opening.



44001-BLK



44001



44002



44005

Cat. No.	Blade Steel	Blade Length	Length Closed	Weight (oz.)
Drop Point Blade				
44000	AUS 8 stainless steel	2-1/4" (57 mm)	3-1/8" (76 mm)	1.5
44000-BLK	AUS 8 stainless steel	2-1/4" (57 mm)	3-1/8" (76 mm)	.08
44001*	AUS 8 stainless steel	2-1/2" (64 mm)	3-1/2" (89 mm)	2.5
44001-BLK*	AUS 8 stainless steel	2-1/2" (64 mm)	3-1/2" (89 mm)	1.3
44002	AUS 8 stainless steel	2-3/8" (60 mm)	3-1/2" (89 mm)	1.5
44003	AUS 8 stainless steel	2-3/4" (70 mm)	4-1/8" (105 mm)	2.5
Sheepfoot Blade				
44004	AUS 8 stainless steel	2-3/8" (60 mm)	3-1/2" (89 mm)	1.5
44005	AUS 8 stainless steel	2-5/8" (67 mm)	4-1/8" (105 mm)	2.5
44006*	AUS 8 stainless steel	2-5/8" (67 mm)	3-1/2" (89 mm)	.13
Coping Blade				
44007*	AUS 8 stainless steel	2-1/2" (63 mm)	3-1/2" (89 mm)	.15

* Includes a pocket/belt clip.

Lightweight Lockback Knives – Tanto Blade

- Tanto blade is AUS 8 stainless-steel hardened to 58-59 Rc.
- Black chrome blade and black anodized-aluminum handle for corrosion resistance.
- Premium quality blade offers superior edge holding.
- Reversible thumb stud provides easy, one-handed opening.



44053BLK

Cat. No.	Blade Steel	Blade Length	Length Closed	Weight (oz.)
44051BLK	AUS 8 stainless-steel	2-3/8" (61 mm)	3-3/8" (86 mm)	1.5
44052BLK*	AUS 8 stainless-steel	2-3/4" (69 mm)	3-5/8" (92 mm)	2.4
44053BLK*	AUS 8 stainless-steel	2-7/8" (73 mm)	4" (101 mm)	3.2

* Includes a pocket/belt clip.

Money-Clip Pocket Knife – Spearpoint Blade and Nail File

- Handsome, brushed stainless steel case with rosewood insert.
- Includes money clip, 1-1/2" (38 mm) spearpoint blade and 1-1/2" (38 mm) nail file.



44031

Cat. No.	Blade Type	Blade Length	Length Closed	Weight (oz.)
44031	stainless steel	1-1/2" (38 mm)	2-1/8" x 7/8" x 1/4" (54 mm x 22 mm x 6 mm)	.80

All dimensions are in inches and (millimeters).

▲WARNING: Always wear approved eye protection.

▲WARNING: Never use on or near live electrical circuits.



Pocket Knives – One Blade

Compact Pocket Knives – Drop Point Blade

- Compact and lightweight knives.
- Stainless steel handles and blades for long life.



44033

- Rosewood handle inserts on both sides.
- Modified spearpoint blades lock open.

Cat. No.	Blade Steel	Blade Length	Length Closed	Weight (oz.)
44032	stainless steel	1-5/8" (41 mm)	2-1/2" (64 mm)	1.0
44033	stainless steel	2" (51 mm)	3" (76 mm)	1.8
44034	stainless steel	2-5/8" (67 mm)	4" (102 mm)	4.0

Sportsman Knives – Drop Point Blade

- Curved handle with big bolster.
- Brass bolsters and ebony wood handles.
- Stainless steel blades for long life.
- Brass linings.



44037

- Blade locks open.
- Cat. No. 44037 furnished with leather snap case with belt loop.

Cat. No.	Blade Steel	Blade Length	Length Closed	Weight (oz.)
44035	stainless steel	2" (51 mm)	3" (76 mm)	1.5
44036	stainless steel	2-3/8" (60 mm)	3-1/2" (89 mm)	2.5
44037	stainless steel	3-3/8" (86 mm)	4-7/8" (124 mm)	6.5

Pocket Knives – Coping Blade

- Coping-type blade.
- Compact and lightweight.
- Ideal for skinning small wire and cable.
- Blade locks open (Cat. No 1550-11).

Cat. No.	Blade Steel	Blade Length	Length Closed	Weight (oz.)
1550-5	carbon steel	2-1/4" (57mm)	3-1/4" (83mm)	1.5
1550-11*	carbon steel	2-1/4" (57mm)	3-1/4" (83mm)	1.5
1550-14*	carbon steel	3" (76mm)	4-1/4" (108mm)	4.0
1550-45	stainless steel	2-1/4" (57mm)	3-1/4" (83mm)	1.5

*Blade locks open



1550-11

Pocket Knives – Sheepfoot Slitting Blade

- Extra-large curved sheepfoot slitting-blade – 2-5/8" (67 mm) long.
- Ideal for heavy-duty line work.
- Woodgrain plastic handle.
- Blade locks open.



1550-4

Cat. No.	Blade Steel	Blade Length	Length Closed	Weight (oz.)
1550-4	carbon steel	2-5/8" (67 mm)	4" (102 mm)	4.0
1550-44	stainless steel	2-5/8" (67 mm)	4" (102 mm)	4.0

Pocket Knife – Slitting Blade

- Large, stainless steel, curved-sheepfoot slitting blade – 2-1/2" (64 mm) long.
- Ideal for heavy-duty line work.
- Plastic handle.
- Blade locks open.



1550-24

Cat. No.	Blade Steel	Blade Length	Length Closed	Weight (oz.)
1550-24	stainless steel	2-1/2" (64 mm)	4-3/8" (111 mm)	2.5

All dimensions are in inches and (millimeters).

▲WARNING: Always wear approved eye protection.

▲WARNING: Never use on or near live electrical circuits.



Pocket Knives – Two Blades

2-Blade Pocket Knives – Spearpoint and Screwdriver-Tip Blades



1550-2

- Standard spearpoint blade – 2-1/2" (64 mm) long.
- Screwdriver-tip blade – 2-1/2" (64 mm) long.
- Screwdriver-tip blade locks open.

Cat. No.	Blade Steel	Blade Lengths	Length Closed	Weight (oz.)
1550-2	carbon steel	2-1/2" (64 mm)	3-3/4" (95 mm)	4.0
1550-42	stainless steel	2-1/2" (64 mm)	3-3/4" (95 mm)	4.0

2-Blade Pocket Knife – Sheepfoot and Screwdriver-Tip Blades



1550-7

- Curved sheepfoot slitting blade – 2-3/8" (60 mm) long.
- Screwdriver-tip blade – 2-1/2" (64 mm) long.
- Screwdriver blade locks open.

Cat. No.	Blade Steel	Blade Lengths	Length Closed	Weight (oz.)
1550-7	carbon steel	2-3/8" (60 mm) and 2-1/2" (64 mm)	3-3/4" (95 mm)	4.0

2-Blade Pocket Knife – Sheepfoot and Insulation-Slitting Blades



1550-10

- Curved sheepfoot skinning blade – 2-3/8" (60 mm) long.
- Special insulation-slitting blade – 1-1/2" (38 mm) long.
- Slitting blade locks open.

Cat. No.	Blade Steel	Blade Lengths	Length Closed	Weight (oz.)
1550-10	carbon steel	2-3/8" (60 mm) and 1-1/2" (38 mm)	3-3/4" (95 mm)	4.0

2-Blade Lightweight Lockback Knife – Drop-Point & Screwdriver Blades



44008

- Drop-point and screwdriver blades are AUS 8 stainless-steel hardened to 58-59 Rc.
- Anodized-aluminum handle for corrosion-resistance.
- Includes removable pocket/belt clip for easy access.
- Thumb stud provides easy one-handed opening.

Cat. No.	Blade Steel	Blade Length	Length Closed	Weight (oz.)
44008*	AUS 8 stainless steel	2-1/2" (63 mm)	3-1/2" (89 mm)	.24

* Includes a pocket/belt clip.

All dimensions are in inches and (millimeters).

▲WARNING: Always wear approved eye protection.

▲WARNING: Never use on or near live electrical circuits.



3-Blade Pocket Knife – Sheepfoot, Spearpoint and Screwdriver-Tip Blades

- Curved sheepfoot skinning blade – 2-3/8" (60 mm) long.



- Standard spearpoint blade – 2-1/2" (64 mm) long.
- Screwdriver-tip blade – 2-1/2" (64 mm) long.
- Screwdriver blade locks open.

Cat. No.	Blade Steel	Blade Lengths	Length Closed	Weight (oz.)
1550-6	carbon steel	2-3/8" (60 mm), 2-1/2" (64 mm), 2-1/2" (64 mm)	3-3/4" (95 mm)	5.0

Pocket Knives – Three Blades

3-Blade Pocket Knife – Spearpoint, Insulation-Slitting and Screwdriver-Tip Blades




- Spearpoint blade – 2-1/2" (64 mm) long.
- Special insulation-slitting blade – 1-1/2" (38 mm) long.
- Screwdriver-tip blade – 2-1/2" (64 mm) long.
- Both slitting blade and screwdriver-tip blade lock open.

Cat. No.	Blade Steel	Blade Lengths	Length Closed	Weight (oz.)
1550-9	carbon steel	2-1/2" (64 mm), 1-1/2" (38 mm), 2-1/2" (64 mm)	3-3/4" (95 mm)	5.0

Multi-Purpose Sharpening Steel

- A knife sharpener – and a lot more.
- Tungsten-carbide bonded to fine, medium and rough sharpening surfaces; effectively sharpens any knife.
- Chisel point makes tool useful for hacking, prying, scraping, splitting, cutting sheet metal or other rough jobs that would harm a knife.
- Leather-sheath handle folds out of the way for use as a sharpener, provides a convenient way to hold tool when used as a chisel or other tool.
- Leather lanyard holds tool in sheath and secures it to belt or ring.

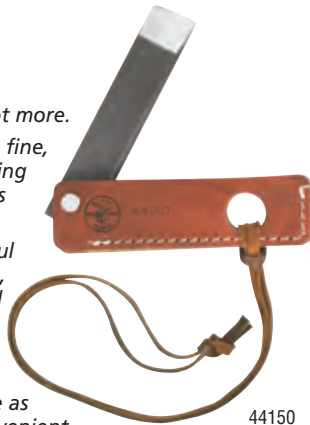

Cat. No.	Overall Size	Weight (lbs.)
44150	5" x 7/8" x 1/4" (127 mm x 22 mm x 6 mm)	.40

Pocket-Sized Knife Sharpener

- A rugged, versatile sharpener featuring fine craftsmanship and unique design.
- Blade unscrews and stores in handle for convenient carrying in tool box, pouch, or pocket.
- Blade is precision-cut, hard-chromed steel for accurate, consistent sharpening and long life.
- Magnetized to trap metal particles when sharpening.
- Handle is high-visibility orange color with handy pocket clip.



Cat. No.	Blade Length	Length Closed	Weight (lbs.)
44151	3-3/4" (95 mm)	5-1/2" (140 mm)	.05

Combination Knife and Scissors Sharpener

- High-grade, tungsten-carbide inserts sharpen both sides of the blade at the same time.
- Restores knife edge in three or four strokes.
- Built-in finger guard helps to protect your hand.
- Lightweight, compact size for easy carrying and storage.
- Sharpens electrician's scissors, pocket knives, retractable-blade utility knives, razor blade knives and serrated knives.



Cat. No.	Overall Size	Weight (lbs.)
48036	4" L x 2-1/4" W x 3/4" D (102 mm x 57 mm x 19 mm)	.10

⚠WARNING: Improper use of knife and scissors sharpener and/or failure to follow instructions can result in injuries. Keep your fingers behind the curved guard and your thumb securely on the multi-grooved thumb-rest indentation, never in front of it.

All dimensions are in inches and (millimeters).

⚠WARNING: Always wear approved eye protection.

⚠WARNING: Never use on or near live electrical circuits.

Special-Purpose Knives

Utility Knife – Retractable Blade



- Top button moves heavy-duty, razor-edged blade to any of three cutting positions.
- Double-ended, reversible blade retracts fully for carrying.
- Lightweight aluminum handle is shaped for comfort.
- Accepts most standard blades.
- Includes three standard blades, stored in handle.
- Blades made in the U.S.A.
- Leather holder available, Cat. No. 5185.

44100

Cat. No.	Length Closed	Weight (lbs.)
44100	6" (152 mm)	.22

Heavy-Duty Utility Knife – Quick Change Retractable Blade

KLEIN-KURVE

- Curved handle design with slip-resistant grip for comfort and ease of use.
- No tools required for quick blade change.
- Plastic holster with belt clip for convenient use.
- Safety overlap handle design for heavy-duty cutting.
- Retractable blade locks in three positions.
- Includes one heavy-duty blade and stores up to ten blades in handle.
- Fits most standard utility blades.
- Blades made in the U.S.A.



44107

Cat. No.	Length Closed	Weight (lbs.)
44107	7" (178 mm)	.50

Double-Locking Folding Utility Knife

- Blade locks in both the open and closed position – an exclusive Klein design.
- Easy blade thumb release – no tools required.
- Uses heavy duty utility blades – most common blade found on the jobsite.
- Includes pocket/belt clip for convenient storage.
- One blade included.

Utility Knife – Quick Change Retractable Blade



- Blade locks in three positions.
- Notch in bottom for cutting of cord or twine up to 1/8" (3 mm) diameter with blade in any position.
- No tools required for quick blade change.
- Includes three heavy-duty blades, stored in handle.
- Blades made in the USA.
- Leather holder available, Cat. No. 5185.

44105

Cat. No.	Length Closed	Weight (lbs.)
44105	6-3/8" (162 mm)	.42

Utility-Knife Blade Dispenser – 100 Blades

- Heavy-duty razor-edged blades.
- Universal size fits Klein and most other makes of utility knives.
- Blades are reversible for extra life.
- Dispenser mounts vertically to dispense one blade at a time.
- Dispenser measures 2-3/4" W x 1-1/8" D x 5" H (70 mm x 29 mm x 127 mm).
- Blades made in the U.S.A.



44102

Cat. No.	Contains	Weight (lbs.)
44102	utility-knife blade dispenser complete with 100 blades	1.00

Utility Knife Blades

- Heavy-duty razor-edged blades.
- Universal size fits Klein and most other makes of utility knives.
- Blades are reversible for extra life.
- Blades made in the U.S.A.



44101

Cat. No.	Blade Size	Package Size	Weight (lbs.)
44101	2-7/16" x .025" (62 mm x 6 mm)	5 blades	.05
44104	2-7/16" x .025" (62 mm x 6 mm)	bulk package of 400 blades	4.0



44108

Cat. No.	Length Closed	Overall Length with blade	Weight (lbs.)
44108	3" (76 mm)	6 1/8" (156 mm)	.30

All dimensions are in inches and (millimeters).

▲WARNING: Always wear approved eye protection.

▲WARNING: Never use on or near live electrical circuits.

▲WARNING: Blades are intended for cutting only, and should be handled and disposed of with care. Bending the blade can cause it to break, possibly resulting in bodily injury.

Special-Purpose Knives

Cable-Sheath Splitting Knife



1515-S

- Compact, lightweight knife for opening lead cables.
- Rugged, forged tempered cutlery steel blade.
- Sharp, chisel-shaped edge.
- Hammer head on back.
- Plastic-dipped handle for comfort.
- Leather guard available, Cat. No. 5574S.

Cat. No.	Overall Length	Blade Length	Weight (lbs.)
1515-S	7-3/8" (187 mm)	2-19/32" (66 mm)	.35

Bell System Cable-Sheath Splitting Knife – Heavy-Duty



1515-1

- Heavy-duty knife for splitting cable sheaths.
- Rugged, forged tempered cutlery steel blade.
- Sharp chisel-shaped edge.
- Plastic-dipped handle for comfort.
- Leather guard available, Cat. No. 5574L.

Cat. No.	Overall Length	Blade Length	Weight (lbs.)
1515-1	8-3/4" (222 mm)	4-1/2" (114 mm)	1.20

Cable/Lineman's Skinning Knives



1560-3



1570-3

- Three-inch steel blade withstands frequent scoring and slitting of cable jacket.
- Blade and ring are securely molded in handle.
- Notch on blade back for scraping or removing wire insulation.
- Comfortable textured handle with finger grooves and guard.
- Heavy-duty serrated steel blade for saw-action cutting (Cat. No. 1560-3).
- No contact between stainless steel ring and hardened steel blade (available on Cat. No. 1570-3).
- Rectangle-shaped handle design for attachment to some utility hot stick equipment.
- Leather sheath available, Cat. No. 5163.

Cat. No.	Description	Handle Color	Length Less Ring	Weight (lbs.)
1560-3	serrated blade, notch, and ring	black	8" (203 mm)	.30
1570-3	hook blade, notch, and ring	red	8" (203 mm)	.30
1570-3LR	hook blade and notch	red	8" (203 mm)	.29

Cable-Splicer's Kits



- Cuts cable, telephone wire, and strips insulation.
- Dimensions: 2-1/8" x 7-1/2" (54 mm x 191 mm).

Cat. No.	Kit Contains	Weight (lbs.)
46037	cable splicer's kit	.50

Cat. No.	Description
44200	cable-splicer's knife
2100-7	electrician's scissors with stripping notches
5187	slotted leather holder for belts up to 2" (51 mm) wide

Cat. No.	Kit Contains	Weight (lbs.)
46039	cable splicer's kit - with free-fall snip	.58

Cat. No.	Description
44200	cable-splicer's knife
2101-0	free-fall snip
5187	slotted leather holder for belts up to 2" (51 mm) wide

Cable-Splicer's Knife

- Special-purpose short blade with comfortable, full-sized, heavy-duty handle.
- Coping-type blade made of the finest cutlery steel, tough and carefully tempered to hold its edge.
- Handle is textured for comfort and firm grip.
- Hang hole for easy storage and portability.

Cat. No.	Overall Length	Blade Length	Weight (lbs.)
44200	6-1/4" (159 mm)	1-3/4" (44 mm)	.15



44200

All dimensions are in inches and (millimeters).

▲WARNING: Always wear approved eye protection.

▲WARNING: Never use on or near live electrical circuits.

▲WARNING: NOT insulated. Will NOT protect against electrical shock.



Electrician's Scissors

Electrician's Scissors



2100-5

- Designed for telecom and electrical applications and heavy-duty use.
- Strong, tough tempered steel.
- Nickel-plated finish resists corrosion.
- Scraper and file on outside of both blades.

Cat. No.	Overall Length	Cutting Length	Weight (lbs.)
2100-5	5-1/4" (133 mm)	1-7/8" (48 mm)	.20

Electrician's Scissors – Stripping Notches



2100-7

- Upper blade has notches for stripping 19 AWG and 23 AWG wire.
- Designed for telecom and electrical applications and heavy-duty use.
- Strong, tough tempered steel.
- Nickel-plated finish resists corrosion.
- Scraper and file on outside of both blades.
- Serrated, lower blade reduces slippage.

Cat. No.	Overall Length	Cutting Length	Weight (lbs.)
2100-7	5-1/4" (133 mm)	1-7/8" (48 mm)	.20

Stainless Steel Electrician's Scissors – Stripping Notches



2100-9



2100-8

- Stainless steel blades to maintain blade durability and sharpness.
- Blade is fully serrated for non-slip cutting action.
- Free-fall snip feature for ease of use (2100-8).
- Cuts electrical communication 19 AWG and 23 AWG wire.
- Extended handle provides comfort and cutting leverage for wire cutting application (2100-8).
- 56 HRC.

Cat. No.	Overall Length	Cutting Length	Weight (lbs.)
2100-8	6-5/16" (160 mm)	1-7/8" (48 mm)	.21
2100-9	5-1/4" (133 mm)	1-7/8" (48 mm)	.21

Industrial High-Leverage Shears

High-Leverage Snip



22000

- Nickel chrome plating resists corrosion and rusting.
- Broad, short jaws provide powerful cutting action (22001, 22002).
- One blade is serrated for non-slip cutting action (22001, 22002).
- Extended handle provides comfort and cutting leverage (22002, 22003).
- High-leverage provides powerful cutting action for light metals, rubber and heavy fabrics (22000, 22003).
- Cuts light wire, fabric, cable and cordage (22001).
- Cuts rubber, cables, light metal, wire metal screens, cordage, plastics and ropes (22002).

Cat. No.	Overall Length	Cutting Length	Weight (lbs.)
22000	7" (180 mm)	1-3/4" (45 mm)	.34
22001	8" (203 mm)	2" (51 mm)	.55
22002	8-1/2" (216 mm)	2" (51 mm)	.55
22003	9" (229 mm)	3" (76 mm)	.49

Large Broad Blade Utility Shear



22002

Broad Blade Utility Shear



22001

8" High-Leverage Utility Shear



22003

All dimensions are in inches and (millimeters).

▲WARNING: Always wear approved eye protection.

▲WARNING: Never use on or near live electrical circuits.



High-Leverage Kevlar® Snip



24000

- Nickel chrome plating resists corrosion and rusting.
- One blade is serrated for non-slip cutting action.
- Spring loaded for self-opening action.
- Handy closure lock for convenient storage (24000, 24001).
- Compatible for right- and left-handed users.
- Excellent for cutting Kevlar® insulation in fiber optic applications (24000, 24001).
- Excellent for cutting electronics and filaments (24005).

Cat. No.	Overall Length	Cutting Length	Weight (lbs.)
24000	6-1/2" (165 mm)	5/8" (16 mm)	.28
24001	6-1/2" (165 mm)	1" (25 mm)	.28
24005	5" (127 mm)	1" (25 mm)	.22

Spring Action Snip



24001

5" Electronic Filament Snip



24005

Kevlar® is a registered trademark of E.I. du Pont de Nemours and Company.

Bent Trimmers

8" Bent Trimmer

- Cuts plastic, rubber, rubber roofing, roofing materials, cording, vinyl, fiberglass components and cloth materials.



23008


- Nickel-chrome plating resists corrosion and rusting.
- Extended handle provides comfort and cutting leverage.



23010

10" Bent Trimmer

- Cuts plastic, rubber, rubber roofing, roofing materials, cording, vinyl, fiberglass insulation and cloth materials.

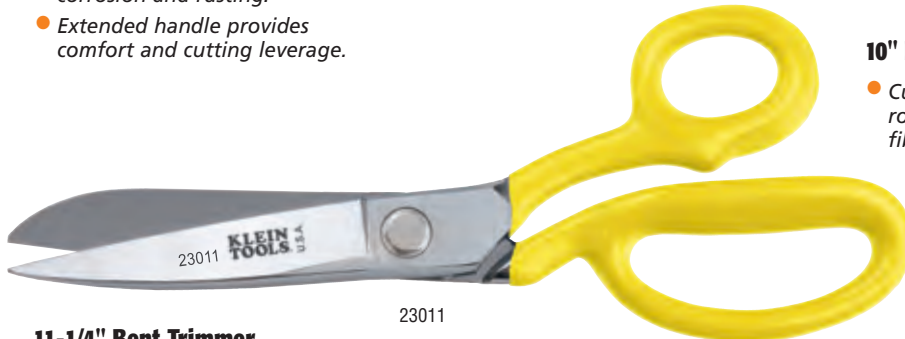

23011

11-1/4" Bent Trimmer

- Cuts felt lining, muslin, cord, rubber, abrasive materials and multiple layers of fabric.



23015

Single Serrated Blunt Blade Shear

- Cuts belting, abrasive belting, heavy fabric, leather, upholstery and heavy carpet.
- Deep serrated blade for non-slip cutting action.

Cat. No.	Overall Length	Cutting Length	Weight (lbs.)
23008	9" (229 mm)	3-1/2" (89 mm)	.41
23010	10-1/2" (267 mm)	4-1/2" (114 mm)	.99
23011	11-1/4" (286 mm)	4-3/4" (121 mm)	1.24
23015	9-3/4" (248 mm)	3-3/16" (81 mm)	.94

All dimensions are in inches and (millimeters).

WARNING: Always wear approved eye protection.

WARNING: Never use on or near live electrical circuits.

