

Cushion-Grip Nut Drivers

Cushion-Grip Hollow-Shaft Nut Drivers – 3" Shafts



630-1/2

Additional Features:

- Standard length for most applications.
- Fits over long bolts and studs.

Cat. No.	Color Code	Hex Size	Shaft Length	Overall Length	Weight (lbs.)
630-3/16	black	3/16"	3" (76 mm)	6-3/4" (171 mm)	.20
630-1/4	red	1/4"	3" (76 mm)	6-3/4" (171 mm)	.20
630-5/16	yellow	5/16"	3" (76 mm)	6-3/4" (171 mm)	.20
630-11/32	green	11/32"	3" (76 mm)	6-3/4" (171 mm)	.20
630-3/8	blue	3/8"	3" (76 mm)	6-3/4" (171 mm)	.20
630-7/16	brown	7/16"	3" (76 mm)	7-5/16" (186 mm)	.25
630-1/2	red	1/2"	3" (76 mm)	7-5/16" (186 mm)	.25
630-9/16	orange	9/16"	4" (102 mm)	9-3/8" (238 mm)	.35
630-5/8	yellow	5/8"	4" (102 mm)	9-3/8" (238 mm)	.35

Refer to the insulated section for insulated nut drivers.

Metric Cushion-Grip Hollow-Shaft Nut Drivers – 3" Shafts



630-11mm

Additional Features:

- Standard length for most applications.
- Fits over long bolts and studs.

Cat. No.	Color Code	Hex Size Metric	Shaft Length	Overall Length	Weight (lbs.)
630-4mm	red	4 mm	3" (76 mm)	6-3/4" (171 mm)	.20
630-4.5mm	yellow	4.5 mm	3" (76 mm)	6-3/4" (171 mm)	.20
630-5mm	black	5 mm	3" (76 mm)	6-3/4" (171 mm)	.20
630-5.5mm	brown	5.5 mm	3" (76 mm)	6-3/4" (171 mm)	.20
630-6mm	red	6 mm	3" (76 mm)	6-3/4" (171 mm)	.20
630-7mm	orange	7 mm	3" (76 mm)	6-3/4" (171 mm)	.20
630-8mm	yellow	8 mm	3" (76 mm)	6-3/4" (171 mm)	.20
630-9mm	green	9 mm	3" (76 mm)	6-3/4" (171 mm)	.20
630-10mm	blue	10 mm	3" (76 mm)	6-3/4" (171 mm)	.20
630-11mm	brown	11 mm	3" (76 mm)	7-5/16" (186 mm)	.20

Cushion-Grip Hollow-Shaft Nut Drivers – 6" Shafts

Additional Features:

- Reaches into deep recesses.
- Fits over extra-long bolts and studs.



646-1/2


Cat. No.	Color Code	Hex Size	Shaft Length	Overall Length	Weight (lbs.)
646-3/16	black	3/16"	6" (152 mm)	9-3/4" (248 mm)	.25
646-1/4	red	1/4"	6" (152 mm)	9-3/4" (248 mm)	.25
646-5/16	yellow	5/16"	6" (152 mm)	9-3/4" (248 mm)	.25
646-11/32	green	11/32"	6" (152 mm)	9-3/4" (248 mm)	.25
646-3/8	blue	3/8"	6" (152 mm)	9-3/4" (248 mm)	.30

Cat. No.	Color Code	Hex Size	Shaft Length	Overall Length	Weight (lbs.)
646-7/16	brown	7/16"	6" (152 mm)	10-5/16" (262 mm)	.35
646-1/2	red	1/2"	6" (152 mm)	10-5/16" (262 mm)	.35
646-9/16	orange	9/16"	6" (152 mm)	11-3/8" (289 mm)	.40
646-5/8	yellow	5/8"	6" (152 mm)	11-3/8" (289 mm)	.40

Magnetic Tip Nut Drivers – Hollow Shafts*

Additional Feature:

- Exclusive hollow shaft* design with Rare Earth magnetic tip features unobstructed pass-through, even on long bolts.

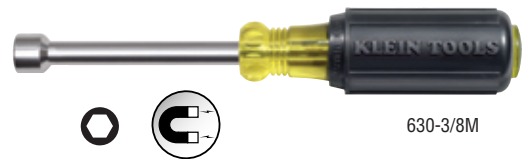

630-3/8M

Cat. No.	Color Code	Hex Size	Shaft Length	Overall Length	Weight (lbs.)
610-1/4M	1/4"	red	1-1/2" (38 mm)	1-1/2" (89 mm)	.10
610-5/16M	5/16"	yellow	1-1/2" (38 mm)	1-1/2" (89 mm)	.10
610-3/8M	3/8"	blue	1-1/2" (38 mm)	1-1/2" (89 mm)	.10
630-3/16M*	3/16"	black	3" (76 mm)	6-3/4" (171 mm)	.20
630-1/4M	1/4"	red	3" (76 mm)	6-3/4" (171 mm)	.20
630-5/16M	5/16"	yellow	3" (76 mm)	6-3/4" (171 mm)	.20
630-11/32M	11/32"	green	3" (76 mm)	6-3/4" (171 mm)	.20
630-3/8M	3/8"	blue	3" (76 mm)	6-3/4" (171 mm)	.20
630-7/16M	7/16"	brown	3" (76 mm)	7-5/16" (186 mm)	.25
630-1/2M	1/2"	red	3" (76 mm)	7-5/16" (186 mm)	.25

Cat. No.	Color Code	Hex Size	Shaft Length	Overall Length	Weight (lbs.)
646-3/16M	3/16"	black	6" (152 mm)	9-3/4" (248 mm)	.25
646-1/4M	1/4"	red	6" (152 mm)	9-3/4" (248 mm)	.25
646-5/16M	5/16"	yellow	6" (152 mm)	9-3/4" (248 mm)	.25
646-11/32M	11/32"	green	6" (152 mm)	9-3/4" (248 mm)	.25
646-3/8M	3/8"	blue	6" (152 mm)	9-3/4" (248mm)	.30
646-7/16M	7/16"	brown	6" (152 mm)	10-5/16" (262 mm)	.35
646-1/2M	1/2"	red	6" (152 mm)	10-5/16" (262 mm)	.35
618-1/4M	1/4"	red	18" (457 mm)	21-3/4" (552 mm)	.50
618-5/16M	5/16"	yellow	18" (457 mm)	21-3/4" (552 mm)	.50

*3/16" magnetic nut driver does not have a hollow shaft.

All dimensions are in inches* and (millimeters).

⚠WARNING: Always wear approved eye protection.

⚠WARNING: NOT insulated. Will NOT protect against electrical shock.

