


Wire Stripper/Cutter – Solid and Stranded Wire

- Strips six standard wire sizes without nicking wire.
- Scissors action of 1/2" (13 mm) wide cutter makes clean cuts with little effort.
- Serrated nose jaws to bend, shape or pull wire; holes for looping wire ends.
- Spring-loaded for self-opening action.
- Comfortable, plastic-covered handles.

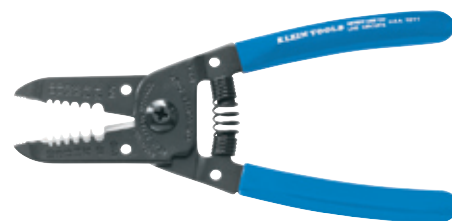

Cat. No.	Overall Length	Strips and Cuts	Handle Color	Weight (lbs.)
1011	6-1/8" (156 mm)	10 – 20 AWG solid & stranded (4.0 mm ² – .50 mm ²)	blue	.23


SOLID
10 – 20 AWG

STRANDED
10 – 20 AWG

1011

Adjustable Wire Strippers/Cutters – Solid and Stranded Wire

- A handy, light, compact tool for stripping insulation.
- Convenient hole for looping or bending wire.
- Black-oxide finish with plastic-dipped handles.
- Cuts, strips, and loops 12-26 solid and stranded wire.
- Adjustable slide stop with set screw for repeat stripping work.

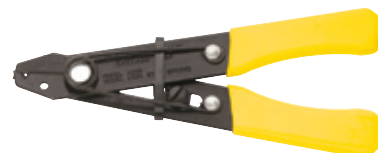

Cat. No.	Hold-Open Spring	Overall Length	Strips and Cuts	Handle Color	Weight (lbs.)
1004	yes	5" (127 mm)	12 – 26 AWG solid & stranded (2.5 mm ² – 0.14 mm ²)	yellow	.18
1003	no	5" (127 mm)	12 – 26 AWG solid & stranded (2.5 mm ² – 0.14 mm ²)	yellow	.14

SOLID
12 – 26 AWG

STRANDED
12 – 26 AWG

1004

Adjustable Wire Stripper – Solid and Stranded Wire

- Simply dial desired wire size for fast, easy stripping.
- Adjustable tool makes short work of cutting and stripping operations.
- Finely honed nose cutter easily gets into tight areas.
- Wire gauge dial sets stripping dies to proper size, helps prevent nicked wire.
- Black-oxide finish with plastic-dipped handles.
- Spring-loaded design – tool opens automatically after each action.



Cat. No.	Overall Length	Strips and Cuts	Handle Color	Weight (lbs.)
74007	5-1/20" (128 mm)	adjusts from 12 – 24 AWG (2.5 mm ² – .25 mm ²)	yellow	.15


SOLID
12 – 24 AWG

STRANDED
12 – 24 AWG

74007

Automatic Wire Stripper – Solid and Stranded Wire

- Strips from No. 10 to 22 AWG, up to a full 1" (24 mm).
- No nicking, cutting or fraying wire.
- Blades also available for 8 to 12 AWG and 16 to 26 AWG.
- Wire is automatically gripped and stripped with the same motion. Release pressure and jaws automatically open to release stripped wire. For clear nylon-jacket conductors, two activations are required.
- Plastic hand grips for comfort.
- Supplied with adjustable wire stop as standard feature, to assure uniform, precise strip length.

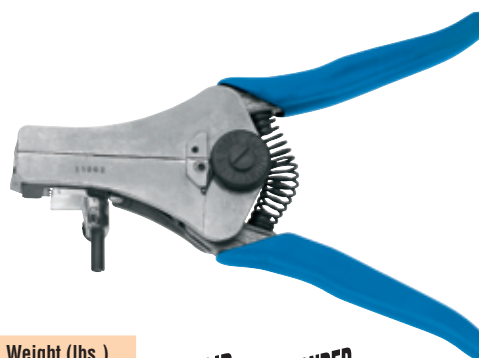

Cat. No.	Overall Length	Strips and Cuts	Handle Color	Weight (lbs.)
11062	6-1/2" (165 mm)	10 – 22 AWG (4.0 mm ² – .34 mm ²)	blue	.76
Replacement Blades (Pair)				
11070		8 – 12 AWG (6.0 mm ² – 2.5 mm ²)		.01
11072		10 – 22 AWG (4.0 mm ² – .34 mm ²)		.01
11075		16 – 26 AWG (1.0 mm ² – .14 mm ²)		.01
Replacement Adjustment Wire Stop				
11080				

SOLID

STRANDED

11062

All dimensions are in inches and (millimeters).

WARNING: NOT insulated. Plastic-dipped or slip-on plastic handles are NOT intended for protection against electrical shock.

WARNING: Never use on or near live electrical circuits.

WARNING: Always wear approved eye protection.

