


# Wire Strippers/Cutters

## Dual NM Cable Stripper/Cutter

- 12/2 and 14/2 stripping slots quickly remove outer jacket of Type NM-B nonmetallic-sheathed cable.
- Cushion grip handles provide comfort.
- Precision-ground stripping holes easily remove insulation on 12 and 14 AWG lead wires.
- Strong-gripping serrated nose; easy bending, shaping and pulling of wire.
- Narrow nose fits into tight places.
- Precision shear-type blades for square, clean cuts on solid copper wire.
- Holes for quick wire looping and bending.
- 6-32 and 8-32 screw-shearing holes.
- Spring-loaded for self-opening action.
- Handy closure lock for convenient storage.

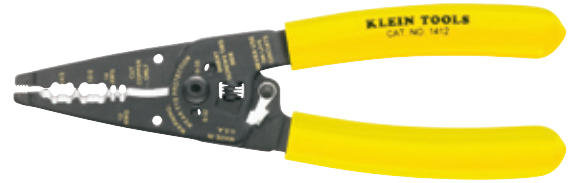

1412

Cat. No.	Handle Color	Overall Length	Strips and Cuts	Type NM-B Cable	Screw Shearing	Weight (lbs.)
1412	yellow	7-7/8" (200 mm)	12 & 14 AWG solid (2.5 mm <sup>2</sup> & 1.5 mm <sup>2</sup> )	12/2 & 14/2	6-32 & 8-32	.39

## Type NM Cable Strippers/Cutters

- Patented stripping slot quickly removes outer jacket of Type NM-B nonmetallic-sheathed cable.
- Handle grips with cushion ridges provide comfort.
- Precision-ground stripping hole easily removes insulation on lead wires.
- Serrated nose easily bends, shapes, or pulls wire.
- Narrow nose fits into tight places.
- Shear-type steel blades for square, clean cuts on solid copper wire.
- Spring-loaded for self-opening action.
- Handy closure lock for convenient storage.
- Holes for looping and bending wire.
- Handle tip identifies size of cable.



1012

Cat. No.	Handle Color	Overall Length	Strips and Cuts	Type NM-B Cable	Weight (lbs.)
1012	yellow/grey with marking 12/2 at tip	6-1/4" (159 mm)	12 AWG solid (2.5 mm <sup>2</sup> )	12/2	.26
1014	yellow/white with marking 14/2 at tip	6-1/4" (159 mm)	14 AWG solid (1.5 mm <sup>2</sup> )	14/2	.26

Strippers, Cutters & Crimpers



## NM Cable Rippers

### NM Cable Rippers

- Easy-to-use cable rippers.
- Slit the outer jacket of Romex<sup>®</sup> cable (all sizes) and other nonmetallic (type NM) sheathed cable.
- Measure conductor wire gauge.



74017



74018

Cat. No.	Overall Length	Slits	Measures Wire Gauge	Weight (lbs.)
74017	4" (102 mm)	all sizes of Romex <sup>®</sup> and NM	8 – 14 AWG (6 mm <sup>2</sup> – 1 mm <sup>2</sup> )	.08
74018	3-1/2" (89 mm)	all sizes of Romex <sup>®</sup> and NM	6 – 14 AWG (10 mm <sup>2</sup> – 1.5 mm <sup>2</sup> )	.08

Romex<sup>®</sup> is a registered trademark of General Cable Corporation.

All dimensions are in inches and (millimeters).

**▲WARNING:** NOT insulated. Plastic-dipped or slip-on plastic handles are NOT intended for protection against electrical shock.

**▲WARNING:** Never use on or near live electrical circuits.

**▲WARNING:** Always wear approved eye protection.

