




ID STANDARD WALL (SW) ENCASED BURIAL (EB) OR DIRECT BURIAL (DB) PRODUCTS

ID STANDARD WALL (SW) CONDUIT

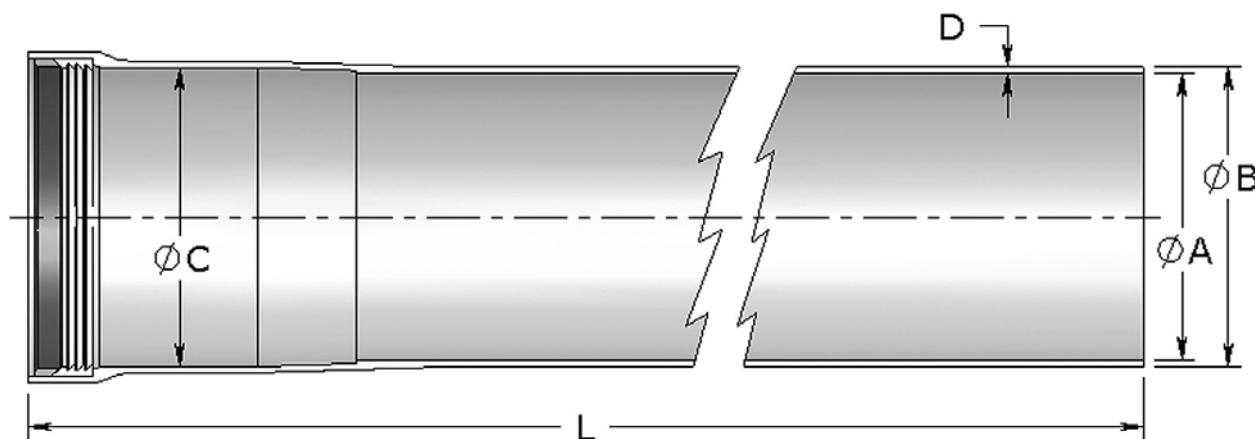

Size	Symbol	ØA	ØB	ØC	D	L	ØA	ØB	ØC	D	L	
in	mm	inches					millimeters					meters
2	53	40-2000	2.000	2.140	2.170	0.070	236.25	50.8	54.4	55.1	1.8	6
2½	63	40-2500	2.500	2.640	2.670	0.070	236.25	63.5	67.1	67.8	1.8	6
3	78	40-3000	3.000	3.140	3.170	0.070	236.25	76.2	79.8	80.5	1.8	6
3½	91	40-3500	3.500	3.640	3.670	0.070	236.25	88.9	92.5	93.2	1.8	6
4	103	40-4000	4.000	4.140	4.170	0.070	236.25	101.6	105.2	105.9	1.8	6
4½	116	40-4500	4.500	4.690	4.730	0.095	236.25	114.3	119.1	120.1	2.4	6
5	129	40-5000	5.000	5.190	5.230	0.095	236.25	127.0	131.8	132.8	2.4	6
6	155	40-6000	6.000	6.190	6.230	0.095	236.25	152.4	157.2	158.2	2.4	6

- All our ID Below Ground products are offered with a TriSeal™ push-fit assembly
- Adhesives are available, if required.
- Standard length is 19.68 ft. (6m) but can also be available in 9.84 ft. section (3m), if required.
- Spigot end tapered for ease of installation

