


BELOW GROUND



ID SW 90° ELBOW

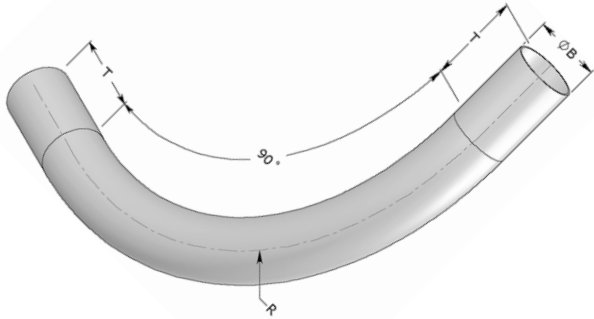

12" RADIUS

Size	Symbol	ØB	R	T	ØB	R	T
in	mm	inches			millimeters		
2	53 40-2030R12	2.140	12	6	54.4	304.8	152.4

18" RADIUS

Size	Symbol	ØB	R	T	ØB	R	T
in	mm	inches			millimeters		
2	53 40-2030R18	2.140	18	6	54.4	457.2	152.4
2½	63 40-2530R18	2.640	18	6	67.1	457.2	152.4

24" RADIUS

Size	Symbol	ØB	R	T	ØB	R	T
in	mm	inches			millimeters		
2	53 40-2030R24	2.140	24	6	54.4	609.6	152.4
2½	63 40-2530R24	2.640	24	6	67.1	609.6	152.4
3	78 40-3030R24	3.140	24	6	79.8	609.6	152.4

36" RADIUS

Size	Symbol	ØB	R	T	ØB	R	T
in	mm	inches			millimeters		
2	53 40-2030R36	2.140	36	6	54.4	914.4	152.4
2½	63 40-2530R36	2.640	36	6	67.1	914.4	152.4
3	78 40-3030R36	3.140	36	6	79.8	914.4	152.4
3½	91 40-3530R36	3.640	36	6	92.5	914.4	152.4
4	103 40-4030R36	4.140	36	6	105.2	914.4	152.4
4½	116 40-4530R36	4.690	36	6	119.1	914.4	152.4
5	129 40-5030R36	5.190	36	6	131.8	914.4	152.4
6	155 40-6030R36	6.190	36	6	157.2	914.4	152.4

48" RADIUS

Size	Symbol	ØB	R	T	ØB	R	T
in	mm	inches			millimeters		
2	53 40-2030R48	2.140	48	6	54.4	1219.2	152.4
2½	63 40-2530R48	2.640	48	6	67.1	1219.2	152.4
3	78 40-3030R48	3.140	48	6	79.8	1219.2	152.4
3½	91 40-3530R48	3.640	48	6	92.5	1219.2	152.4
4	103 40-4030R48	4.140	48	6	105.2	1219.2	152.4
4½	116 40-4530R48	4.690	48	6	119.1	1219.2	152.4
5	129 40-5030R48	5.190	48	6	131.8	1219.2	152.4
6	155 40-6030R48	6.190	48	6	157.2	1219.2	152.4

60" RADIUS

Size	Symbol	ØB	R	T	ØB	R	T
in	mm	inches			millimeters		
2	53 40-2030R60	2.140	60	6	54.4	1524.0	152.4
2½	63 40-2530R60	2.640	60	6	67.1	1524.0	152.4
3	78 40-3030R60	3.140	60	6	79.8	1524.0	152.4
3½	91 40-3530R60	3.640	60	6	92.5	1524.0	152.4
4	103 40-4030R60	4.140	60	6	105.2	1524.0	152.4
4½	116 40-4530R60	4.690	60	6	119.1	1524.0	152.4
5	129 40-5030R60	5.190	60	6	131.8	1524.0	152.4
6	155 40-6030R60	6.190	60	6	157.2	1524.0	152.4

72" RADIUS

Size	Symbol	ØB	R	T	ØB	R	T
in	mm	inches			millimeters		
2	53 40-2030R72	2.140	72	6	54.4	1828.8	152.4
2½	63 40-2530R72	2.640	72	6	67.1	1828.8	152.4
3	78 40-3030R72	3.140	72	6	79.8	1828.8	152.4
3½	91 40-3530R72	3.640	72	6	92.5	1828.8	152.4
4	103 40-4030R72	4.140	72	6	105.2	1828.8	152.4
4½	116 40-4530R72	4.690	72	6	119.1	1828.8	152.4
5	129 40-5030R72	5.190	72	6	131.8	1828.8	152.4
6	155 40-6030R72	6.190	72	6	157.2	1828.8	152.4

ID SW

