

WALL FAN HEATER

WF SERIES

VERSATILITY IS THE NAME OF THE GAME!

The WF is a high-capacity fan heater that's ideal for building lobbies, long corridors, stairwells, workshops, factories, and warehouses. Its electrical element is made of high-quality nichrome assuring an immediate surge of hot air. The various modes of wall installation make the WF heater one of the most versatile fan heaters on the market: it can be surface mounted or recessed, with a variety of models and heating capacities to choose from.



NEW GRILLE WITH ROUNDED SIDES
DURABLE AND STYLISH

WIDE RANGE OF MODELS & HEATING CAPACITIES
INCLUDING A 4800 W SINGLE MODEL

NICHROME ELEMENT
ASSURING INSTANT HEAT

NEW DISCONNECT SWITCH
OPTIONAL

IDEAL FOR:
LOBBY, CORRIDOR, FACTORY, WAREHOUSE, STAIRWELL

- COLOURS**
- standard: white, soft white
 - luxurious finish: stainless steel (see price list)
 - ORORA (optional): denim blue, midnight blue, turquoise, moss green, canary yellow, red, orange, anodized aluminum paint, gravel gray, charcoal, espresso, black (refer to [page 8 of the catalogue](#))


FINISH
epoxy-polyester powdercoat or stainless steel

- MANUFACTURING**
- 20-gauge steel cabinet and 18-gauge steel grille
 - top air intake with bottom air discharge
 - quiet helicoidal fan: single unit 1 x 160 CFM - double unit 2 x 160 CFM - triple unit 3 x 160 CFM
 - thermal protection with automatic reset
 - totally enclosed, permanently lubricated motor

ELEMENT
high quality nichrome element producing instant heat

CONTROL
connection of multiple units to the same thermostat is possible with a relay kit without transformer (optional) and an external transformer (not provided)

- INSTALLATION**
- wall mounted
 - recessed or surface mounted with surface adapter (optional)

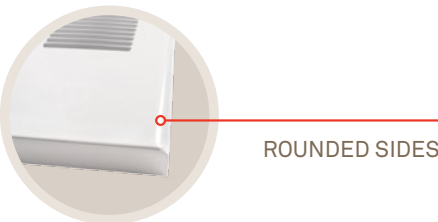

ACCESSORIES		
PRODUCT	DESCRIPTION	PRICE
WFT1	built-in single pole thermostat [120 V-600 V]	43.50
WFT2	built-in double pole thermostat [120 V-600 V]	55.75
WFSA1*	surface adapter (single unit)	58.50
WFSA2*	surface adapter (double unit)	119.00
WFSA3*	surface adapter (triple unit)	178.00
WFSA1SS	stainless steel surface adapter (single unit)	144.00
WFSA2SS	stainless steel surface adapter (double unit)	247.00
WFSA3SS	stainless steel surface adapter (triple unit)	348.00
WFDIS-30*	disconnect switch kit 600 V/30 A, 2 poles	115.00
WFDIS-40*	disconnect switch kit 600 V/40 A, 2 poles/3 poles	136.00
WFDIS-60*	disconnect switch kit 600 V/60 A, 2 poles/3 poles	165.00
WFC24RX*	relay kit without transformer 24 V	100.00

* Add W for white or SW for soft white
* Factory installation

TECHNICAL SPECIFICATIONS

WITHOUT CONTROL			BUILT-IN THERMOSTAT			240 V CONTROL	24 V CONTROL			POWER	VOLTAGE	WEIGHT	MODEL	
CODE	PRICE W OR SW	PRICE SS	CODE	PRICE W OR SW	PRICE SS	CODE	CODE	PRICE W OR SW	PRICE SS	WATTS	VOLTS	KG	LB	UNIT
WF1508	471.00	581.00	WF1508T	515.00	625.00	WF1508C	WF1508C24	607.00	717.00	1500	208	9	20	SINGLE
WF1502	471.00	581.00	WF1502T	515.00	625.00	WF1502C	WF1502C24	607.00	717.00	1500/1125	240/208	9	20	SINGLE
WF1507	724.00	834.00	WF1507T	768.00	878.00	WF1507C	WF1507C24	860.00	970.00	1500	277	9	20	SINGLE
WF1503	687.00	797.00	WF1503T	731.00	841.00	WF1503C	WF1503C24	823.00	933.00	1500	347	9	20	SINGLE
---	---	---	WF1505T	768.00	878.00	WF1505C	WF1505C24	860.00	970.00	1500	480	9	20	SINGLE
---	---	---	WF1506T	768.00	878.00	WF1506C	WF1506C24	860.00	970.00	1500	600	10	22	SINGLE
WF2008	471.00	581.00	WF2008T	515.00	625.00	WF2008C	WF2008C24	607.00	717.00	2000	208	9	20	SINGLE
WF2002	471.00	581.00	WF2002T	515.00	625.00	WF2002C	WF2002C24	607.00	717.00	2000/1500	240/208	9	20	SINGLE
WF2007	724.00	834.00	WF2007T	768.00	878.00	WF2007C	WF2007C24	860.00	970.00	2000	277	9	20	SINGLE
WF2003	687.00	797.00	WF2003T	731.00	841.00	WF2003C	WF2003C24	823.00	933.00	2000	347	9	20	SINGLE
---	---	---	WF2005T	768.00	878.00	WF2005C	WF2005C24	860.00	970.00	2000	480	9	20	SINGLE
---	---	---	WF2006T	768.00	878.00	WF2006C	WF2006C24	860.00	970.00	2000	600	10	22	SINGLE
WF3008	484.00	594.00	WF3008T	526.00	636.00	WF3008C	WF3008C24	620.00	730.00	3000	208	9	20	SINGLE
WF3002	484.00	594.00	WF3002T	526.00	636.00	WF3002C	WF3002C24	620.00	730.00	3000/2250	240/208	9	20	SINGLE
WF3007	737.00	847.00	WF3007T	780.00	890.00	WF3007C	WF3007C24	873.00	983.00	3000	277	9	20	SINGLE
WF3003	700.00	810.00	WF3003T	744.00	854.00	WF3003C	WF3003C24	836.00	946.00	3000	347	9	20	SINGLE
---	---	---	WF3005T	780.00	890.00	WF3005C	WF3005C24	873.00	983.00	3000	480	9	20	SINGLE
---	---	---	WF3006T	780.00	890.00	WF3006C	WF3006C24	873.00	983.00	3000	600	10	22	SINGLE
WF4008	521.00	631.00	WF4008T	564.00	674.00	WF4008C	WF4008C24	657.00	767.00	4000	208	9	20	SINGLE
WF4002	521.00	631.00	WF4002T	564.00	674.00	WF4002C	WF4002C24	657.00	767.00	4000/3000	240/208	9	20	SINGLE
WF4007	774.00	884.00	WF4007T	818.00	928.00	WF4007C	WF4007C24	910.00	1020.00	4000	277	9	20	SINGLE
WF4003	737.00	847.00	WF4003T	780.00	890.00	WF4003C	WF4003C24	873.00	983.00	4000	347	9	20	SINGLE
---	---	---	WF4005T	818.00	928.00	WF4005C	WF4005C24	910.00	1020.00	4000	480	9	20	SINGLE
---	---	---	WF4006T	818.00	928.00	WF4006C	WF4006C24	910.00	1020.00	4000	600	10	22	SINGLE
WF4808	546.00	656.00	WF4808T	592.00	702.00	WF4808C	WF4808C24	689.00	799.00	4800	208	9	20	SINGLE
WF4802	546.00	656.00	WF4802T	592.00	702.00	WF4802C	WF4802C24	689.00	799.00	4800/3600	240/208	9	20	SINGLE
WF4807	812.00	922.00	WF4807T	858.00	968.00	WF4807C	WF4807C24	956.00	1066.00	4800	277	9	20	SINGLE
WF4803	773.00	883.00	WF4803T	819.00	929.00	WF4803C	WF4803C24	916.00	1026.00	4800	347	9	20	SINGLE
---	---	---	WF4805T	858.00	968.00	WF4805C	WF4805C24	956.00	1066.00	4800	480	9	20	SINGLE
---	---	---	WF4806T	858.00	968.00	WF4806C	WF4806C24	956.00	1066.00	4800	600	10	22	SINGLE
---	---	---	WF6008CT	1344.00	1554.00	WF6008C	WF6008C24	1300.00	1510.00	6000	208	18	40	DOUBLE
---	---	---	WF6002T	1207.00	1417.00	WF6002C	WF6002C24	1300.00	1510.00	6000/4500	240/208	18	40	DOUBLE
---	---	---	WF6007T	1578.00	1788.00	WF6007C	WF6007C24	1670.00	1880.00	6000	277	18	40	DOUBLE
---	---	---	WF6003T	1578.00	1788.00	WF6003C	WF6003C24	1670.00	1880.00	6000	347	18	40	DOUBLE
---	---	---	WF6005T	1578.00	1788.00	WF6005C	WF6005C24	1670.00	1880.00	6000	480	20	44	DOUBLE
---	---	---	WF6006T	1578.00	1788.00	WF6006C	WF6006C24	1670.00	1880.00	6000	600	20	44	DOUBLE
---	---	---	WF60083CT*	1344.00	1609.00	WF60083C*	WF60083C24*	1300.00	1565.00	6000	208	36	80	TRIPLE
---	---	---	WF60053CT*	1713.00	1978.00	WF60053C*	WF60053C24*	1670.00	1935.00	6000	480	36	80	TRIPLE
---	---	---	WF60063CT*	1713.00	1978.00	WF60063C*	WF60063C24*	1670.00	1935.00	6000	600	36	80	TRIPLE
---	---	---	WF8008CT	1429.00	1639.00	WF8008C	WF8008C24	1386.00	1596.00	8000	208	18	40	DOUBLE
---	---	---	WF8002CT	1429.00	1639.00	WF8002C	WF8002C24	1386.00	1596.00	8000/6000	240/208	18	40	DOUBLE
---	---	---	WF8007CT	1942.00	2152.00	WF8007C	WF8007C24	1900.00	2110.00	8000	277	18	40	DOUBLE
---	---	---	WF8003CT	1942.00	2152.00	WF8003C	WF8003C24	1900.00	2110.00	8000	347	18	40	DOUBLE
---	---	---	WF8005CT	1942.00	2152.00	WF8005C	WF8005C24	1900.00	2110.00	8000	480	20	44	DOUBLE
---	---	---	WF8006CT	1942.00	2152.00	WF8006C	WF8006C24	1900.00	2110.00	8000	600	20	44	DOUBLE
---	---	---	WF90083CT*	1950.00	2215.00	WF90083C*	WF90083C24*	1906.00	2171.00	9000	208	36	80	TRIPLE
---	---	---	WF90053CT*	2550.00	2815.00	WF90053C*	WF90053C24*	2506.00	2771.00	9000	480	36	80	TRIPLE
---	---	---	WF90063CT*	2550.00	2815.00	WF90063C*	WF90063C24*	2506.00	2771.00	9000	600	36	80	TRIPLE
---	---	---	WF12008CT	2135.00	2400.00	WF12008C	WF12008C24	2092.00	2357.00	12 000	208	36	80	TRIPLE
---	---	---	WF12002CT	2135.00	2400.00	WF12002C	WF12002C24	2092.00	2357.00	12 000/9000	240/208	36	80	TRIPLE
---	---	---	WF12007CT	2735.00	3000.00	WF12007C	WF12007C24	2692.00	2957.00	12 000	277	36	80	TRIPLE
---	---	---	WF12003CT	2735.00	3000.00	WF12003C	WF12003C24	2692.00	2957.00	12 000	347	36	80	TRIPLE
---	---	---	WF12005CT	2735.00	3000.00	WF12005C	WF12005C24	2692.00	2957.00	12 000	480	36	80	TRIPLE
---	---	---	WF12006CT	2735.00	3000.00	WF12006C	WF12006C24	2692.00	2957.00	12 000	600	36	80	TRIPLE
---	---	---	WF120083CT*	2135.00	2400.00	WF120083C*	WF120083C24*	2092.00	2357.00	12 000	208	36	80	TRIPLE
---	---	---	WF120053CT*	2735.00	3000.00	WF120053C*	WF120053C24*	2692.00	2957.00	12 000	480	36	80	TRIPLE
---	---	---	WF120063CT*	2735.00	3000.00	WF120063C*	WF120063C24*	2692.00	2957.00	12 000	600	36	80	TRIPLE


Add W for white, SW for soft white or SS for stainless steel (see [page 8 of the catalogue](#) for optional colours and contact your °STELPRO representative for all other colours)

* Three-phase unit


--- not available

THROW DISTANCE AND HEAT RISE


UNITS		THROW DISTANCE		HEAT RISE	
KW	M	FT.	°C	°F	
1.5	4.1	13'7"	30	53	
2	4.1	13'7"	42	75	
3	4.1	13'7"	61	110	
4	4.1	13'7"	74	133	
4.8	4.1	13'7"	93	167	
6	4.1	13'7"	61	110	
8	4.1	13'7"	74	133	
9	4.1	13'7"	61	110	
12	4.1	13'7"	74	133	

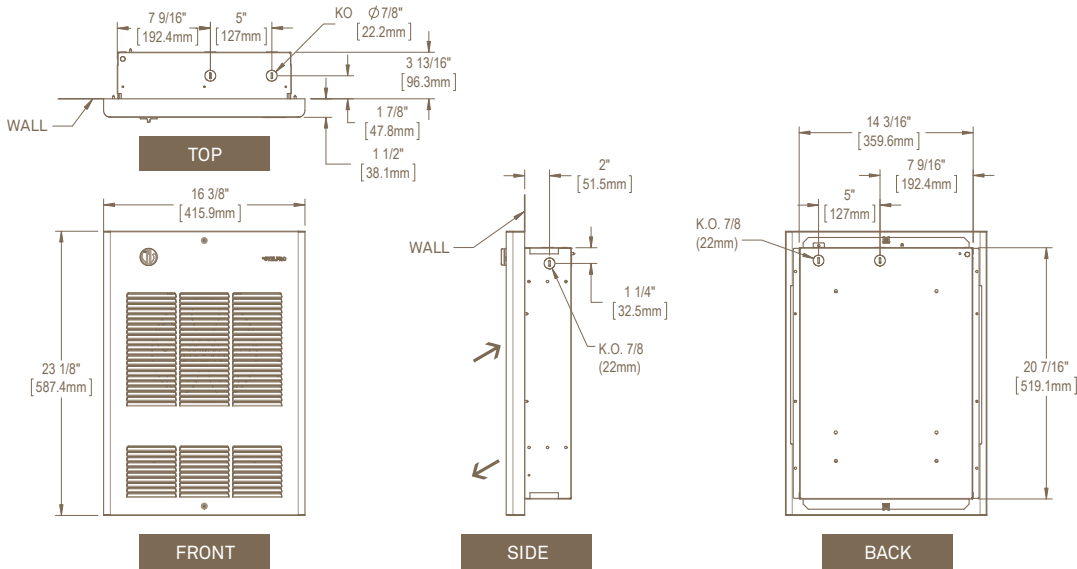

SINGLE UNIT

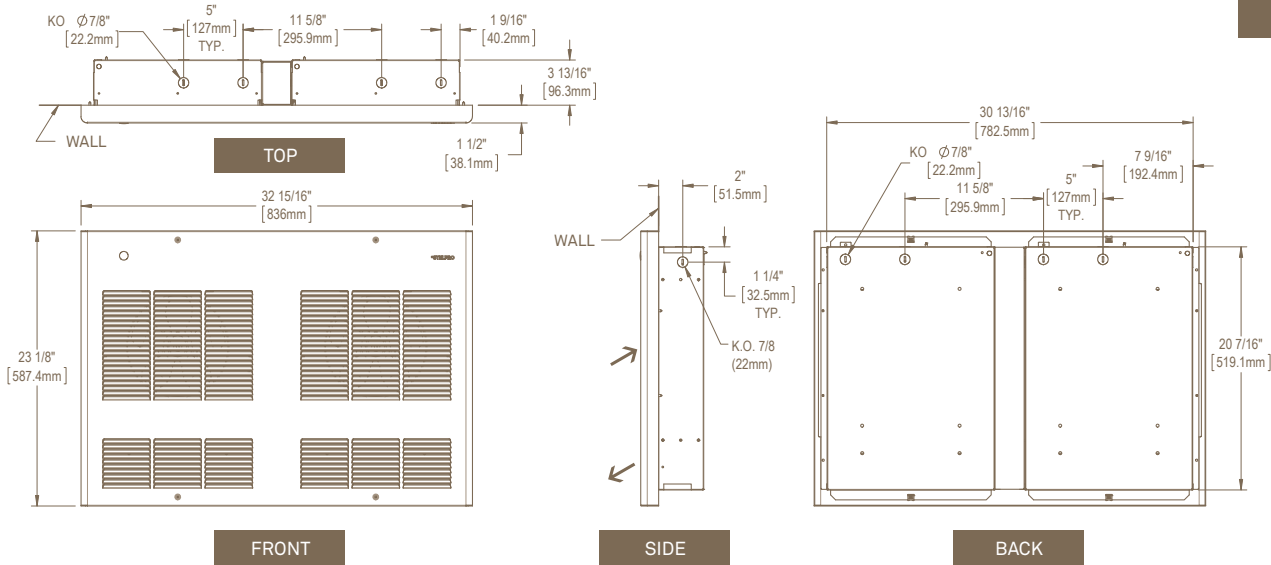

DOUBLE UNIT

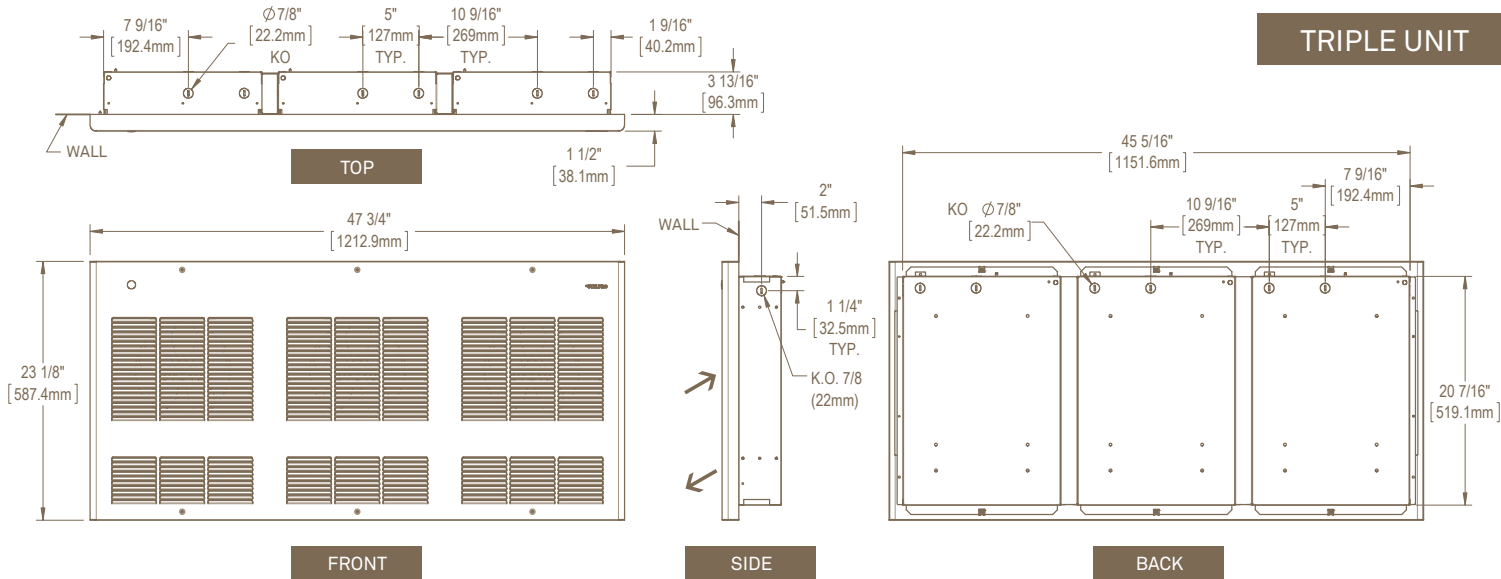

TRIPLE UNIT